


8501XTE1

NEMA Control Relay, Type X, pneumatic timer attachment, one minute on delay, 10A resistive at 600 VAC, 1 NO and 1 NC

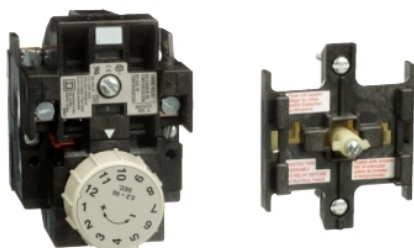

Main

Range of Product	8501X
Relay Type	Control relay
Product or Component Type	Timing relay

Complementary

Contacts Configuration	1 NO/1 NC
Time delay type	On-delay
Time range	0.2...60 s
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 18...AWG 12 copper
Terminal Tightening Torque	Control circuit 9.03...12.04 lbf.in (1.02...1.36 N.m) screw terminals

Environment

Product Certifications	CSA LR60905 class 3211 02 CE UL recognized E78403 CCN NKCR2
------------------------	---

Ordering and shipping details

Category	21159 - 8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	785901537342
Nbr. of units in pkg.	1
Package weight(Lbs)	12.16 oz (344.7 g)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	3.31 in (8.4 cm)
Package 1 width	4.41 in (11.2 cm)
Package 1 Length	6.42 in (16.3 cm)

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------