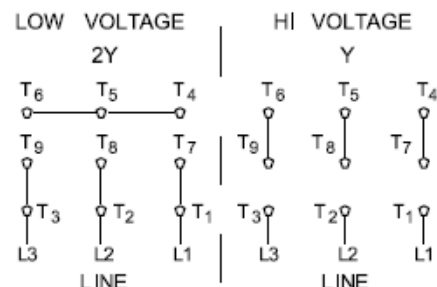


Dayton[®]**WASHDOWN PREMIUM
EFFICIENT MOTOR****CC082A**

MODEL NO. 4GPT4A

MFG.NO. WTL145T-4W

PH 3

CONNECTIONTO REVERSE ROTATION INTERCHANGE
ANY TWO LINELEADS**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.



ENCL. TEFC

MAX.AMB. 40 °C

HP 2.0/1.5

DUTY CONT.

RPM 1750/1450

HZ 60/50

VOLT 230/460

VOLT 190/380

F.L.A. 6.0/3.0

F.L.A. 5.2/2.6

S.F.A. 6.8/3.4

S.F.A. 6.0/3.0

SER. FACT. 1.15

INS.CL. F

FRAME 145TC

NEMA NOM.EFF. 86.5%

P.F. 0.83

CODE K

DES. B

BRG. SHAFT END 6205

BRG.OPPOSITE SHAFT END 6205

Thermally Protected NONE

DATE CODE 1207

Mfd.For Dayton Electric Mfg.Co.,Lake Forest,IL 60045 USA

Made in China