


RDC24 Relay Module

Description

Altronix RDC24 DIN rail mountable relay is designed for continuous duty. This rugged and dependable relay will handle any switching application.

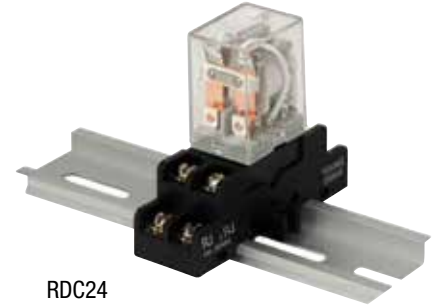

RDC24

Specifications

Input

Voltage	24VDC.
Current Draw	43mA.

Contact Rating 10A/220VAC or 28VDC DPDT contacts.

Agency Listings

UL and cUL Recognized.
CE European Conformity.

Physical and Environmental

Dimensions (W x D x H)

3.125" x 1.375" x 2.375" (79.4mm x 35mm x 86mm).

Product Weight 0.1 lbs. (0.05 kg).

Shipping Weight 0.15 lbs. (0.07 kg).

Temperature

Operating -25°C to 55°C (-13°F to 131°F).

Storage -25°C to 70°C (-13°F to 158°F).

Relative Humidity 85% +/-5%.