

Perlator® Faucet Aerator - 1.5 gpm Flow Restricted Regular Size




flow, stop and go®

Features and Benefits

- ▶ Watercolours® design: Color coding to identify flow rate and stream pattern.
- ▶ Patented construction provides a splash-free stream, well-aerated and soft to the touch.
- ▶ Integrated anti-liming honeycomb replaces conventional wire mesh screens prone to lime build up.
- ▶ Anti-clogging dome screen filters sediment and particles.
- ▶ Compatible with regular and vandal proof M22 & M24 metric housings.
- ▶ Available housing finishes: chrome, polished brass, brushed nickel and oil rubbed bronze.
- ▶ Laser marked housings with statutory marks.

Certifications

ANSI/NSF®-61-372
ASME A112.18.1M and CSA B125
Meets **CALGreen** requirements
WaterSense

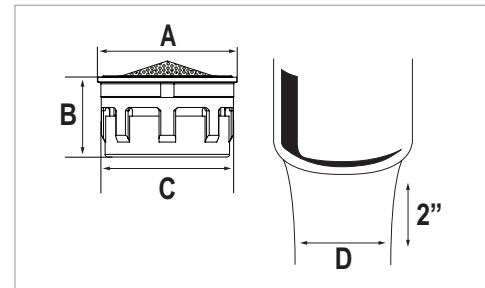

Dimensions

No	mm	In
A	20.88	.822
B	12.00	.472
C	19.97	.786
D	≈ 13	≈ 1/2

Housings



Technical Data


Materials: Body Acetal
Washer EPDM

Continuous		Short-term (5 minutes max.) Per ASME A112.18.1 testing requirements.	
max. 60 °C	max. 140 °F	max. 70 °C	max. 160 °F
90 psi max.	6.2 bar max.	125 psi max.	8.5 bar max.

Thread & Part Number			
Part #	Designation	Thread Size	Qty.
5504705	Insert only		1
5500205	Regular male	15/16"-27	1
5500705	Regular female	55/64"-27	1
5501205	Regular dual thread	15/16"-27 x 55/64"-27	1
5505403	Regular dual thread	15/16"-27 x 55/64"-27	6
5505804	Regular dual thread	15/16"-27 x 55/64"-27	50
5502405	Vandal proof regular male	15/16"-27	1
5502705	Vandal proof regular dual thread	15/16"-27 x 55/64"-27	1
5502706	Vandal proof regular dual thread	15/16"-27 x 55/64"-27	40

Color Code		
Dome	Ring	Basket
Green	Green	Dark Gray

Flow Rate Curve

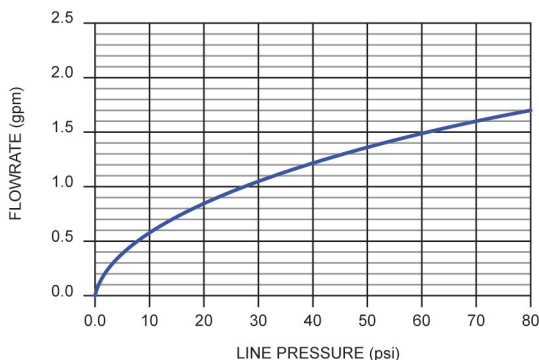

NEOPERL, Inc., Waterbury, CT • Tel: 203-756-8437 • Fax: 203-574-2107 • www.neoperl.com