

# Careguard®

## Laminar Stream - 1.5 gpm

### Flow Restricted Regular Size




flow, stop and go®

#### Features and Benefits

- ▶ With built-in Agion® antimicrobial product technology.
- ▶ Provides a splash-free crystal clear (non-aerated) stream.
- ▶ Saves water and energy.
- ▶ Unique screenless Cascade® construction hinders lime build up.
- ▶ Recommended for use in healthcare facilities to prevent mixing air and water.
- ▶ Compatible with regular and vandal proof M22 & M24 metric housings.
- ▶ Available housing finishes: chrome, polished brass, brushed nickel and oil rubbed bronze.
- ▶ Laser marked housings with statutory marks.

#### Certifications

ANSI/NSF®-61-372  
 ASME A112.18.1M and CSA B125  
 Meets **CALGreen** requirements  
 WaterSense

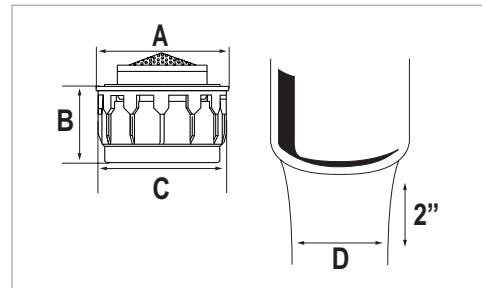

#### Dimensions

No	mm	In
A	20.93	.823
B	11.95	.470
C	20.00	.787
D	≈ 13	≈ 1/2

#### Thread & Part Number

Part #	Designation	Thread Size	Qty.
5504805	Insert only		1
5500305	Regular male	15/16" -27	1
5500805	Regular female	55/64" -27	1
5501305	Regular dual thread	15/16" -27 x 55/64" -27	1
5505503	Regular dual thread	15/16" -27 x 55/64" -27	6
5501304	Regular dual thread	15/16" -27 x 55/64" -27	50
5506106	Vandal proof regular dual thread	15/16" -27 x 55/64" -27	40


#### Housings



#### Color Code

Dome	Ring	Basket
Light Gray	Light Gray	Light Gray

#### Flow Rate Curve


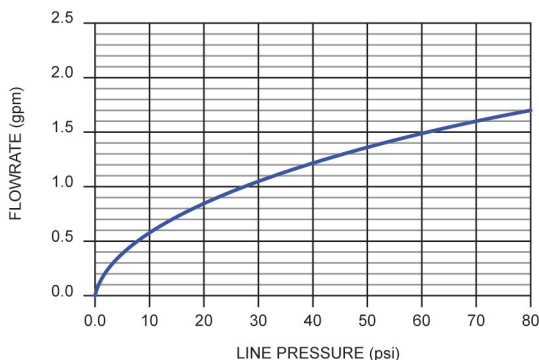


#### Technical Data

Materials: Body Acetal with Agion®  
 Washer EPDM

Continuous

  Short-term (5 minutes max.)  
 Per ASME A112.18.1 testing requirements.



NEOPERL, Inc., Waterbury, CT • Tel: 203-756-8437 • Fax: 203-574-2107 • www.neoperl.com