

Perlator® Faucet Aerator - 2.2 gpm Flow Restricted Regular Size



flow, stop and go®

Features and Benefits

- ▶ Watercolours® design: Color coding to identify flow rate and stream pattern.
- ▶ Patented construction provides a splash-free stream, well-aerated and soft to the touch.
- ▶ Integrated anti-liming honeycomb replaces conventional wire mesh screens prone to lime build up.
- ▶ Anti-clogging dome screen filters sediment and particles.
- ▶ Compatible with regular and vandal proof M22 & M24 metric housings.
- ▶ Available housing finishes: chrome, polished brass, brushed nickel and oil rubbed bronze.
- ▶ Laser marked housings with statutory marks.

Certifications

ANSI/NSF®-61-372
ASME A112.18.1M and CSA B125


Thread & Part Number

Part #	Designation	Thread Size	Qty.
5504905	Insert only		1
5500405	Regular male	15/16" -27	1
5500905	Regular female	55/64" -27	1
5501405	Regular dual thread	15/16" -27 x 55/64" -27	1
5505603	Regular dual thread	15/16" -27 x 55/64" -27	6
5505904	Regular dual thread	15/16" -27 x 55/64" -27	50
5502505	Vandal proof regular male	15/16" -27	1
5502805	Vandal proof regular dual thread	15/16" -27 x 55/64" -27	1
5502806	Vandal proof regular dual thread	15/16" -27 x 55/64" -27	40


Color Code

Dome	Ring	Basket
Red	Red	Dark Gray

Flow Rate Curve

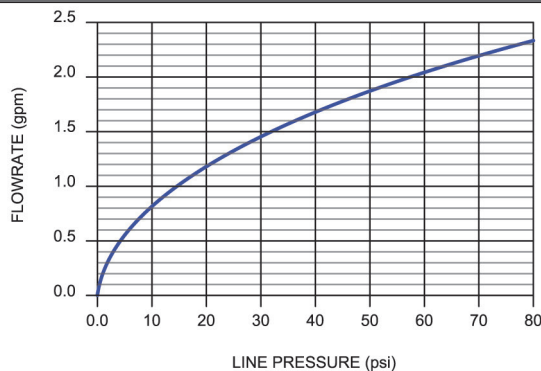

NEOPERL, Inc., Waterbury, CT • Tel: 203-756-8437 • Fax: 203-574-2107 • www.neoperl.com

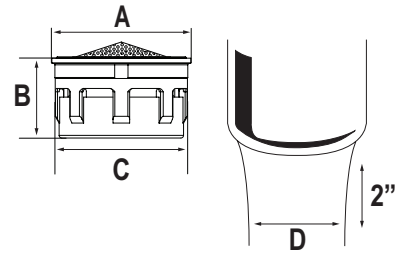

Dimensions

No	mm	In
A	20.88	.822
B	12.00	.472
C	19.97	.786
D	≈ 13	≈ 1/2

Housings



Technical Data

Materials: Body Washer Acetal
EPDM

Continuous

Short-term (5 minutes max.)
Per ASME A112.18.1 testing requirements.

