

Surge and Isolated Ground Devices



Isolated Ground Straight Blade Receptacles



- Limits electrical noise on the equipment grounding circuit by providing two grounding paths for the installation
- Nylon deep face design
- Triple-wipe brass line contacts
- Ground contacts and ground termination
- Nickel and brass plated wrap-around steel yoke

Pre-Marked Wallplates




Opening	Color	"Isolated Ground"	"Computer Only"
Duplex	Orange	NP80IG	NPJ8CO
Duplex	Ivory	—	NPJ8C
Single receptacle	Orange	NP70IG	—
Decorator type	Orange	NP260IG	—
Decorator type	Ivory	—	NPJ26C

Extra Heavy Duty Industrial, Hospital Grade and Specification Grade Receptacles



		Extra Heavy Duty					Specification Grade			
Face		Nylon Face					Nylon			
Wiring		Back and Side					Back and Side			
Style		Duplex		Decorator		Single		Terminal Screws Wire Leads		
Rating	Color	Hospital Grade	Industrial Grade	Hospital Grade	Hospital Grade	Industrial Grade	Commercial Grade	QUADPLEX®		
NEMA 5-15, 15A 125V	Gray Ivory Orange Red White	— — BRY8200IG — —	BRY5262IGGRY BRY5262IGI BRY5262IG — BRY5262IGW	9200IGGRY 9200IGI 9200IG 9200IGRED 9200IGW	— — 8210IG — —	5261IGGRY 5261IGI 5261IG — 5261IGW	CR15IGRY CR15IGI CR15IG — CR15IGW	— — 1254IGO — —	— — — — —	— — — — —
NEMA 5-20, 20A 125V	Gray Ivory Lt. Almond Orange Red White	— — — BRY8300IG — —	BRY5362IGGRY BRY5362IGI — BRY5362IG — BRY5362IGW	9300IGGRY 9300IGI — 9300IG 9300IGRED 9300IGW	— — — 8310IG — —	5361IGGRY 5361IGI — 5361IG — 5361IGW	CR20IGRY CR20IGI CR20IGLA CR20IG — CR20IGW	— — — 21254IGO — —	— — — — — —	— — — 21254IGOL — —
NEMA 6-15, 15A 250V	Orange	—	BRY5662IG	—	—	—	—	—	—	—
NEMA 6-20, 20A 250V	Orange	—	BRY5462IG	—	—	8410IG	—	—	—	—

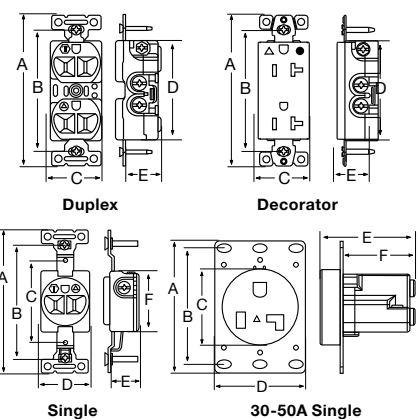

30 and 50 Amp Straight Blade Receptacles

Rating	Color	RTP Nylon Face, 2-Pole 3-Wire	
NEMA 5-30, 30A 125V	Orange	9530IG	NEMA 6-30, 30A 250V 9630IG
NEMA 5-50, 50A 125V	Orange	9550IG	NEMA 6-50, 50A 250V 9650IG



Product Dimensions Inches (mm)

	Duplex	Decorator	Single 15/20A	30-50A
A	4.06" (103.1)	3.81" (96.8)	4.06" (103.1)	3.68" (93.5)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)	2.37" (60.3)
C	1.38" (35.1)	1.38" (35.1)	2.38" (60.5)	2.12" (54.0)
D	2.68" (68.1)	2.69" (68.3)	1.38" (35.1)	2.25" (57.2)
E	0.92" (23.4)	0.93" (23.6)	1.78" (45.2)	2.35" (59.9)
F	—	—	0.91" (23.1)	1.79" (45.6)

Lexan® is a registered trademark of Sabic Innovative Plastics.