



AC1387

DELUXE A/C Line Repair Kit

COVERS
100s
OF VEHICLES




Make Instant Repairs To A/C Lines On Hundreds Of Vehicles

AC1387 Advantages:


- Repair damaged rubber and aluminum lines including pinholes, cracks, kinks and more
- On-the-car repairs made simple
- Make connections easily by hand; no specialty tools required
- Covers common line sizes including 3/8", 1/2", 5/8", & 3/4"
- Compression unions and line adapters designed specifically for A/C repair applications
- Conforms to SAE J2064 specifications for low permeability
- Pressure rated up to 600 PSI

Fast, Long-Lasting A/C Repairs for High and Low Sides

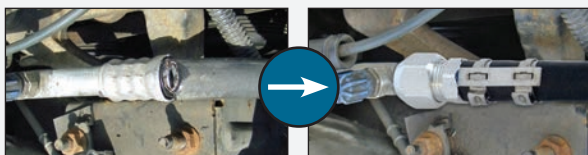

PROBLEM: Damaged A/C hose leaking at connection

PROBLEM SOLVED: With hose to compression union adapter

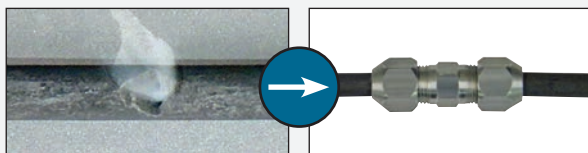

PROBLEM: Damaged A/C aluminum line

PROBLEM SOLVED: With compression union

47 Pieces Plus 20' Hose

Simple To Assemble

Repair lines in minutes. It's as simple as 1,2,3!



1 Place clamps into clamp holder; insert onto hose

2 Push adapter into hose; crimp clamps with clamp pliers

3 Tighten compression union onto aluminum line

1.800.390.3996 • phone: 330.745.3300 • fax: 330.745.3488 • www.surrauto.com

AC1387 KIT CONTENTS



Bold items included in **AC1387 Kit** | *Italic items are available to order.*

Compression Unions

IMAGE	PART#	DESCRIPTION	QTY
	AC516	<i>5/16" A/C Compression Union</i>	—
	AC38	3/8" A/C Compression Union	1
	AC12	1/2" A/C Compression Union	1
	AC58	5/8" A/C Compression Union	1
	AC34	3/4" A/C Compression Union	1
METRIC			
	AC8M	<i>8 mm A/C Compression Union</i>	—
	AC10M	<i>10 mm A/C Compression Union</i>	—
	AC12M	<i>12 mm A/C Compression Union</i>	—
	AC15M	<i>15 mm A/C Compression Union</i>	—
	AC16M	<i>16 mm A/C Compression Union</i>	—
	AC19M	<i>19 mm A/C Compression Union</i>	—

Compression Block Offs

IMAGE	PART#	DESCRIPTION	QTY
	AC516CB	<i>5/16" A/C Compression Block Off</i>	—
	AC38CB	<i>3/8" A/C Compression Block Off</i>	—
	AC12CB	<i>1/2" A/C Compression Block Off</i>	—
	AC58CB	<i>5/8" A/C Compression Block Off</i>	—
	AC34CB	<i>3/4" A/C Compression Block Off</i>	—
METRIC			
	AC8MCB	<i>8 mm A/C Compression Block Off</i>	—
	AC10MCB	<i>10 mm A/C Compression Block Off</i>	—
	AC12MCB	<i>12 mm A/C Compression Block Off</i>	—
	AC15MCB	<i>15 mm A/C Compression Block Off</i>	—
	AC16MCB	<i>16 mm A/C Compression Block Off</i>	—
	AC19MCB	<i>19 mm A/C Compression Block Off</i>	—

Hose To Compression Union Adapters

Straight

IMAGE	PART#	DESCRIPTION	QTY
	AC16516	<i>#6 Hose To 5/16" Compression Union</i>	—
	AC1638	#6 Hose To 3/8" Compression Union Adapter	1
	AC1812	#8 Hose To 1/2" Compression Union Adapter	1
	AC11058	#10 Hose To 5/8" Compression Union Adapter	1
	AC11234	#12 Hose To 3/4" Compression Union Adapter	1
METRIC			
	AC168M	<i>#6 Hose to 8 mm Compression Union</i>	—
	AC1610M	<i>#6 Hose to 10 mm Compression Union</i>	—
	AC1812M	<i>#8 Hose to 12 mm Compression Union</i>	—
	AC11015M	<i>#10 Hose to 15 mm Compression Union Adapter</i>	—
	AC11016M	<i>#10 Hose to 16 mm Compression Union Adapter</i>	—
	AC11219M	<i>#12 Hose to 19 mm Compression Union Adapter</i>	—

90°

IMAGE	PART#	DESCRIPTION	QTY
	AC26516	<i>#6 Hose to 90° 5/16" Compression Union Adapter</i>	—
	AC2638	#6 Hose to 90° 3/8" Compression Union	1
	AC2812	#8 Hose to 90° 1/2" Compression Union	1
	AC21058	#10 Hose to 90° 5/8" Compression Union	1
	AC21234	#12 Hose to 90° 3/4" Compression Union	1

Line Reducers

IMAGE	PART#	DESCRIPTION	QTY
	AC1612	<i>#6 Hose to 1/2" Compression Union</i>	—
	AC1858	<i>#8 Hose to 5/8" Compression Union</i>	—
	AC11034	<i>#10 Hose to 3/4" Compression Union</i>	—

In Line Service Ports

IMAGE	PART#	DESCRIPTION	QTY
	AC412L	<i>1/2" Service Port Valve – Low Side</i>	—
	AC458L	<i>5/8" Service Port Valve – Low Side</i>	—
	AC438H	<i>3/8" Service Port Valve – High Side</i>	—
	AC412H	<i>1/2" Service Port Valve – High Side</i>	—

Hose, Clamps, Splicers & Tools

Hose

IMAGE	PART#	DESCRIPTION	QTY
	AC6H	#6 A/C Hose – 5/16" (8 mm [printed on hose])	5'
	AC6H25	<i>#6 A/C Hose – 5/16" (8 mm [printed on hose])</i>	25'
	AC8H	#8 A/C Hose – 13/32" (10 mm [printed on hose])	5'
	AC8H25	<i>#8 A/C Hose – 13/32" (10 mm [printed on hose])</i>	25'
	AC10H	#10 AC/Hose – 1/2" (13 mm [printed on hose])	5'
	AC10H25	<i>#10 AC/Hose – 1/2" (13 mm [printed on hose])</i>	25'
	AC12H	#12 A/C Hose – 5/8" (16 mm [printed on hose])	5'
	AC12H25	<i>#12 A/C Hose – 5/8" (16 mm [printed on hose])</i>	25'

Clamp Sets

IMAGE	PART#	DESCRIPTION	QTY
	AC6806	#6 Clamp Set – Blue Tab	5
	AC6808	#8 Clamp Set – Yellow Tab	5
	AC6810	#10 Clamp Set – Green Tab	5
	AC6812	#12 Clamp Set – Red Tab	5

Hose Splicers

IMAGE	PART#	DESCRIPTION	QTY
	AC370606	<i>#6 Hose to #6 Hose In Line Splicer</i>	1
	AC370808	<i>#8 Hose to #8 Hose In Line Splicer</i>	1
	AC371010	<i>#10 Hose to #10 Hose In Line Splicer</i>	1
	AC371212	<i>#12 Hose to #12 Hose In Line Splicer</i>	1

Tools

IMAGE	PART#	DESCRIPTION	QTY
	CP360	360° Seal Clamp Pliers <i>Up to 1" O.D.</i>	1
	TC35	Tube & Hose Cutter <i>Up to 1 1/4" O.D.</i>	1

1.800.390.3996 • phone: 330.745.3300 • fax: 330.745.3488 • www.surrauto.com