



TR555

DELUXE Transmission Oil Cooler Line Repair Kit

NEW &
IMPROVED



Replace Or Repair Transmission Oil Cooler Lines For Virtually Any Vehicle Within Minutes

- Use to replace or make repairs on both 5/16" & 3/8" lines
- Convenient, all-in-one kit pays for itself in as little as one job
- Immediate Part Availability, Easier to Install Than OE Lines
- Hundreds of domestic and foreign applications
- Perfect for damaged lines including rust, cracks, pinholes, and more
- Triple-walled rubber hose safe and durable; pressure rated up to 250 PSI/temperatures up to 350° F

New Technology: Featuring OEM High-Temp Rubber Hose

80 Pieces Plus
15' Hose


Make A New Line Or Repair A Leak In As Little As 5 Minutes



PROBLEM: Leaking
transmission line connector

PROBLEM SOLVED:
With quick connect and
new transmission hose

Easy Assembly

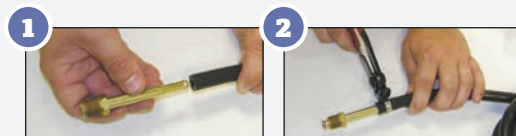

1
Push on rubber
hose to fitting

2
Crimp clamp


1.800.390.3996 • phone: 330.745.3300 • fax: 330.745.3488 • www.surrauto.com

TR555 KIT CONTENTS






NEW & IMPROVED

All items included in **TR555 Kit**





Rubber Hose

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	TR516H	5/16" / 3/8"	5/16" Transmission Rubber Hose Universal (use for both 5/16" and 3/8" repairs)	25' Roll


Line Connectors

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	TR750	3/8"	Dodge/Jeep Transmission Line	1
	TR755	3/8"	Ford Transmission Line	1
	TR760	3/8"	GM Transmission Line	1
	TR765	3/8"	GM Transmission Line	1
	TR770	3/8"	GM Transmission Line	1

Line Nuts

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	TR605	3/8"	3/8" Inverted Flare Nut 5/8" - 18 (use with TR985 & TR990)	4
	TR610	3/8"	3/8" Bubble Flare Nut M16 x 1.5 (use with TR985 & TR990)	4
	TR615	3/8"	3/8" Bubble Flare Nut M18 x 1.5 (use with TR985 & TR990)	4
	TR620	3/8"	3/8" Inverted Flare Nut (5/8"-18 w/dog ear) (use with TR985 & TR990)	2






Universal Quick Connect

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	TR720	3/8"	3/8" Straight Push Quick Connect to Rubber	1

Line Adapters

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	TR405	5/16"	5/16" Steel Compression to 5/16" Rubber	1
	TR410	3/8"	3/8" Steel Compression to 5/16" Rubber	1
	TR935	5/16"	5/16" Inverted Flare with 5/8" - 18 Nut to Rubber	2
	TR940	5/16"	5/16" GM O-Ring with 1/2" - 20 Nut to Rubber	2
	TR945	5/16"	5/16" Inverted Flare with 1/2" - 20 Nut to Rubber	2
	TR950	5/16"	5/16" Rubber to Rubber Connector	1
	TR955	5/16"	5/16" Quick Connect to Rubber	1
	TR960	3/8"	3/8" & 5/16" Rubber to Rubber Connector	1
	TR965	3/8"	3/8" Quick Connect to Rubber	1
	TR970	3/8"	3/8" GM 45° Male to Rubber	1
	TR975	3/8"	3/8" GM 90° Male to Rubber	1
	TR980	3/8"	3/8" GM Straight Male to Rubber	2
	TR985	3/8"	3/8" Inverted Flare to Rubber (use with TR605, TR610, TR615 & TR620)	2
	TR990	3/8"	3/8" GM O-Ring to Rubber (use with TR605, TR610, TR615 & TR620)	2

Tools & Accessories

IMAGE	PART#	LINE SIZE	DESCRIPTION	QTY
	CL12	1/2"	1/2" Hanger Clamp (includes screw) (use with TR516H 5/16" Rubber Hose)	10
	CP360	Up to 1" O.D.	360° Seal Clamp Pliers	1
	TC35	Up to 1-1/4" O.D.	Tube and Hose Cutter	1
	K6806	9/16"	9/16" Seal Clamp (use with TR516H 5/16" Rubber Hose)	21
	TR775	3/8"	3/8" Transmission Connector Clip	5

1.800.390.3996 • phone: 330.745.3300 • fax: 330.745.3488 • www.surrauto.com