

TUBE CLAMPS & DOOR STOPS/LATCHES




Magnetic Tube Clamps

Powerful magnetic clamp securely holds water lines, cables, electrical conduit, etc. to steel walls, beams or structures. They eliminate the need to drill mounting holes, making installation or future repositioning fast and easy!

- Powerful Permanent magnets
- No holes to drill
- Closes and locks automatically when pipe, tube or cable is inserted
- Reusable one-piece clamps




Hold - lbs (kg)	Magnet	Clamp Size (in)	Width (in)	Magnet Dia. (in)	OAH (in)	Wt. (lbs)	Model No.
7.0 (3.18)	Ceramic	3/8	-	1.24	1.37	0.05	MX1000T037
7.0 (3.18)	Ceramic	1/2	-	1.24	1.50	0.05	MX1000T050
11.0 (4.99)	Ceramic	3/4	-	1.41	2.00	0.10	MX1500T075
42.5 (19.28)	Rare Earth	3/4	-	1.41	2.00	0.10	MX1500RT075
19.0 (8.62)	Ceramic	1	-	2.03	2.25	0.20	MX2000T100
47.5 (21.55)	Rare Earth	1	-	2.03	2.25	0.20	MX2002RT100
OVL (in)							
43.5 (19.73)	Rare Earth	3/4	1.37	3.50	2.12	0.21	LP2100R2T075
43.5 (19.73)	Rare Earth	1	1.37	3.62	2.37	0.22	LP2100R2T100

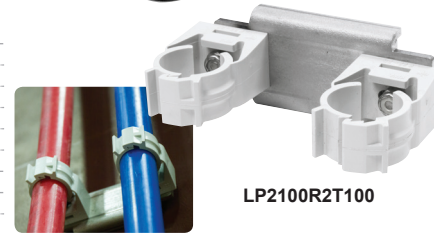

Magnetic Door Latches

These extremely powerful Rare Earth magnetic latches have a very thin profile. Ideal for door & cabinet applications or for mounting panels, signs, pictures, etc. Plated magnet, washers and screws reduce corrosion. Washers are recessed to allow the screw head to set below the contact area.

- Rare Earth Neodymium Permanent Magnet
- ML050 uses 3M VHB Adhesive on the magnet
- Screw(s) included are #6 x 5/8" long

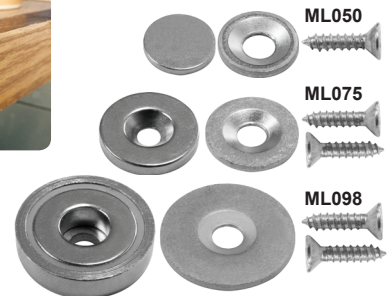

Style	Hold - lbs (kg)	Magnet			Strike Plate			Wt. - lbs	Model No.
		OD (in.)	TH (in.)	Hole Dia. (in.)	OD (in.)	TH (in.)	Hole Dia. (in.)		
A	2 (0.91)	0.50	0.06	N/A	0.56	.070	.221	0.0001	ML050
B	13 (5.90)	0.75	0.12	0.18	0.70	.070	.221	0.01	ML075
C	37 (16.78)	0.98	0.31	0.21	1.00	.070	.221	0.05	ML098

Magnetic Connectors

These Powerful Rare Earth magnetic connection systems hold doors, cabinets, key rings, knives, tools in indoor or outdoor applications. Ideal for home, office, garage, RV or marine setting. Permanent Rare Earth magnets embedded inside Non-Marring housing.

- Permanent Rare Earth Magnets
- ABS plastic housing
- 3M adhesive backing
- Available in Black or White



Max Hold (lbs)	(kg)	Description	Flange Dia. (in)	Magnet Dia. (in)	Projects (in)	Wt. (lbs)	Magnet Color	Model No.
Magnetic Connector Models (Black or White)								
5.5	2.49	2 Magnets	1-1/2	3/4	1-1/8	0.05	Black	D1BL
5.5	2.49	2 Magnets	1-1/2	3/4	1-1/8	0.05	White	D1WH

Magnetic Door Holders/Stops

These powerful Rare Earth magnetic connection systems can be used to hold doors & cabinets. Ideal for home, office, garage, RV or marine settings, these permanent Rare Earth magnets are embedded inside a non-Marring housing and come with several different mounting options, including adhesive, screws or rivets.

- Permanent Rare Earth Magnet(s)
- Non-Marring EPDM* rubber housing
- Powder coated steel floor bracket (Floor Model Only)
- 8 mounting holes provided
- Mounting screws included
- Optional mounting methods, rivets or adhesive



Max Hold (lbs)	(kg)	Description	Flange Dia. (in)	Magnet Dia. (in)	Projects (in)	Wt. (lbs)	Magnet Color	Model No.
Floor Mount Model								
27	12.25	1 Magnet, 1 Plate, 1 Bracket, Hardware	3-1/2	1-3/8	2-3/4	2.20	Orange	D3X1BKT
31	14.06	2 Magnets, 1 Plate, 1 Bracket, Hardware	3-1/2	1-3/8	2-3/4	2.45	Orange/Black	D3X2BKT

Note: Models with 2 magnets project farther than most door knobs

Max Hold (lbs)	(kg)	Description	Flange Dia. (in)	Magnet Dia. (in)	Projects (in)	Wt. (lbs)	Magnet Color	Model No.
Trailer Mount Model								
27	12.25	1 Magnet, 1 Hardware	3-1/2	1-3/8	1-3/8	0.45	Black	D3X1BL
27	12.25	1 Magnet, 1 Plate, Hardware	3-1/2	1-3/8	1-3/8	0.65	Black	D3X1BLP
31	14.06	2 Magnets, Hardware	3-1/2	1-3/8	2-3/4	0.90	Black	D3X2BL

Note: Models with 2 magnets project farther than most door knobs

*EPDM = Ethylene Propylene Diene Monomer (Type of Synthetic Rubber)