



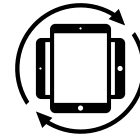

PAD-CGS

Compact Gooseneck Floor Stand for 7-13 inch Tablets

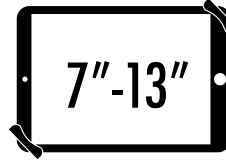

Easily adjusts for horizontal or vertical views

Compact Gooseneck Floor Stand

Create a mobile, adjustable workstation for your tablet with CTA Digital's Compact Gooseneck Floor Stand for 7-13 Inch Tablets. This stand is without equal in adjustability, featuring a powerful, flexible gooseneck and a tilting headpiece with easy 360-degree rotation. Customize your workstation further, with the stand's height-adjusting, telescoping pole and attachable storage cradle, perfect for an external battery pack or a stack of business cards. The included swivel casters attach effortlessly to the stand base, giving your stand easy mobility in your home, office, living room, classroom, or retail space. The quick-adjusting tablet holder slides open and secures your 7-13 inch tablet by the corners, leaving ports and buttons fully accessible.

Features:

- Flexible, sturdy gooseneck adjusts to any position
- Jointed tablet holder tilts side to side and rotates 360 degrees for landscape and portrait viewing
- Telescoping pole allows easy height adjustment
- Attachable battery-pack cradle
- Stable, weighted metal base
- Durable, easy-rolling swivel casters
- Compatible with 7-13 inch tablets, including iPad mini, iPad Air, iPad Pro 12.9, and Surface Pro 4

Specifications:


- Pole adjustment range: 22 – 38 inches
 - Maximum stand height: 58 inches
 - Gooseneck length: 12 inches
 - Base dimensions: 17.5" x 17.5"
- Tablet holder range: 8.625 – 15.5 inches
- Storage cradle dimensions: 3.5" x 3" x 1"
 - Weight: 10.39 lbs.

Package Includes:

- | | |
|-----------------------------------|-------------------------------|
| (1) Stand base | (1) Tablet holder |
| (1) Telescoping pole | (4) Swivel casters |
| (1) Multi-function storage cradle | (1) Set of tools and hardware |
| (1) Gooseneck | |



Adjustable Holder

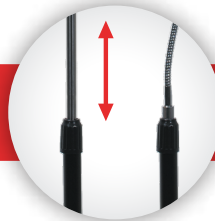

Telescoping Pole



Swivel Casters



Battery Pack Holder

	Quantity	Width	Height	Depth	Weight	UPC Barcode
Packaging	1	6	3.7	24	12	656777014278
Master	4	12.7	8	24.5	49	10656777014275