


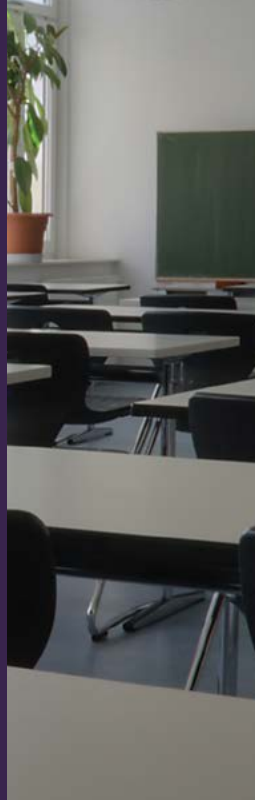

LJT
LED Troffer

LAW
LED Wraparound

LCS
LED Open Striplight



Three LED products that have it all.

- Simple fluorescent replacement
- Readily available in stock
- Affordably priced
- Rebate friendly
- Long-life 60,000 hour LED at L80 lumen maintenance for reduced maintenance on site
- User friendly with access to LED boards and drivers from below
- Modular replacement of components
- Choice of LED color temperature
- Familiar shapes, sizes, and appearances for simplicity of use
- Controls compatible
- Integral battery pack option (1,400 lumens)

LED luminaires

LJT LED Troffer

- Replaces 1, 2, 3 and 4-lamp fluorescent troffers
- Up to 115 lumens per watt
- 1x4 Lumens: 2,255 up to 7,170
- 2x2 Lumens: 1,380 up to 4,715
- 2x4 Lumens: 2,560 up to 9,760
- 3000K, 3500K, 4000K, 5000K
- Recessed, surface, or cable
- All models standard with IC rating
- DesignLights Consortium® (DLC) qualified with many configurations qualifying for DLC Premium; see www.designlights.org



LAW LED Wraparound

- Replaces 1-lamp and 2-lamp fluorescent wraps
- Up to 109 lumens per watt
- 2' and 4'
- 2' lumens: from 2,600 up to 4,300
- 4' lumens: from 2,500 up to 5,600
- 3000K, 3500K, 4000K, 5000K
- Surface mount or suspended
- DesignLights Consortium® (DLC) qualified; see www.designlights.org



LCS LED Striplight

- Replaces 1, 2, 3, 4, or 6-lamp fluorescent strips
- Up to 124 lumens per watt
- 2', 4' and 8'
- 2' Lumens: 3,000
- 4' Lumens: from 2,800 up to 11,200
- 8' lumens: from 5,600 up to 22,400
- 3000K, 3500K, 4000K, 5000K
- Surface mount or suspended
- Wire guard option
- DesignLights Consortium® (DLC) qualified; see www.designlights.org



LJT ORDERING INFORMATION

LJT										U			
MODEL	COLOR TEMP	CEILING TYPE	SHIELDING				VOLTAGE	OPTIONS					
LJT LED Lensed Troffer	30 3000K 35 3500K 40 4000K 50 5000K	G Grid ¹ SM Surface Mount CM Cable Mount ²	A12 Pattern 12 Acrylic Lens A12125 Pattern 12 Acrylic Lens, 0.125" Nominal A12F Pattern 12 Frosted Acrylic Lens A12125F Pattern 12 Frosted Acrylic Lens, 0.125" Nominal A19 Pattern 19 Acrylic Lens, 0.156" Nominal A19F Pattern 19 Frosted Acrylic Lens .156"				U 120V-277V	C388 3-Wire Flex C488 4-Wire Flex C588 5-Wire Flex ELL14 Emergency Battery Pack, 1400 Lumens, Installed ^{5,6} GLR Fast Blow Fuse G1 Single Gasketing (Door to Housing) G2 Double Gasketing (G1 and Lens to Door) G3 Triple Gasketing (G2 and Housing to Ceiling) EOR End of Row (SM/CM only) ⁷ INT Intermediate (SM/CM only) ⁷ GTD Generator Transfer Device CP Chicago Plenum					
SIZE	LUMEN OUTPUT		PRODUCT AVAILABILITY — NOMINAL LUMENS					PRODUCT AVAILABILITY — NOMINAL LUMENS					
14 1' x 4' 22 2' x 2' 24 2' x 4'	XW Extra Low Watt (1x4, 2x4) VW Very Low Watt MW Medium low Watt LW Low Watt ML Medium Lumen HL High Lumen VL Very High Lumen XL Extra High Lumen (2x4 only)		SIZE	LUMEN PACKAGE	LUMENS	WATTS	LPW	SIZE	LUMEN PACKAGE	LUMENS	WATTS	LPW	
			14	XW	2255-2526	20	111-127	24	XW	2560-2915	20	127-145	
				VW	2835-3230	27	106-121		VW	3340-3805	27	125-142	
				MW	3330-3795	31	109-124		MW	3770-4295	31	123-140	
				LW	3655-4160	34	107-122		LW	4140-4720	34	122-139	
				ML	4035-4595	38	106-120		ML	4580-5215	38	119-136	
				HL	4620-5260	45	102-117		HL	5285-6015	45	117-133	
				VL	6300-7170	59	107-122		VL	7190	59	121-138	
			22	VW	1380-1570	13	105-120		XL	850-9760	73	117-134	
				MW	1870-2130	18	103-117	Based on A12 lens, range represents 3000K through 5000K. Lumens vary according to color temperatures and other factors. See specific photometric test(s).					
				LW	2400-2740	24	102-116						
				ML	3265-3720	31	104-119						
				HL	3575-4070	33	109-125						
				VL	4140-4715	42	100-113						

See Product Availability table below.

ACCESSORIES (ORDER SEPARATELY)	
FK14	1' x 2' Single Flange Kit4
FK22	2' x 2' Single Flange Kit
FK24	2' x 4' Single Flange Kit
FKCR	Flange Kit Row Adaptor (All Sizes)
CM48Y2SC3F-KIT	48" Cable Mount Kit for 2' Wide CM Ceiling Type, 3 Wire Feed Cord
CM48Y1SC3F-KIT	48" Cable Mount Kit for 1' Wide Cable Mount Fixtures, 3 Wire Feed Cord

DOOR	
FS	White Flush Steel
FA	White Flush Aluminum

For more door options contact factory.

- ¹ For drywall, order G with Flange Kit Accessory.
 - ² Order hanger accessories separately.
 - ³ Not available with 2x4 XL Lumen output.
 - ⁴ 50 watt and below.
 - ⁵ For compatibility with Dual-Lite LiteGear® inverters in lieu of EL Battery Pack, contact Hubbell Lighting Representative.
 - ⁶ Not available with 2x2 Surface or Cable Mount.
 - ⁷ Provides ends with wiring access for continuous row mounting.
- Damp Label - standard. IC Rating - standard.

LAW								U			
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DRIVER	VOLTAGE	OPTIONS					
LED Wraparound	2 2' 4 4'	30 3000K 35 3500K 40 4000K 50 5000K	LW Low Watt ML Medium Lumen HL High Lumen	E Fixed Output ESD Step Dimming ED 0-10V Dimming	U 120V-277V	ELL14 Emergency Battery Pack Installed, 1400 Lumens ^{1,2} GLR Fast Blow Fuse PAF Paint After Fabrication NYC NYC Compliant					
ACCESSORIES (ORDER SEPARATELY)											
S18	18" Stem, Canopy	¹ For compatibility with Dual-Lite LiteGear® inverters in lieu of installed Battery Pack, contact Hubbell Lighting Representative.									
SS18	18" Swivel Stem—45° Swivel	² Only available in 4 ft.									

LCS								U			
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DRIVER	VOLTAGE	OPTIONS					
LCS LED Striplight	2 2' 4 4' 8 8'	30 3000K 35 3500K 40 4000K 50 5000K	LW Low Watt ML Medium Lumen HL High Lumen VL Very High Lumen	E Fixed Output ESD Step Dimming ED 0-10V Dimming ED1 0-10V 1% Dimming	U 120V-277V 347 347 (E, ED, ED1 only)	ELL14 Emergency Battery Pack, 1400 Lumens ^{1,2,3} GLR Fast Blow Fuse PAF Paint After Fabrication NYC NYC Compliant					
ACCESSORIES (ORDER SEPARATELY)											
CSWG4	4' Wire Guard										
S18	18" Stem, Canopy										
SS18	18" Swivel Stem—45° Swivel										
CSHC	Chain Hanger Assembly										
		¹ Not available in 2' size. ² For compatibility with Dual-Lite LiteGear® inverters in lieu of installed Battery Pack, contact Hubbell Lighting Representative. ³ Not available in VL packages									