

**FEATURES**

- LED Wraparound
- Long life 50,000 hour LEDs at L80 for reduced maintenance
- DesignLights Consortium® (DLC) qualified
- Four LED color choices and 80 CRI
- 4' Size offers three lumen packages
- 2' Size offers two lumen packages
- Optional integral emergency battery pack
- Heavy gauge steel housing, die embossed for maximum rigidity
- White steel end plates
- Diffuser features flat bottom and vertical sides
- Interior overlay for smooth appearance without pixelation
- Hinges from either side
- LED boards and driver accessible for future maintenance or upgrades
- Modular replaceability of LED components
- Surface mount or stem suspended
- Five Year Warranty

**PROJECT INFORMATION**

Project Name \_\_\_\_\_

Type \_\_\_\_\_

Catalog No. \_\_\_\_\_

Date \_\_\_\_\_

**CONSTRUCTION**

Housing, end plates, and wireway are formed from code-gauge steel.

**SHIELDING**

100% acrylic prismatic with interior overlay for smooth appearance without pixelation.

**FINISH**

White painted parts are treated with a five-stage phosphate bonding process and finished with high reflectance baked enamel. For a post-painted housing finish select PAF option.

**ELECTRICAL**

Long-life LEDs are rated for 50,000 hours at L80 lumen maintenance. Driver options include fixed output for on/off function, step dimming (high/low/off), or continuous 0-10V dimming.

**CERTIFICATION**

All luminaires are built to UL 1598 and 2108 standards, and bear appropriate CSA labels. Damp location labeling is standard. Emergency equipped fixtures labeled UL924. Adheres to LM79, LM80, and TM21 industry standards. DesignLights Consortium® (DLC) qualified. Please refer to the DLC website for specific product qualifications at [www.designlights.org](http://www.designlights.org).

**WARRANTY**

Five year warranty (Terms and Conditions apply).

**ORDERING INFORMATION**

**EXAMPLE LAW4-35ML-EU**

LAW		-		-		U		-	
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DRIVER	VOLTAGE	OPTIONS			
LAW LED Wraparound	2 2' 4 4'	30 3000K 35 3500K 40 4000K 50 5000K	LW Low Watt ML Medium Lumen HL High Lumen	E Fixed Output ESD Step Dimming ED 0-10V Dimming ED1 0-10V 1% Dimming LUTH Lutron H Series LUTS Lutron S Series	U 120V-277V 347 347V (E,ED,ED1 only)	ELL14 Emergency Battery Pack Installed, 1400 Lumens <sup>1,2</sup> GLR Fast Blow Fuse PAF Paint After Fabrication NYC NYC Compliant			

**ACCESSORIES (ORDER SEPARATELY)**

S18	18" Stem, Canopy
SS18	18" Swivel Stem - 45° Swivel

**PRODUCT AVAILABILITY**

SIZE	OUTPUT	NOMINAL LUMENS (3500K)	NOMINAL WATTS	EFFICACY
2'	LW	2600	25	105
	ML	4300	49	88
4'	LW	2500	23	109
	ML	4700	48	98
	HL	5600	55	102

Actual lumens will vary according to color temperature and other factors. For exact lumens and watts see specific photometric test(s).

<sup>1</sup> For compatibility with Dual-Lite LiteGear® inverters in lieu of installed battery pack, contact Hubbell Lighting representative.

<sup>2</sup> Only available in 4 ft.

**PHOTOMETRIC DATA**

Test 9114 Test Date 6/6/14

**LUMINAIRE DATA**

Luminaire	LAW2-40LW-EU LAW LED Low Profile Wraparound, Wraps 8" x 24" LED with acrylic prisms wraparound lens and frosted overlay
Ballast	D15CC55UNVTC
Ballast Factor	1.00
Lamp	LED
Fixture Lumens	2647
Watts	25.20
Mounting	Surface
Shielding Angle	0° = 90 90° = 90
Spacing Criterion	0° = 1.22 90° = 1.13
Luminous Opening in Feet	Length: 2.00 Width: 0.67 Height: 0.13


**ZONAL LUMEN SUMMARY**

Zone	Lumens	Lamp	Fixt.
0-30	930	35.1	35.1
0-40	1456	55.0	55.0
0-60	2168	81.9	81.9
0-90	2521	95.2	95.2
0-180	2647	100.0	100.0

**ENERGY DATA**

Total Luminaire Efficiency	100.0
Total Lumens per Watt	105
ANSI/IESNA RP-1-2004 Compliance	Noncompliant
Comparative Yearly Lighting Energy Cost per 1000 Lumens	\$2.26 based on 3000 hrs. and \$0.08 per KWH

**INDOOR CANDELA PLOT**

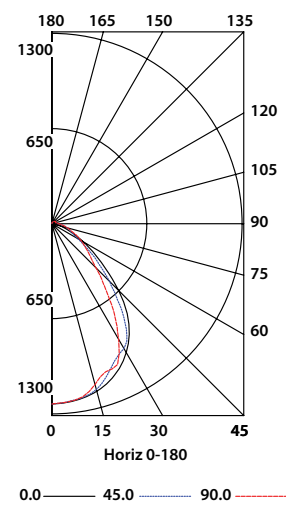

**LUMINAIRE DATA**

Test 15387 Test Date 7/18/14

Luminaire	LAW4-40ML-EU LAW LED Low Profile Wraparound, Wraps 8" x 48" LED with acrylic prisms wraparound lens and frosted overlay
Ballast	D15CC55UNVTC
Ballast Factor	1.00
Lamp	LED
Fixture Lumens	4714
Watts	47.60
Mounting	Surface
Shielding Angle	0° = 90 90° = 90
Spacing Criterion	0° = 1.23 90° = 1.09
Luminous Opening in Feet	Length: 4.00 Width: 0.67 Height: 0.12


**ZONAL LUMEN SUMMARY**

Zone	Lumens	Lamp	Fixt.
0-30	1558	33.1	33.1
0-40	2437	51.7	51.7
0-60	3744	79.4	79.4
0-90	4425	93.9	93.9
0-180	4714	100.0	100.0

**ENERGY DATA**

Total Luminaire Efficiency	100.0
Total Lumens per Watt	99
ANSI/IESNA RP-1-2004 Compliance	Noncompliant
Comparative Yearly Lighting Energy Cost per 1000 Lumens	\$2.45 based on 3000 hrs. and \$0.08 per KWH

**INDOOR CANDELA PLOT**

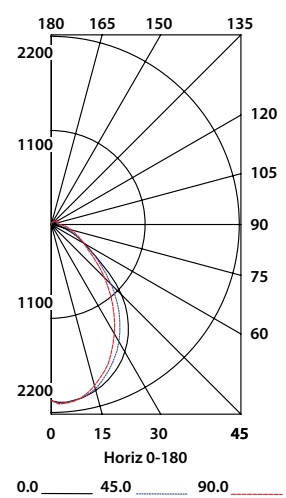

**LUMINAIRE DATA**

Test 15386 Test Date 7/21/14

Luminaire	LAW4-40HL-EU LAW LED Low Profile Wraparound, Wraps 8" x 48" LED with acrylic prisms wraparound lens and frosted overlay
Ballast	D15CC55UNVTC
Ballast Factor	1.00
Lamp	LED
Fixture Lumens	5602
Watts	54.80
Mounting	Surface
Shielding Angle	0° = 90 90° = 90
Spacing Criterion	0° = 1.24 90° = 1.09
Luminous Opening in Feet	Length: 0.67 Width: 4.00 Height: 0.13


**ZONAL LUMEN SUMMARY**

Zone	Lumens	Lamp	Fixt.
0-30	1837	32.8	32.8
0-40	2872	51.3	51.3
0-60	4415	78.8	78.8
0-90	5250	93.7	93.7
0-180	5602	100.0	100.0


**ENERGY DATA**

Total Luminaire Efficiency	100.0
Total Lumens per Watt	102
ANSI/IESNA RP-1-2004 Compliance	Noncompliant
Comparative Yearly Lighting Energy Cost per 1000 Lumens	\$2.35 based on 3000 hrs. and \$0.08 per KWH


**INDOOR CANDELA PLOT**

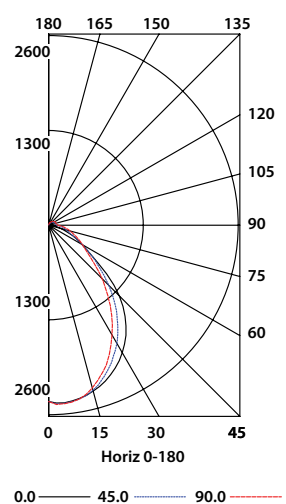

**DIMENSIONAL DATA**

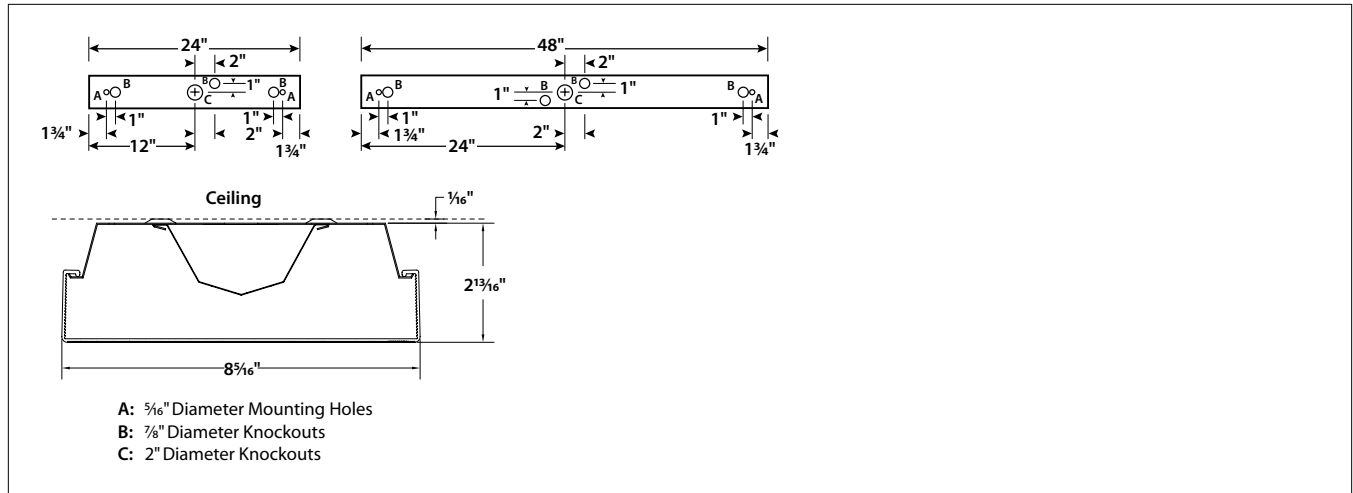

**STEM MOUNTING**

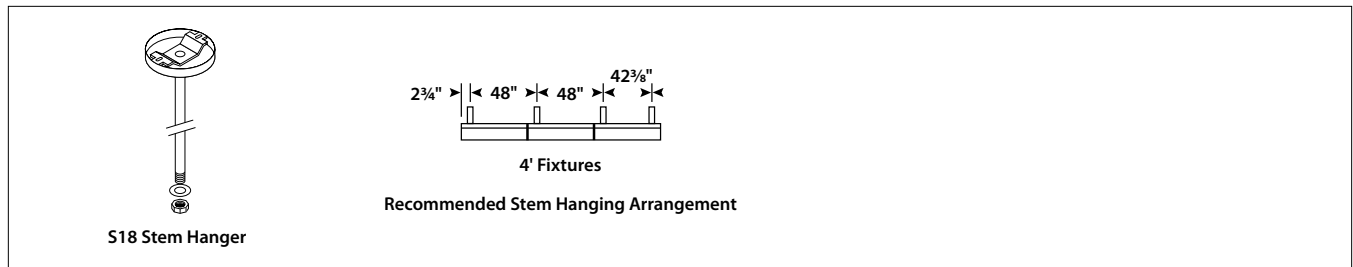

**NOTE:** All dimensions are in inches; dimensions and specifications are subject to change without notice. Please consult factory or check sample for verification.