


EXPOSED TEE SUSPENSION SYSTEMS ACCESSORIES

SUSPENSION SYSTEMS — Standard Accessories


2" Beam End Retaining Clip — Joins main beam or cross tee to wall molding and web of suspension system with no visible pop rivets.

- ALBERC2 (aluminum) — 200 pcs
- FZALBERC2 (aluminum) — 50 pcs
- BERC2 (steel) — 200 pcs
- FZBERC2 (steel) — 50 pcs

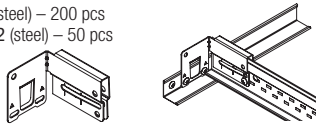


BERC — Beam End Retaining Clip — Joins web of main beam or cross tee to wall molding with no visible pop rivets.

- BERC — 200 pcs
- FZBERC — 50 pcs

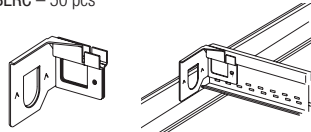


Seismic Joint Clip — Main Beam — Allows the ceiling to be divided at a splice on the main beam to accommodate the IBC mandate for ceiling areas greater than 2500 SF to have seismic separation joints. ES4 expansion sleeve is used to cover 3/4" gap.

 - SJMR15 for 15/16" — 100 pcs
- FZSJMR15 for 15/16" — 50 pcs
- SJMR9 for 9/16" — 100 pcs
- FZSJMR9 for 9/16" — 50 pcs




Seismic Joint Clip Cross Tee — Offers a tested seismic solution for separation joints in Seismic Category D, E, and F installations.

- SJCG (PeakForm®) — 200 pcs
- FZSJCG (PeakForm) — 50 pcs
- SJCSI (square bulbs) — 200 pcs
- FZSJCSI (square bulbs) — 50 pcs

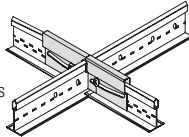


Expansion Sleeves

- ES4 — for 15/16" Prelude® — 100 pcs
- FZES4 — 50 pcs
- ES49 — for 9/16" Suprafine® — 100 pcs
- FZES49 — 50 pcs
- ES76004 — for 1/4" Silhouette® — 200 pcs
- FZES76004 — 50 pcs
- ES76008 — for 1/8" Silhouette — 200 pcs
- FZES76008 — 50 pcs

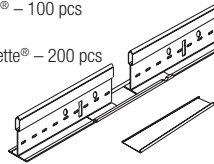

AXSJ-Axiom® Slip Joint — Used to join two acoustical ceiling systems on seismic D, E, F installations. Can also be used to join two different ceiling systems. Hanger wire holes every 6", beginning 3" from each end.

- AXSJ — 120" LFT

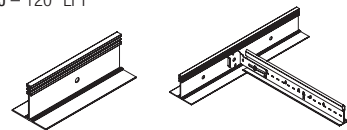


STAC — Single Tee Adapter Clip — Used to create code compliant non-seismic and seismic C and D, E, F off-module main beam to cross tee connections.

- STAC — 120 pcs
- FZSTAC — 50 pcs




GC3W90 — Grip Clip 3-Way — Joins main beams to cross tee via locking barbs without pop rivets or screws.

 - GC3W90 — 250 pcs
- FZGC3W90 — 50 pcs



XTACAG — Cross Tee Adapter Clip — Used to attach field-cut cross tees to main beams

- XTACAG — 100 pcs
- FZXTACAG — 50 pcs

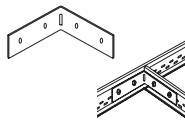

GCWA — Grip Clip Wall Attachment — Joins main beam or cross tee to wall molding via locking barbs without pop rivets or screws.

- GCWA — 250 pcs
- FZGCWA — 50 pcs

 


Closure Clips
MCC4G for Silhouette®
1/4" reveal — 200 pcs

- FZMCC4G — 50 pcs
- MCC8 for Silhouette 1/8" reveal — 200 pcs
- FZMCC8 — 50 pcs
- IES3 for Interlude® — 200 pcs
- FZIES3 — 50 pcs


C1430 — Variable Placement Hook Clip — Attach to T-Bar to create special length tees and position anywhere along the main beams.

- C1430 — 200 pcs
- FZC1430 — 50 pcs




DLCC — Direct Load Ceiling Clip — To hang suspension system below existing 15/16" grid face, transferring weight directly to hanger wire; may be used to preserve the fire rating of an existing ceiling and to support heavy accessories.

 - DLCC — 250 pcs
- FZDLCC — 50 pcs




UPCAG — Partition Clip — Fastens partition track section to suspension system for secure attachment; flip for 9/16" or 15/16" suspension system.

- UPCAG — 200 pcs
- FZUPCAG — 50 pcs

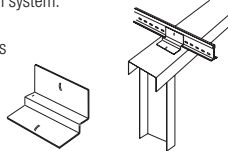


UTC — Uptight Clip — For tight suspension system attachment to 1-1/2" channel; bridging under HVAC ducts; can be used to install the suspension system tight to wood joists.

- UTC — 250 pcs
- FZUTC — 50 pcs

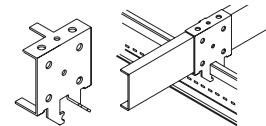


Channel Beam Splice — Used to suspend main beams to 1-1/2" black iron carrying channels.

 - CBS4A (4") — 200 pcs; FZCBS4 — 50 pcs
- CBS6A (6") — 200 pcs; FZCBS6 — 50 pcs
- CBS8A (8") — 200 pcs; FZCBS8 — 50 pcs
- CBS10A (10") — 150 pcs; FZCBS10 — 50 pcs
- CBS12A (12") — 150 pcs; FZCBS12 — 50 pcs
- For 2" Black Iron
- CBS2004A (4") — 75 pcs; FZCBS2004A — 50 pcs
- CBS2006A (6") — 75 pcs; FZCBS2006A — 50 pcs
- CBS2008A (8") — 75 pcs; FZCBS2008A — 50 pcs




SH12 — PeakForm® Support Hanger — For suspension systems 12" knock-out at 12" O.C.

- SB12 Square Bulb Support Hanger — 12 pcs/bundle
- SB12G90 Square Bulb Support — 12 pcs/bundle
- SH12 Hanger — 12 pcs/bundle

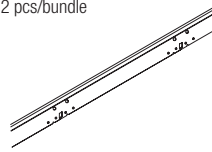


Adjustable Grid Spacer Clip — Used to space two parallel main beams for light fixtures, air diffusers, etc.; allows for 1/4" adjustments with three different clips.

- GSC9 Main Beam Center Line Spacing 2'1/2" - 8'1/2" — 100 pcs; FZGSC9 — 50 pcs
- GSC12 Main Beam Center Line Spacing 5'1/2" - 11'1/2" — 100 pcs; FZGSC12 — 50 pcs
- GSC16 Main Beam Center Line Spacing 9'1/2" - 15'1/2" — 100 pcs; FZGSC16 — 50 pcs

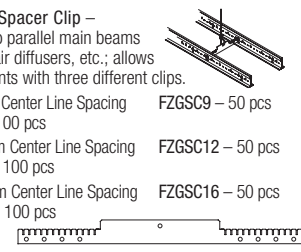


ABSC — Air Bar Spacer Clip — Parallel attachment of main beams; evenly spaces suspension system members for air diffuser; available in sizes from 1-7/8" to 6" in 1/8" increments.

- ABSC — 250 pcs

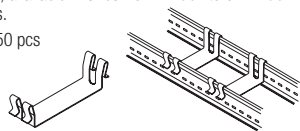

DWC — Drywall Clip — Allows for a "second" ceiling to be installed below a drywall ceiling; attach through installed drywall to supporting structure; DWC-approved for use in UL® Designs P237, P239, P240, and P241.

 - DWC — 250 pcs
- FZDWC — 50 pcs




7876 — Field Rout Tool

- 1 pc
- ARPLUG — Cross Tee Plug Clip 80 pcs




TZYK/TZBC — TechZone® Yoke & Brace

 - TZYK TechZone Yoke — 100 pcs
- FZTYK TechZone Yoke — 50 pcs





435A/436A — Optima® Panel Stabilizer Clips

 - 435A Stabilizer Clips for 3/4" - 1" panels — 50 pcs
- 436A Stabilizer Clips for 1-1/2" panels — 50 pcs



440A/441A/442A/443/522A — Vector® Clips

 - 440A Ultima® Panel Border Clip — 50 pcs
- 441A Optima® Panel Border Clip — 50 pcs
- 442A Hold-Down Clip — 50 pcs
- 443 Border Clips for Calla® Vector® — 50 pcs
- 522A Mid-point Clip — 50 pcs

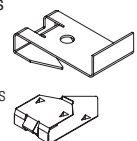

EXPOSED TEE SUSPENSION SYSTEMS ACCESSORIES

LEED® WELL™ | LBC

UP TO 30% RECYCLED CONTENT

energy management
 construction waste mgmt
 regional materials
 design for flexibility
 EPD
 recyclable/producer resp.
 biobased materials
 recycled content
 sourcing of raw materials
 material ingredient reporting
 low emitting materials
 lighting quality
 acoustics

 
Calculate sustainability with GreenGenie™
 armstrongceilings.com/greengenie

LOCATION DEPENDENT

7866 – Bullnose Corner Cover – For nominal 7/8" molding; snap over molding to trim outside corners; fits 1" radius block; 2" legs.


7864 – Bullnose Corner Cover – For nominal 7/8" molding; fits 3/4" radius block; 2" legs.

7866 – 100 pcs
 FZ7866 – 50 pcs
 7864 – 100 pcs
 FZ7864 – 50 pcs




7867 – Field-Cut Corner Cover – For nominal 15/16" molding; cut to fit irregular corner conditions; 2" legs.

 7867 – 100 pcs
 FZ7867 – 50 pcs




7869 – Inside/Outside Corner Cover – For nominal 7/8" angle molding; 1-3/4" legs.

7869 – 50 pcs

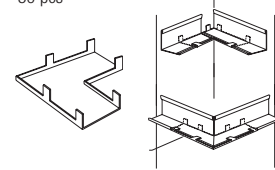


7863 – Outside Corner Cover – For nominal 7/8" angle molding; snap over molding to trim outside corners; 2" legs.

 7863 – 100 pcs
 FZ7863 – 50 pcs




7865 – Outside Corner Cover – For nominal 9/16" angle molding; snap over molding to trim outside corners; 2" legs.

 7865 – 100 pcs
 FZ7865 – 50 pcs




Shadow Molding – Inside Corner – Snaps over molding to easily trim inside corner:

 7874C use with 7874 – 100 pcs; FZ7874C – 50 pcs
 7861 use with 7873 – 100 pcs; FZ7861 – 50 pcs
 8771C use with 7877 – 100 pcs; FZ8771C – 50 pcs
 7878C use with 7878 – 100 pcs; FZ7878C – 50 pcs




Shadow Molding – Outside Corner – snaps over molding to easily trim outside corner:

 78740C use with 7874 – 100 pcs; FZ78740C – 50 pcs
 7862 use with 7873 – 100 pcs; FZ7862 – 50 pcs
 78770C use with 7877 – 100 pcs; FZ78770C – 50 pcs
 78780C use with 7878 – 100 pcs; FZ78780C – 50 pcs




LFC – Fixture Clip – Prefinished White for use at corners of light fixture modules on 9/16" exposed tee suspension systems (Suprafine®, Interlude®, Silhouette®); increases corner size to 15/16" which adapts light fixtures designed for the 15/16" suspension system; used when fixtures are not positively attached to the suspension system.

 LFC – 50 pcs; FZLFC – 50 pcs




414AG – Retention Clip – Attaches to main beams and cross tees behind lay-in ceiling; helps prevent accidental panel displacement by basketballs and other forces from below the ceiling.

414AG – 100 pcs
 FZ414AG – 50 pcs

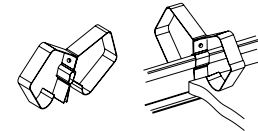


UHDCA – Universal Hold-Down Clip – Attaches to top bulb of the suspension system to hold 1/16" to 5/8" lay-in panel in place; helps to prevent ceiling panel fluttering at entryways.

UHDCA – 1,000 pcs
 FZUHDCA – 50 pcs

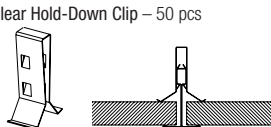

DW58LT – Transition Clip for 5/8" Drywall – Facilitates transition from drywall to acoustical ceiling; one-sided hold-down clip; eliminates need for drywall bead. Locking tabs provide secure location for DGS tees.

 DW50LT – Transition Clip for 1/2" Drywall – 125 pcs
 FZDW50LT – 50 pcs




7425 – 24" Stabilizer Bar – 100 pcs

7431 – 30" Stabilizer Bar – 100 pcs


7445 – 48" Stabilizer Bar – 100 pcs

Used to maintain uniform spacing of suspension system components (main beams and cross tees).

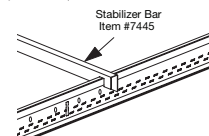

7891 – 12 Gauge Soft Hanger Wire (12' length) – Used to hang suspended ceilings from structural deck.

 7891 – 140 pcs



EHDC50A – Exterior Hold-Down Clip for 1/2" lay-in ceiling panels and drywall;

EHDC58AG – Exterior Hold-Down Clip for 5/8" lay-in ceiling panels and drywall;


EHDC75A – Exterior Hold-Down Clip for 3/4" lay-in ceiling panels and drywall;

locks under bulb of suspension system member to prevent upward movement.

EHDC50A – 125 pcs; FZEHDC50A – 50 pcs

EHDC58AG – 125 pcs; FZEHDC58AG – 50 pcs

EHDC75A – 125 pcs; FZEHDC75A – 50 pcs

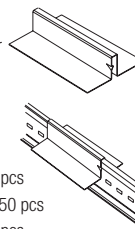


GA7327 – Grid Adapter – Allows for easy directional changes of Prelude® Main beams; 27" long component has two different end details. One end has a SuperLock™ clip with a rout 3" from the end, opposite end has an XL® clip with override end detail. This enables the adapter to be connected to either end of a Prelude main beam or plugged into a rout location on a main beam or cross tee.

GA7327 – 60 pcs




WS12 – Hanger Wire Splice – Splices 12-gauge hanger wire; recommended for renovation applications; provides easy adjustment of ceiling height.

 WS12 – 1,000 pcs
 FZWS12 – 50 pcs



BACG90A – Wind Uplift Clip – 250 pcs

FZBAGG90A – 50 pcs

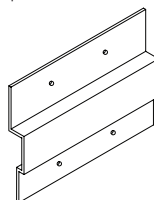

12 lb. Aircraft Cable and Connectors

AC1210 – 10' length

AC1215 – 15' length

AC1220 – 20' length

ACHC – Cable Quick Loop Connector

1 pc