



A-Shape LED

8.8A19/PER/950/P/E26/DIM 6/1FB T20

Philips A-Shape Dimmable LED Lamps are the smart LED Alternative to standard incandescent. The unique lamp design provides omni-directional light with excellent dimming performance.


Product data

General Information		Warm Up Time to 60% Light (Nom)	
Base	E26 [Single Contact Medium Screw]		0.5 s
EU RoHS compliant	Yes	Power Factor (Nom)	0.7
Nominal Lifetime (Nom)	15000 h	Voltage (Nom)	120 V
Switching Cycle	50000X	Temperature	
Technical Type	8.8-60W	T-Case Maximum (Nom)	90 °C
Light Technical		Controls and Dimming	
Color Code	950 [CCT of 5000K]	Dimmable	Yes
Beam Angle (Nom)	250 °	Mechanical and Housing	
Initial lumen (Nom)	800 lm	Bulb Finish	Frosted
Color Designation	Daylight	Bulb Shape	A19 (A19)
Correlated Color Temperature (Nom)	5000 K	Approval and Application	
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Energy Efficiency Label (EEL)	Not applicable
Color Consistency	<4	Energy Consumption kWh/1000 h	- kWh
Color Rendering Index (Nom)	90	Product Data	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Order product name	8.8A19/PER/950/P/E26/DIM 6/1FB T20
Operating and Electrical		EAN/UPC - Product	046677550455
Input Frequency	60 Hz	Order code	550459
Power (Rated) (Nom)	8.8 W	Numerator - Quantity Per Pack	1
Lamp Current (Nom)	80 mA	Numerator - Packs per outer box	6
Wattage Equivalent	60 W		
Starting Time (Nom)	0.5 s		

A-Shape LED

Material Nr. (12NC)	929002036304
Net Weight (Piece)	0.060 kg


Dimensional drawing

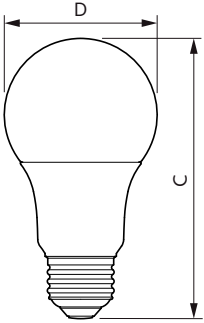


Bulb A19 120V 8.8-60W 800lm 5000K E26 D

Product	D	C
8.8A19/PER/950/P/E26/DIM 6/1FB T20	62.5 mm	111.5 mm


Photometric data

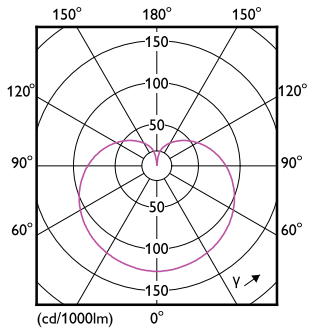

40 60 75 100W E26 A19 A21 Frosted

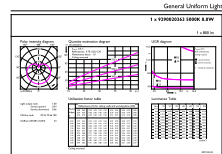

60W E26 A19 950 Frosted

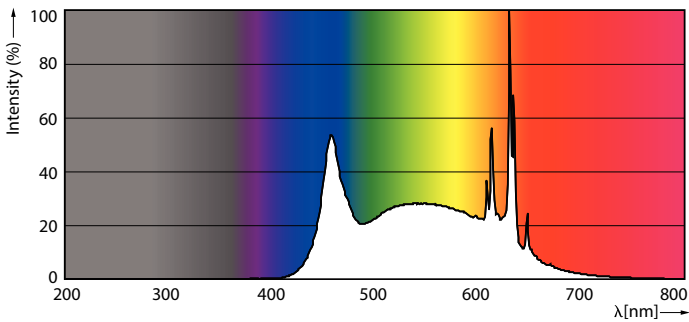

60W E26 A19 950 Frosted

A-Shape LED

Lifetime



15K LED

15K LMP

