

Combination Wallplates

Combination, Nylon, Standard Wallplates

Color	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Box Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Black	P126BK	P826BK	P1326BK	P226BK	—	P326BK	—
Brown	P126	P826	—	P226	—	P326	—
Gray	P126GY	P826GY	P1326GY	P226GY	—	P326GY	—
Ivory	P126I	P826I	P1326I	P226I	P1262I	P326I	P2262I
Light Almond	P126LA	P826LA	P1326LA	P226LA	P1262LA	P326LA	P2262LA
White	P126W	P826W	P1326W	P226W	P1262W	P326W	P2262W

Combination, Nylon, Mid-Size Wallplates


Color	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Box Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Black	—	PJ826BK	—	—	—	—	—
Brown	PJ126	PJ826	—	—	—	—	—
Gray	PJ126GY	PJ826GY	—	—	—	—	—
Ivory	PJ126I	PJ826I	PJ1326I	PJ226I	—	—	—
Light Almond	PJ126LA	PJ826LA	PJ1326LA	PJ226LA	—	—	—
White	PJ126W	PJ826W	PJ1326W	PJ226W	—	—	—

Combination, Standard, Metal Wallplates

Material	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Strap Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Brass	SB126	SB826	—	—	—	—	—
Brass Plated	—	—	—	—	—	—	—
Chrome	—	—	—	—	—	—	—
SS 302/304	SS126	SS826	SS1426	SS226	—	SS326	—

Note: See section O for complete selection of wallplates.

Dimensions

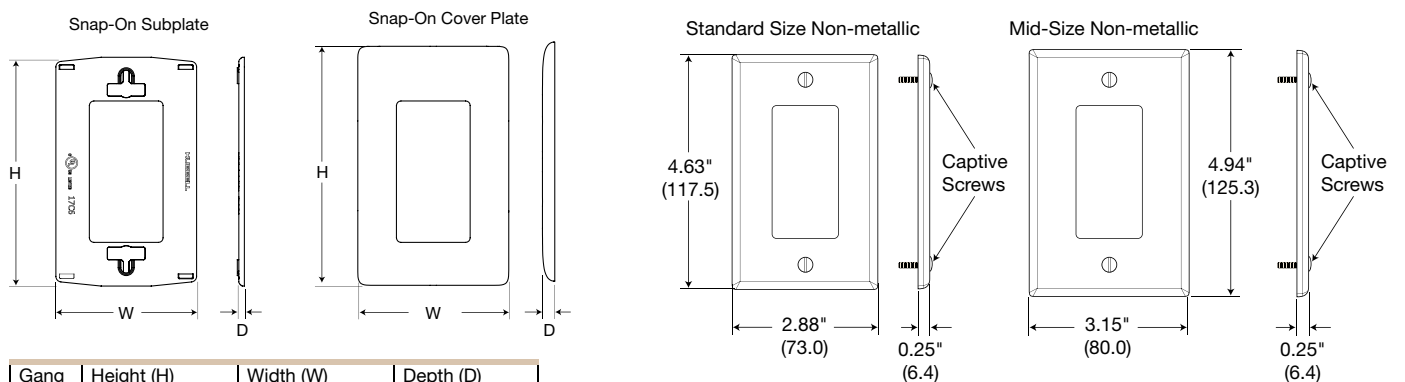

Gang	Height (H)	Width (W)	Depth (D)
1	4.75" (120.6)	3.00" (76.2)	.25" (6.2)
2	4.75" (120.6)	4.81" (122.2)	.25" (6.2)
3	4.75" (120.6)	6.62" (168.2)	.25" (6.2)
4	4.75" (120.6)	8.44" (214.3)	.25" (6.2)

Dimensions in Inches (mm)