


A RECHARGEABLE HEADLAMP WITH CLASS I, DIV 1 SAFETY RATINGS.

Three lighting modes cover a variety of tasks: spot for a focused beam, flood for soft area illumination that won't tire your eyes and spot/flood combo for even more light output.

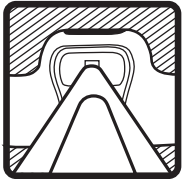

Spot/Flood Combo = 250 lumens

Features charge indicator
Red = charging
Green = charged



CHARGING



CHARGED

Battery charges
in 4.5 hours

Multi-function push-button switch
easy to use even with gloves

Adjustable elastic head strap



Lithium ion battery



Spot and flood beams:
– Spot: 190 lumens; 2,000 candela; 89m beam; runs 7.5 hours
– Flood: 120 lumens; 90 candela; 19m beam; runs 13 hours
– Spot/flood combo: 250 lumens; runs 7 hours
Tilting head prevents neck fatigue
Tough, polycarbonate thermoplastic construction with elastomer button; Unbreakable polycarbonate lenses; recessed to prevent scratches
IP67 rated; dust-tight and waterproof to 1m for 30 minutes; 2m impact resistance tested

Class I, II, Division 1, Groups A, B, C, D, E, F, G; Class III; Class 1, Zone 0, Group IIC, T-Code: T4
4.1 oz (116.2 grams) with battery
Limited Lifetime Warranty Visit streamlight.com for full warranty information
#61460 - USB HAZ-LO - 120V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow
#61462 - USB HAZ-LO - 230V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow

3M® and Dual Lock® are registered trademarks of the 3M Company