


DEWALT®

**PERFORM
PROTECT™**

**BRUSHLESS
MOTOR**

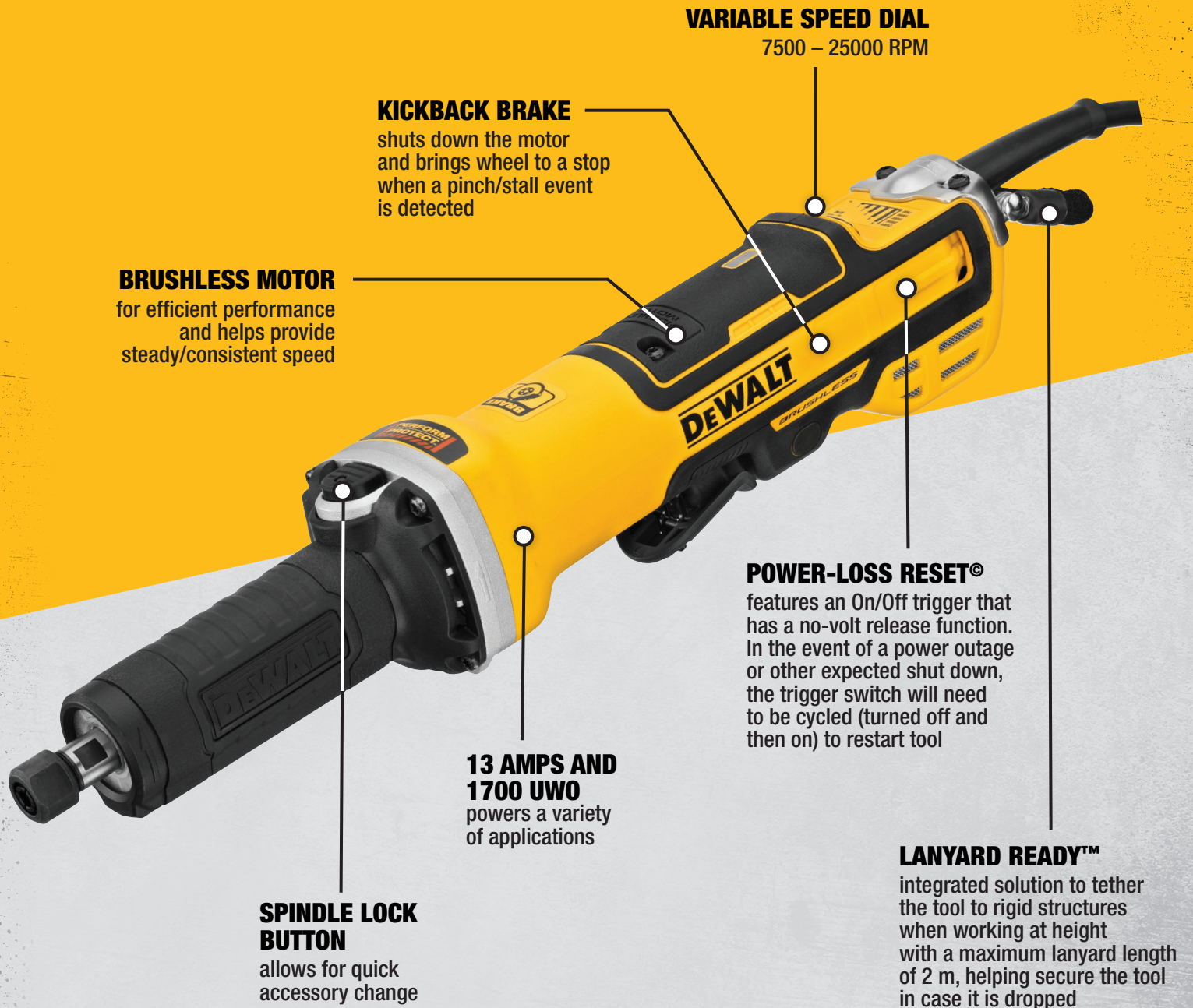

VARIABLE SPEED DIAL

7500 – 25000 RPM

KICKBACK BRAKE

shuts down the motor and brings wheel to a stop when a pinch/stall event is detected

BRUSHLESS MOTOR

for efficient performance and helps provide steady/consistent speed

POWER-LOSS RESET®

features an On/Off trigger that has a no-volt release function. In the event of a power outage or other expected shut down, the trigger switch will need to be cycled (turned off and then on) to restart tool

13 AMPS AND 1700 UWO
powers a variety of applications

SPINDLE LOCK BUTTON

allows for quick accessory change

LANYARD READY™

integrated solution to tether the tool to rigid structures when working at height with a maximum lanyard length of 2 m, helping secure the tool in case it is dropped

2" BRUSHLESS VARIABLE SPEED DIE GRINDER (LANYARD READY™)

DWE4997NVS



› Variable Speed Dial helps provide control over no-load speed range up to 28000 RPM.



› LED lights help illuminate dark workspaces.

SPECIFICATIONS

AMPS	13 AMPS
No Load Speed	7500-25000 RPM
Lock-On Switch	No
Variable Speed	Yes
Spindle Lock	Yes
Tool Weight (Tool only)	4.32 lbs (1.96 kg)

TOOL WARRANTY



RELATED PRODUCTS

DWE4887
1-1/2 IN.
DIE GRINDER



DWE4997VS
2 IN. BRUSHLESS
DIE GRINDER WITH
LOCK-ON



DCG426M2
20V MAX* 1-1/2 IN.
DIE GRINDER KIT"



1-800-4-DEWALT

www.DEWALT.com

Copyright ©2020 DeWALT. The following are examples of trademarks for one or more DeWALT power tools and accessories: the yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.