



**HBL9450A**

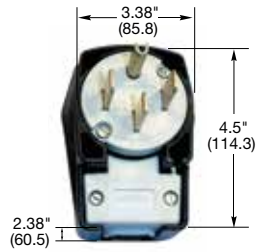

**HBL9451C**



**HBL9452C**

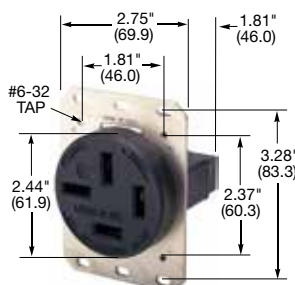

**HBL8350A**

## 50A, 125/250V, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY



**50A 125/250V**  
NEMA 14-50R  
UL CSA  
3(2) HP



**50A 125/250V**  
NEMA 14-50P  
UL CSA  
3(2) HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL9450A</b>
Plug, nylon.	.625"-1.310" (15.9-33.3)	- <b>HBL9451C</b>
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	- <b>HBL9452C</b>

## 50A, 3Ø 250V AC, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY



**50A 3Ø 250V AC**  
NEMA 15-50R  
UL CSA  
7.5 HP



**50A 3Ø 250V AC**  
NEMA 15-50P  
UL CSA  
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL8450A</b>
Plug, nylon.	.625"-1.310" (15.9-33.3)	- <b>HBL8451C</b>
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	- <b>HBL8452C</b>



## 50A, 3ØY 120/208V AC, 4 Pole, 4 Wire Non-Grounding, Receptacles and Plugs

**IP20**  
SUITABILITY



**50A 3ØY**  
120/208V AC  
NEMA 18-50R  
UL Listed  
7.5 HP



**50A 3ØY**  
120/208V AC  
NEMA 18-50P  
UL Listed  
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL8350A</b>
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	- <b>HBL8352C</b>

*Note: RTP is an abbreviation for reinforced thermoplastic polyester.  
See page A-50 for accessories.*

Dimensions in Inches (mm)