

**30 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC
4 Pole, 4 Wire, Non-Grounding**

IP20
SUITABILITY



**30A 3ØY 120/208V AC
NEMA L18-30P
3 HP**

**30A 3ØY 277/480V AC
NEMA L19-30P
10 HP**

**30A 3ØY 347/600V AC
NEMA L20-30P**

Plugs

Description	Cord Dia.	Catalog Number
Black and white nylon.	.350"-1.150" (9-29)	HBL2751 HBL2761 HBL2771

Note: See page B-55 for accessories.




HBL2751

Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	HBL2755 HBL2765 HBL2775

Note: See page B-54 for accessories.

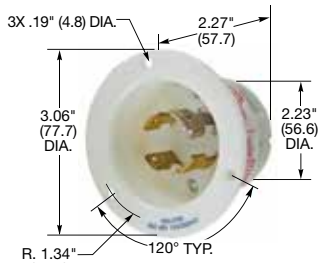

HBL2755

IP20
SUITABILITY



**30A 3ØY 120/208V AC
NEMA L18-30R
3 HP**

**30A 3ØY 277/480V AC
NEMA L19-30R
10 HP**

**30A 3ØY 347/600V AC
NEMA L20-30R**

Connector Bodies

Description	Cord Dia.	Catalog Number
Black and white nylon.	.350"-1.150" (9-29)	HBL2753 HBL2763 HBL2773

Note: See page B-54 for accessories.




HBL2753

Single Flush Receptacles

Description	Catalog Number
Black nylon face, back and side wired.	HBL2750 HBL2760 HBL2770

Note: See page B-54 for accessories.

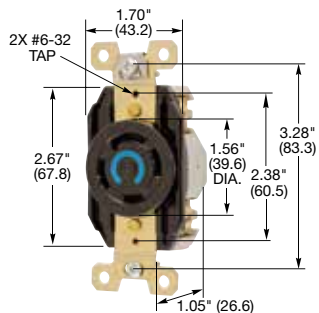


HBL2750

Flanged Receptacles

Description	Catalog Number
Nylon casing, back wired.	HBL2756 HBL2766 HBL2776

Note: See page B-54 for accessories.

See page B-71 for technical information on Twist-Lock devices.

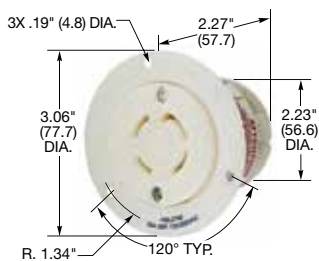

HBL2756

Dimensions in Inches (mm)