

## 20 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC 4 Pole, 4 Wire, Non-Grounding

**IP20**  
SUITABILITY



20A 3ØY 120/208V AC  
NEMA L18-20P  
2 HP

20A 277/480V AC  
NEMA L19-20P  
5 HP

20A 347/600V AC  
NEMA L20-20P

### Plugs

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.350"-1.150" (9-29)	<b>HBL2441</b>	<b>HBL2451</b>	<b>HBL2461</b>

Note: See page B-54 for accessories.




**HBL2441**

### Flanged Inlets

Description	Catalog Number		
Nylon casing, back wired.	<b>HBL2445</b>	<b>HBL2455</b>	<b>HBL2465</b>

Note: See page B-54 for accessories.

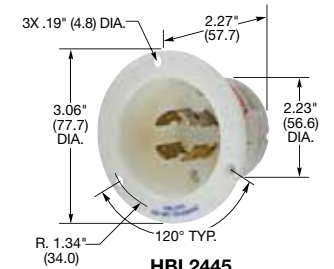

**HBL2445**

**IP20**  
SUITABILITY



20A 3ØY 120/208V AC  
NEMA L18-20R  
2 HP

20A 277/480V AC  
NEMA L19-20R  
5 HP

20A 347/600V AC  
NEMA L20-20R

### Connector Bodies

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.350"-1.150" (9-29)	<b>HBL2443</b>	<b>HBL2453</b>	<b>HBL2463</b>

Note: See page B-54 for accessories.




**HBL2443**

### Single Flush Receptacles

Description	Catalog Number		
Black nylon face, back and side wired.	<b>HBL2440</b>	<b>HBL2450</b>	<b>HBL2460</b>

Note: See page B-54 for accessories.

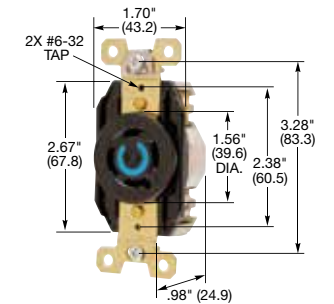

**HBL2440**

### Flanged Receptacles

Description	Catalog Number		
Nylon casing, back wired.	<b>HBL2446</b>	<b>HBL2456</b>	<b>HBL2466</b>

Note: See page B-54 for accessories.


See page B-71 for technical information.

See page B-41 for switched enclosure.

See page B-44 for Add-A-Shroud® kit. For use with connector bodies.

Only receptacles and plugs up to 480V AC are HP rated.

HP ratings are AC only.

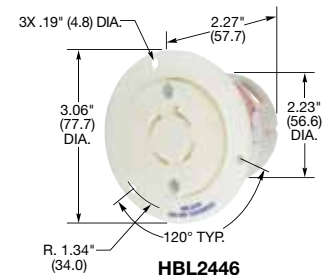

**HBL2446**

Dimensions in Inches (mm)