

2443P

Product no.: 2443P

Round nose pliers with very precise, smooth jaws



 
Pliers for miniature and standard electronics



Optimized ergonomically shaped handles for increased comfort



Non-reflecting surface, ESD-safe



source images

Built to Last - Longest lasting durability on the planet


Weller Erem™ Pliers are designed to ensure an accurate and sure grip every time. Manufactured with uncompromising Swiss quality and created for worldwide applications, including electronics assembly and healthcare, Weller Erem Pliers are built to last. Feel the difference with Weller Erem™ – the proven choice. Every time.

Type Type of Cut Cutting Capacity

Series 2400 MagicSense

mm 0,03 0,1 0,2 0,3 0,4 0,5 0,6 0,7 0,8 0,9 1,0 1,1 1,2 1,3 1,4 1,5 1,6 1,7 1,8 1,9 2,0
Inch .0001 .003 .007 .011 .015 .019 .023 .027 .031 .035 .039 .043 .047 .051 .055 .059 .062 .066 .070 .074 .078

Type	Type of Cut	Cutting Capacity
	Semi Flush	0,2 - 1,6
	Flush	0,2 - 1,6
	Super Full Flush	0,2 - 1,6
	Flush	0,2 - 1,2
	Flush	0,2 - 1,6
	Flush	0,2 - 1,2
	Flush	0,2 - 1,2
	Flush	0,2 - 0,8
	Flush	0,2 - 0,8
	Flush / Carbide	0,2 - 1,6

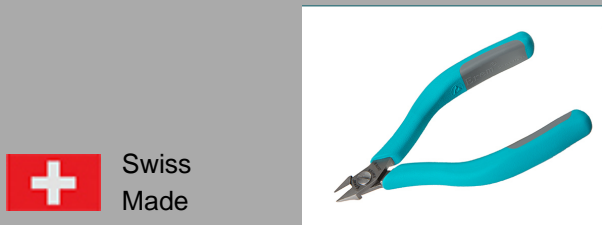



Technical Data

Length mm	146
Jaw length in mm	30.3
Head width mm	11
Head thickness mm	6
Width of tips in mm	0.8
Total height of both tips in mm	1.6
Length inches	5.748
Jaw length inches	1.319
Head width Inches	0.43
Head thickness Inches	0.24
Width of tips in Inches	0.031
Total height of both tips in Inches	0.063
ESD-safe	on
Erem applications	---
Material	Special tool steel
Weight in g	76
Weight in oz	2.681