

## Xcelerator Jacks

# HUBBELL

### Xcelerator USOC Jack

#### Features

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

#### Ordering Information

Description	Color	Catalog No.	UPC
Xcelerator USOC Jack	Ivory	HXJUEI	662620824666

#### Listings

6-Position USOC Compliant  
Mechanical TIA-568-C.2  
UL Listed 1863  
CSA Certified  
RoHS Compliant

#### Specifications

Nose Contact	Beryllium copper with precious metal plating over nickel under plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

#### Performance

##### Electrical


6-Position USOC Compliant

##### Mechanical

Nose Contact Mating Cycles: 2000  
IDC Contact Termination: 10x  
Keystone Latching Force: 25 lbs.  
Contact performance confirmed over the full range of ISO/FCC compliant plug

#### Applications

Phone  
DSL

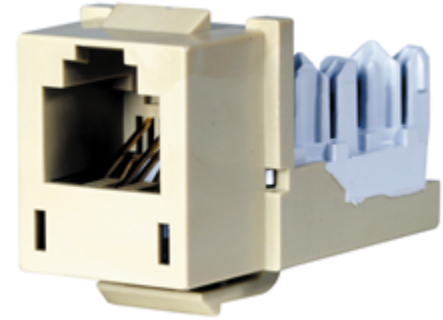

#### Accessories

1-Punch Tool	TX4P
Dust Cover	HXJDC25
Termination Puck	HXTP25

#### Online Resources

eCatalog