



A-Shape LED

12.2A19/PER/950/P/E26/DIM 6/1FB T20

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information		Warm Up Time to 60% Light (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5 s
EU RoHS compliant	Yes	Power Factor (Nom)	0.7
Nominal Lifetime (Nom)	15000 h	Voltage (Nom)	120 V
Switching Cycle	50000X	Temperature	
Technical Type	12.2-75W	T-Case Maximum (Nom)	85 °C
Light Technical		Controls and Dimming	
Color Code	950 [CCT of 5000K]	Dimmable	Yes
Beam Angle (Nom)	250 °	Mechanical and Housing	
Luminous Flux (Nom)	1100 lm	Bulb Finish	Frosted
Color Designation	Daylight	Bulb Shape	A19 (A19)
Correlated Color Temperature (Nom)	5000 K	Approval and Application	
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Energy Efficiency Label (EEL)	Not applicable
Color Consistency	<4	Energy Consumption kWh/1000 h	- kWh
Color Rendering Index (Nom)	90	Product Data	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Order product name	12.2A19/PER/950/P/E26/DIM 6/1FB T20
Operating and Electrical		EAN/UPC - Product	046677560997
Input Frequency	60 Hz	Order code	929002285204
Power (Nom)	12.2 W	Numerator - Quantity Per Pack	1
Lamp Current (Nom)	100 mA	Numerator - Packs per outer box	6
Wattage Equivalent	75 W		
Starting Time (Nom)	0.5 s		

A-Shape LED

Material Nr. (12NC)	929002285204
Net Weight (Piece)	0.060 kg


Dimensional drawing

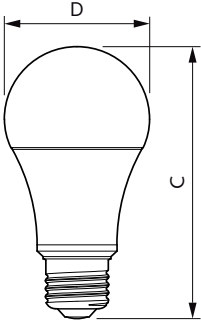


A19 120V 12.2-75W 1100lm 5000K E26 D

Product	D	C
12.2A19/PER/950/P/E26/DIM 6/1FB T20	60 mm	112 mm


Photometric data

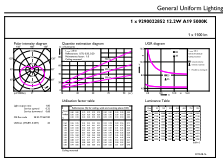

LEDbulb 12,2W A19 E26 950 FR

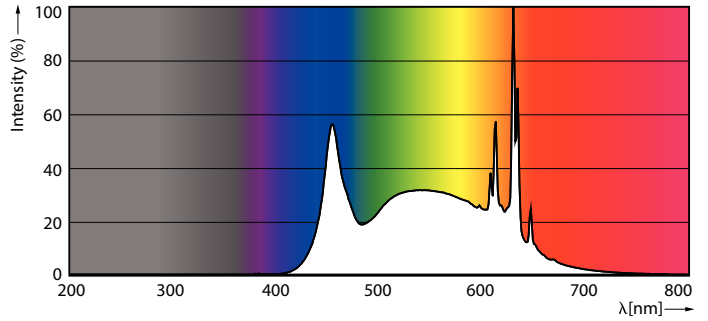

LEDbulb 12,2W A19 E26 950 FR

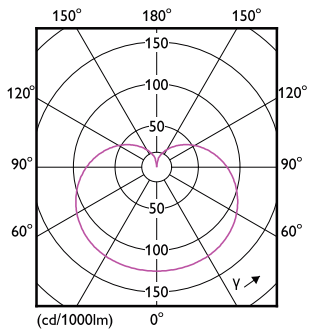

LEDbulb A19 12,2W E26 1100lm 950 FR

A-Shape LED

Lifetime



15K LED

15K LMP

