

HyFlex[®]

ADVANCED MECHANICAL PROTECTION

11-754

Our lightest ANSI A4 / ISO Level D Cut Resistant touchscreen glove



Cut



Light Duty

Ultralight ANSI A4/ISO D cut-resistant gloves with touchscreen compatibility

- **Heightened defenses:** Meeting ANSI A4 and ISO D standards for cut resistance, and equipped with INTERCEPT™ Cut Resistance Technology yarn, HyFlex[®] 11-754 industrial gloves guard against lacerations and prevent common workplace injuries
- **Enhanced sensitivity:** Palm-dipped, with Nylon[®] liner, these PU-coated gloves benefit from advanced tactile sensitivity and touchscreen compatibility
- **Elevated comfort:** Lightweight and fitted to natural hand contours, HyFlex[®] 11-754 PPE gloves cause minimal hand fatigue
- **Improved dexterity:** These polyurethane gloves' ultralight design also increases flexibility and ease of use
- **Reduced irritation:** HyFlex[®] 11-754 industrial working gloves are Dermatest[®]-approved for skin-friendliness and cleanliness



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication
- Automotive Aftermarket

Applications

- Assembly & inspection of components
- Picking, fastening components
- Final assembly
- Applying finish to materials, products

HyFlex®

ADVANCED MECHANICAL PROTECTION

11-754

Our lightest ANSI A4 / ISO Level D Cut Resistant touchscreen glove

Key Features

- ANSI A4/ISO D cut protection: 3x greater defense from lacerations*
- Ultralight design: All-day comfort and dexterity are ensured
- Touchscreen compatible: Tactile sensitivity for optimized productivity
*versus standard ANSI A2/ISO B-rated gloves


Technologies



Touchscreen Compatible

Performance Standards & Regulatory Compliance

REACH Compliant

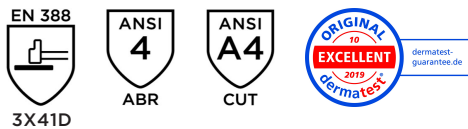

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	COLOR	PACKAGE
HyFlex® 11-754	Finishing: Palm dipped Coating Material: Polyurethane Liner Material: Nylon, Spandex, Stainless steel Cuff Style: Knitwrist	18	6, 7, 8, 9, 10, 11, 12	Grey	• 12 pairs/bag, 12 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3, 678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalin Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

