


SEE WHAT'S UP AHEAD & BELOW WITH THE CLASS I, DIV. 1 DUAL LIGHT 325 LUMEN RAZOR FSL.

- Class I, Div 1 ATEX/IECEx Zone 0
- 3 light modes - high and low and combo
- Forward light runs 24 hours on low, 7 hours on high
- Forward and downward light runs 10 hours
- Downlight eliminates trips, slips and falls
- 2 lights - a forward beam and a downward beam, combo of both
- Two magnets: one on integrated belt clip and one at base of flashlight
- Drop rating of 2 meters
- Tail cap slot for lanyard connection point

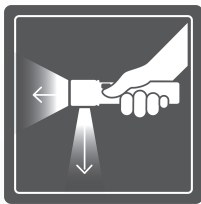

2 Magnets for Handsfree Lighting!

HIGH MODE

FL1 STANDARDS	
325 LUMENS	7 h
14,000 cd	2m
236m	1m

LOW MODE

FL1 STANDARDS	
125 LUMENS	24 h
7,000 cd	2m
167m	1m

DOWNLIGHT

FL1 STANDARDS	
150 LUMENS	20 h
1,000 cd	2m
63m	1m

COMBO

FL1 STANDARDS	
300 LUMENS	10 h
7000 cd	2m
167m	1m

See it all.™



SPECIFICATIONS

POWER SOURCE: 3 AA-cell Alkaline Batteries

LAMP: Advanced LED Technology

COLOR: High-Vis Yellow

LIGHT OUTPUT: High 325 Lumens, Low 125 Lumens,
Downlight 150 Lumens,
Dual Mode (Forward + Downlight) 300 Lumens

PEAK BEAM INTENSITY: High 14,000 Candela, Low 7,000 Candela,
Downlight 1,000 Candela

BEAM DISTANCE: High 236 meters, Low 167 meters, Downlight 63 Meters

INGRESS PROTECTION: Waterproof 1 Meter IPX7

RUN TIME: High 7 Hours, Low 24 Hours,
Downlight 20 Hours,
Dual Mode (Forward + Downlight) 10 Hours

WEIGHT: 8 oz.

LENGTH: 7.125 in. **WIDTH:** 2 in. **HEIGHT:** 2 in.

SAFETY RATINGS

UL 913

Class I Div 1 & 2 A-D

Class II Div 1 & 2 E-G

Class III Div 1 & 2

T2

ATEX/IECEX/UKCA

II 1G Ex ia op is IIC T2 Ga

ACCESSORIES

#23863 - 6 1/2" Orange Slip Over Wand

#10B-226 - Helmet Clip

#60170D - Counter display is available to ship loaded and assembled.



ACCESSORIES

#10B-226 - Helmet Clip



See it all.™

KBS