

855GX IntelliBender®

SAVE MONEY WITH EVERY BEND.

SIMPLE.



ORIENT SHOES



SELECT ANGLE(S)



BEND



4X FASTER SETUP!*



PRODUCTIVE.

- Change from Rigid/IMC to EMT in under 1 minute
- Conduit sensor automatically detects size of conduit
- One-button program for standard bends
- Calculate marks for complex bends in under 1 minute

ACCURATE.

- Absolute encoder stops bends at exact angles, and accommodates for conduit spring back
- Digital pendant gives accurate feedback
- Save, repeat and export bends via USB port

Type of Conduit	Cost reduction after 100 pieces saved*
2" Rigid	\$4382.80
2" EMT	\$1674.00

RELIABLE.

- Rugged construction withstands the demands of the jobsite
- Solid-state electronics rated for over 1,000,000 bends, so you can keep saving time, conduit, and money.



* Claims based on list price of 10' long EMT and Rigid conduit. Speed claims based on timed 4-bend saddle comparisons between the 855GX, Gardner Bender B2000, and other similar benders.



855GX IntelliBender®

FOR PRODUCT VIDEOS,
DEMONSTRATIONS AND MORE, VISIT:
www.youtube.com/GreenleeDEMO

QUICK SETUP.

Sensors automatically detect conduit size for fast setup.

COMPLETE CONTROL.

Digital pendant provides accurate bend progress feedback.

ACCURATE.


Absolute encoder stops bending at precise angles.

FASTER.

Rotate shoe to change from Rigid/IMC to EMT in under 1 minute.

SMARTER.

Calculate U-Bends and Saddles in under 1 minute.

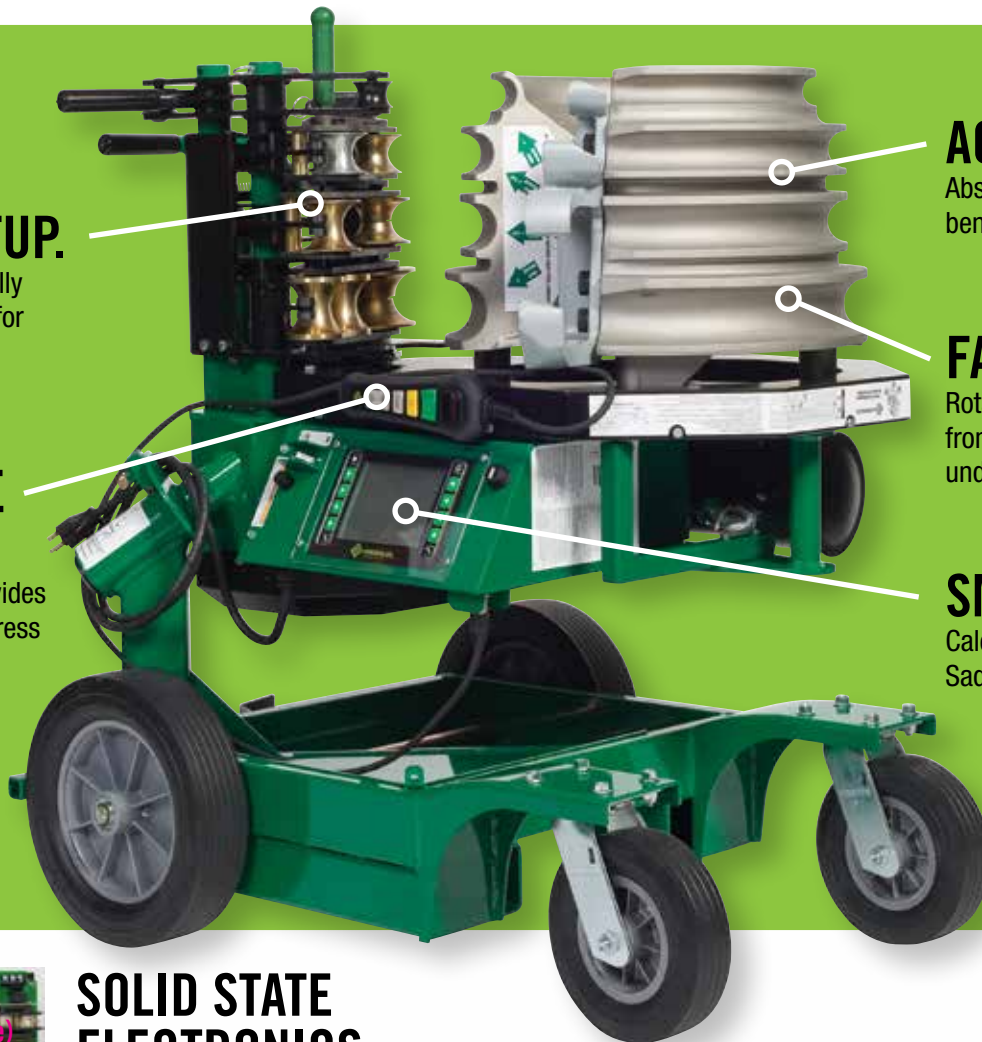

SOLID STATE ELECTRONICS.

System eliminates risk of arc flashes and increases machine life.

**MAKE BENDS FASTER,
SAFER AND EASIER WITH
THE GREENLEE 855GX**

CAT. NO.	UPC NO.	DESCRIPTION
855GX	12579	855GX IntelliBender™ for bending 3/4" to 1" Rigid and 1" to 2" EMT / IMC conduit.
12582	12582	855GX Shoe Group for bending 1/2" – 2" PVC Coated Rigid Conduit.



www.greenlee.com MA-5561 12/18
4455 Boeing Drive • Rockford, IL 61109-2988 • USA • 815-397-7070
©2018 Greenlee Tools, Inc. • An ISO 9001 Company • Printed in USA

