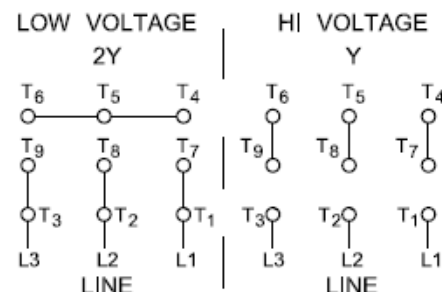


Dayton[®]**WASHDOWN MOTOR****RU**
E47479**CS**[®]
C 244681
US

MODEL NO. 6WY28A

MFG.NO. WTSNR18-056-13

PH 3

CONNECTIONTO REVERSE ROTATION INTERCHANGE
ANY TWO LINE LEADS

ENCL. TENV

MAX.AMB. 40°C

HP 0.33/0.25

DUTY CONT.

RPM 1745/1450

HZ 60/50

VOLT 208-230/460

VOLT 190/380

F.L.A. 1.4-1.2/0.6

F.L.A. 1.0/0.5

S.F.A. 1.5-1.3/0.65

S.F.A. 1.2/0.6

SER.
FACT. 1.15

INS.CL. F

FRAME 56C

NEMA
NOM.EFF. 82.5%

P.F. 0.71

CODE K

DES. B

BRG.
SHAFT END 6205BRG.OPPOSITE
SHAFT END 6205Thermally
Protected NONE

DATE CODE 1207

**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.



Mfd.For Dayton Electric Mfg.Co.,Lake Forest,IL 60045 USA

Made in China