

**Dayton**<sup>®</sup>**WASHDOWN MOTOR**

  
E47479


  
C 244681 US


MODEL NO. 6WY31A

MFG.NO. WTSNR18-056-12

PH 3


**CONNECTION**

LOW VOLTAGE

HI VOLTAGE

2Y

Y

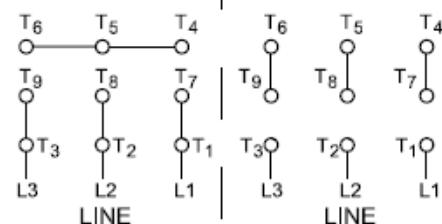

TO REVERSE ROTATION INTERCHANGE  
ANY TWO LINE LEADS

ENCL. TENV

MAX.AMB. 40°C

HP 0.5/0.33

DUTY CONT.

RPM 1745/1450

HZ 60/50

VOLT 208-230/460

VOLT 190/380

F.L.A. 1.8-1.6/0.8

F.L.A. 1.4/0.7

S.F.A. 2.0-1.8/0.9

S.F.A. 1.6/0.8

SER.  
FACT. 1.15

INS.CL. F

FRAME 56C

NEMA  
NOM.EFF. 82.5%

P.F. 0.78

CODE K

DES. B

BRG.  
SHAFT END 6205BRG.OPPOSITE  
SHAFT END 6205Thermally  
Protected NONE

DATE CODE 1207

**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.



Mfd.For Dayton Electric Mfg.Co.,Lake Forest,IL 60045 USA

Made in China