

Dayton®

WASHDOWN PREMIUM EFFICIENT MOTOR



CC082A

MODEL NO. 6WY38C

MFG.NO. WTL143T-4W1

PH 3

ENCL. TENV

MAX.AMB. 40°C

HP 1.0/0.75

DUTY CONT.

RPM 1740/1440

HZ 60/50

VOLT 230/460

VOLT 190/380

F.L.A. 3/1.5

F.L.A. 2.8/1.4

S.F.A. 3.6/1.8

S.F.A. 3.2/1.6

SER. FACT. 1.15 INS.CL. F

FRAME 56HC

NEMA NOM.EFF. 85.5% P.F. 0.71

CODE K DES. B


BRG. SHAFT END 6205

BRG.OPPOSITE SHAFT END 6205

Thermally Protected NONE

DATE CODE 1601

CONNECTION

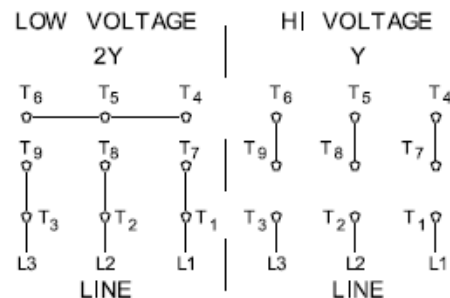

TO REVERSE ROTATION INTERCHANGE
ANY TWO LINE LEADS



WARNING

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.



Mfd. For Dayton Electric Mfg. Co., Lake Forest, IL 60045 USA

Made in China