

Dayton®**WASHDOWN PREMIUM
EFFICIENT MOTOR****CC082A**

MODEL NO. 6WY57C

MFG.NO. WTL143T-4W1

PH 3

ENCL. TENV

MAX.AMB. 40°C

HP 1.0/0.75

DUTY CONT.

RPM 1740/1440

HZ 60/50

VOLT 230/460

VOLT 190/380

F.L.A. 3/1.5

F.L.A. 2.8/1.4

S.F.A. 3.6/1.8

S.F.A. 3.2/1.6

SER.
FACT. 1.15

INS.CL. F

FRAME 56C

NEMA
NOM.EFF. 85.5%

P.F. 0.71

CODE K

DES. B

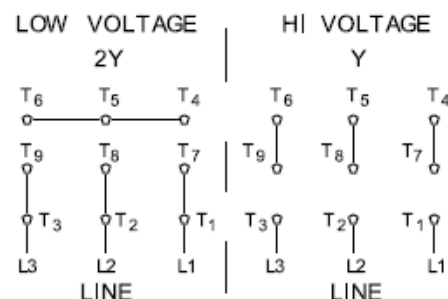
BRG.
SHAFT END 6205BRG.OPPOSITE
SHAFT END 6205Thermally
Protected NONE

DATE CODE 1601

Mfd.For Dayton Electric Mfg.Co.,Lake Forest,IL 60045 USA

Made in China

CONNECTION

TO REVERSE ROTATION INTERCHANGE
ANY TWO LINE LEADS**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.

