

BESSEY® VarioClippix®


The Variable Spring Clamp



Simply better.

The VarioClippix® is a clever variation on a standard spring clamp. The handles stay at a constant setting, while the variable upper jaw can open as wide as 4" (100 mm). One innovative clamp does the work of four different spring clamps.

- 1 Rapid-action, polyamid, sliding top jaw infinitely adjusts to fit project ... the clamping capacity of a 4" spring clamp with the comfort of a 2" clamp.
- 2 Ergonomic 2-component handle - designed for comfort and a firm grip.
- 3 Soft-touch pads for a non-marring firm grip.

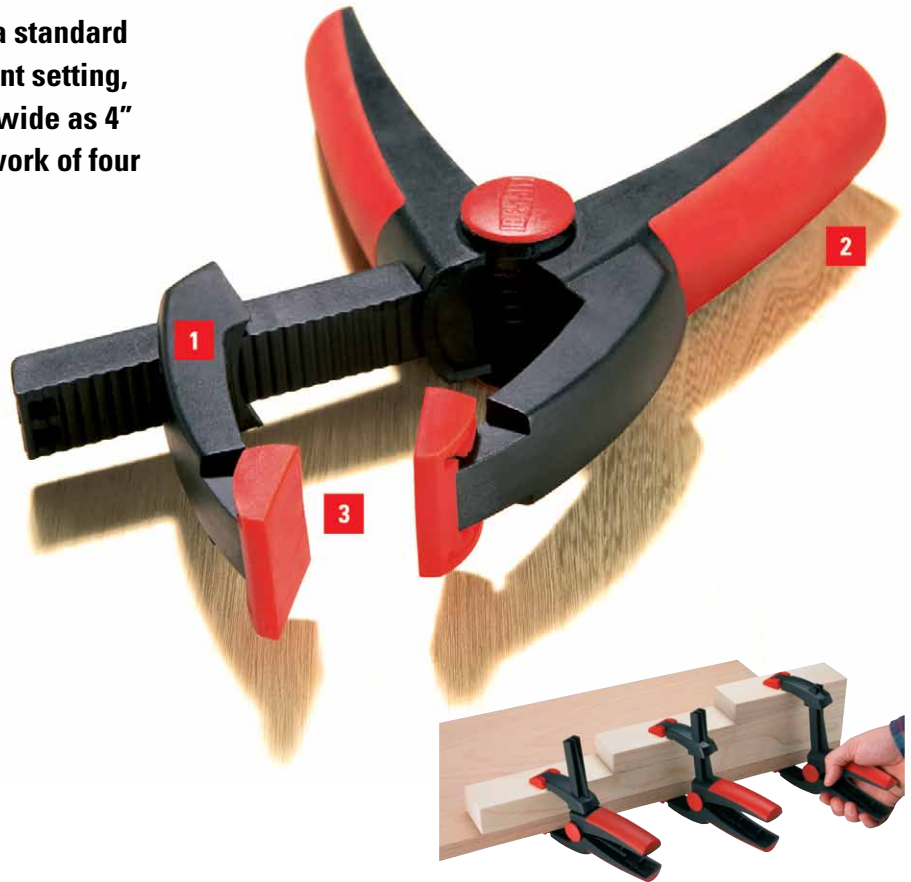

Variable Opening

Infinitely adjustable up to 4" (100 mm) opening...It does the work of 4 different spring clamps, offering optimum handling.

Variable Angle

Once the opening of the VarioClippix is adjusted, the clamp can be applied from any angle...the upper jaw won't slide down the rail until 'you' move it.

Variable Force

The combination of the moveable jaw and a spring clamp permits the user to do something unique for a spring clamp...you can vary the pressure from maximum to almost nothing with one clamp.

Catalog Number	Opening		Depth	
XV3-50	60 mm	2 ³ / ₈ "	37 mm	1 ¹ / ₂ "
XV5-100	100 mm	4"	50 mm	2"

Rev. Mar 20 2012