

CLEAN ROOM™ FL / CLEAN ROOM™ VL & VL

Square Lay-in
smooth texture



SUSTAIN®
High Performance
Sustainable
Ceiling Systems

▼ Clean Room VL panels with Clean Room 1-1/2" suspension system

CAD/Revit® drawings at:
armstrongceilings.com/cadrevit



▲ Clean Room™ FL panels with Clean Room 15/16" suspension system

▲ VL panels with Prelude® XL® 15/16" suspension system

Smooth-texture panels with a water-repellent, scrubbable surface that meets guidelines for controlled environments and FSIS/USDA.

KEY SELECTION ATTRIBUTES

- Clean Rooms up to ISO Class 5 (Class 100) (excludes items 869, 871)
- Clean Room FL panels are part of the Sustain® portfolio, and meet the most stringent industry sustainability compliance standards today
- Excellent sound blocking CAC 35-40
- CleanAssure™ family of products – includes disinfectable panels, suspension systems, and trim
- Bacteria-resistant surface
- Mold- and mildew-resistant surface
- Durable – Washable, Scrubbable, Water-repellant, Impact-resistant, Scratch-resistant, Soil-resistant
- 30-Year Limited System Warranty against visible sag, mold, and mildew
- 10-Year replacement panel available for items 1715, 1716, 1720, 1721



TYPICAL APPLICATIONS

Clean Room FL, Clean Room VL


- Clean Rooms
- Kitchens/food preparation areas
- Laboratories
- Healthcare
 - Patient rooms
 - Treatment rooms
 - Semi-restricted surgical areas
 - Emergency rooms

VL (Perforated)

- Lavatories/restrooms
- Utility rooms

NOTE: 24" x 24" items 1715 and 1720 and 24" x 48" items 1716 and 1721 are to be used together within the same ceiling – field panels are used for acoustics and border panels for cutting

COLORS

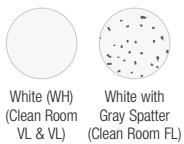

DETAILS (Other Suspension Systems compatible. Refer to listing on next page.)



1. Clean Room™ FL
2. Clean Room™ VL
3. VL
4. Clean Room™ FL with 15/16" suspension system
5. Clean Room™ VL with 1-1/2" suspension system

CLEAN ROOM™ FL / CLEAN ROOM™ VL & VL

Square Lay-in
smooth texture

USDA
CERTIFIED
BIOBASED
PRODUCT
PRODUCT 91%

SUSTAIN*
High Performance
Sustainable Ceiling Systems

Declare.

GREENGUARD
Gold Certified
(details below)

LEED®
WELL™ LBC

Refer to individual product pages for LEED info.



LOCATION DEPENDENT

VISUAL SELECTION

PERFORMANCE SELECTION

\$\$\$


armstrongceilings.com/catdwgs	Susp. Dwg.	Item No.	Dimensions (Inches)	UL Classified Acoustics	NRC + CAC	Total Acoustics ¹	Fire Performance	Light Reflect	Anti-Mold/Mildew	Sag Resistant	Certified Low VOC Emissions	CleanAssure™ Disinfectable Panels	DURABILITY							Recycle Program	30-Yr Warranty	
												Fog & Spray	Wipe	Water Repel	Wash	Scrub	Impact	Scratch	Soil			
CLEAN ROOM™ FL Field Panel*	1, 6, 7	1715	24 x 24 x 3/4"	□	0.55	35	N/A Class A	0.79	•	•	•	•	•	•	•	•	•	•	•	•	N/A	•
15/16" or 1-1/2" Square Lay-in		1716	24 x 48 x 3/4"	□	0.55	35	N/A Class A	0.79	•	•	•	•	•	•	•	•	•	•	•	•	N/A	•
CLEAN ROOM™ FL Border Panel*	1, 6, 7	1720	24 x 24 x 5/8"	□	N/A	35	N/A Class A	0.79	•	•	•	•	•	•	•	•	•	•	•	•	N/A	•
15/16" or 1-1/2" Square Lay-in		1721	24 x 48 x 5/8"	□	N/A	35	N/A Class A	0.79	•	•	•	•	•	•	•	•	•	•	•	•	N/A	•
5/8" Thick – 15/16" or 1-1/2" Square Lay-in																						
Made-to-Order Sizes		Width	Length		N/A	N/A	N/A Class A	0.78	•	•	•	•	•	•	•	•	•	•	•	•	N/A	•
CLEAN ROOM™ FL		24"	24" - 48"																			
CLEAN ROOM™ VL Unperforated	1, 6, 7	868	24 x 24 x 5/8"	□	N/A	40	N/A Fire Guard™	0.80	•	Std	N/A	•	•	•	•	•	•	•	•	•	N/A	10-Yr
15/16" or 1-1/2" Square Lay-in		870	24 x 48 x 5/8"	□	N/A	40	N/A Fire Guard	0.80	•	Std	N/A	•	•	•	•	•	•	•	•	•	N/A	10-Yr
VL Perforated (Not for Clean Rooms)	1	869	24 x 24 x 5/8"	□	0.55	35	N/A Fire Guard	0.78	•	Std	N/A	N/A	N/A	N/A	•	•	•	•	•	•	N/A	10-Yr
15/16" or 1-1/2" Square Lay-in		871	24 x 48 x 5/8"	□	0.55	35	N/A Fire Guard	0.78	•	Std	N/A	N/A	N/A	N/A	•	•	•	•	•	•	N/A	10-Yr

4-6 WEEKS
order to ship



¹ Total Acoustics® ceiling panels have an ideal combination of sound absorption and sound blocking in one product. Also see Optima® Health Zone™ and Ultima® Health Zone™ for use in Clean Rooms. * Specify field and border panels together.

SUSPENSION SYSTEMS

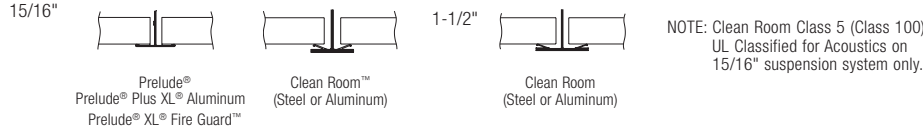

PHYSICAL DATA

Material
Wet-formed mineral fiber

Surface Finish
1715, 1716, 1720, 1721 – Soil-resistant polyester film
868, 870, 869, 871 – Vinyl-faced membrane

Fire Performance
Class A: ASTM E84 and CAN/ULC S102 surface burning characteristics. Flame Spread Index of 25 or less. Smoke Developed Index of 50 or less (UL labeled).
Fire Guard™: A fire-resistive ceiling when used in applicable UL assemblies
ASTM E1264 Classification
1715, 1716, 1720, 1721 – Type IV, Form 2, Pattern G H
868, 870, – Type IV, Form 2, Pattern E
869, 871 – Type IV, Form 2, Pattern C E
Fire Class A

Anti-Mold/Mildew
Ceiling tiles with BioBlock® performance resist the growth of mold and mildew on the tile surface.

Humidity/Sag Resistance
HumiGuard® Plus ceiling panels are recommended for areas subject to high humidity, up to, but not including, standing water and outdoor applications. Excluding items 868 and 870.

VOC Emissions
Third-party certified compliant with California Department of Public Health CDPH/EHLB/Standard Method Version 1.2, 2017. This standard is the guideline for low emissions in LEED®, WELL Building Standard™, Living Building Challenge® (LBC), CalGreen Title 24, ANSI/ASHRAE/USGBC/IES Standard 189; ANSI/GBI Green Building Assessment Protocol.

High Recycled Content
Contains greater than 50% total recycled content. Total recycled content based on product composition of post-consumer and pre-consumer (post-industrial) recycled content per FTC guidelines.

Insulation Value
R Factor – 1.5 (BTU units)
R Factor – 0.26 (Watts units)



Cleaning and Disinfecting
Cleaning and CDC approved disinfecting options available on armstrongceilings.com/cleaning

30-Year Performance Guarantee & Warranty
When installed with Armstrong® Suspension System. Details at armstrongceilings.com/warranty

Weight; Square Feet/Carton
1715 – 1.02 lbs/SF; 48 SF/ctn
1716 – 1.02 lbs/SF; 64 SF/ctn
1720 – 1.04 lbs/SF; 48 SF/ctn
1721 – 1.17 lbs/SF; 64 SF/ctn
868, 869 – 1.10 lbs/SF; 48 SF/ctn
870, 871 – 1.11 lbs/SF; 64 SF/ctn

NOTE: For assistance on proper Clean Room installation, contact TechLine at 1 877 276-7876.

Minimum Order Quantity
1 carton, excludes other size panels

Metric Items Available
1715M, 1716M, 1720M, 1721M, 868M, 870M, 869M, 871M – Metric items are subject to extended lead times and minimum quantities. Contact your representative for more details.

TechLine / 1 877 276-7876
armstrongceilings.com/cleanroom
BPCS-3044-922

LEED® is a trademark of the U.S. Green Building Council; Declare® and Living Building Challenge® (LBC) are trademarks of the International Living Future Institute®; WELL™ and WELL Building Standard are trademarks of the International WELL Building Institute; UL and UL Certified are trademarks of UL LLC; all other trademarks used herein are the property of AWI Licensing LLC and/or its affiliates © 2022 AWI Licensing LLC



MINERAL FIBER – Standard