



71 72 610

Bolt Cutter

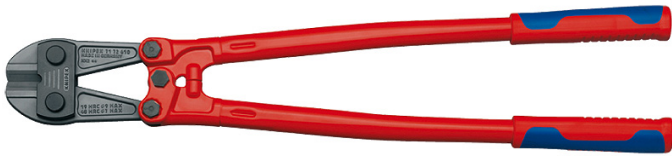

- cutting capacity up to 48 HRC hardness
- robust cutting edges are additionally induction hardened, cutting-edge hardness approx. 62 HRC
- forged-in stopper with comfortable shock-absorber
- good access due to very flat construction of head and joint area
- ergonomically angled handles to minimise effort
- sturdy non-slip two-colour dual component handle sleeves
- precise adjustment (12 positions) by eccentric bolt
- high cutting performance with minimum effort due to optimum co-ordination of the cutting edge angle and transmission ratio
- bolted cutter head, replaceable
- blade: chrome vanadium heavy-duty steel, forged, oil-hardened
- joint: special tool steel, forged
- handles: steel tube, powder-coated

Article No.	71 72 610
EAN	4003773066767
Head	grey atramentized
Handles	with multi-component grips
HRC 19 Ø mm	9
HRC 48 Ø mm	7
HRC 40 Ø mm	8
Cutting edge length mm mm	34
Head thickness mm	33
Length mm	610
Net weight g	2550

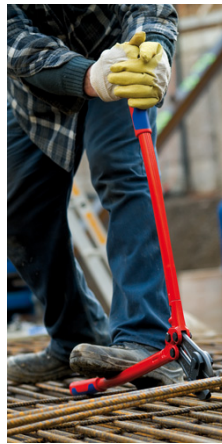

Forged-in stopper with damping inserts: cushions the cutting stroke comfortably



technical change and errors excepted



Spare Parts

Article No.	EAN	
71 79 610	4003773066811	Spare cutter head for 71 72 610 complete with screws