


# 78 13 125 ESD

## Electronic Super Knips® ESD



- precision pliers for ultra fine cutting work, e. g. in electronics and fine mechanics
- electrically discharging handles - dissipative
- ground, very sharp cutting edges without bevel for flush cutting
- precision shaped tips cut wires resting on a board from 0.2 mm dia.
- joint with stainless steel rivet
- extremely smooth movement for minimum operator fatigue
- with opening spring and opening limiter
- INOX - stainless steel
- cutting edge hardness approx. 54 HRC
- with lead catcher - no uncontrolled loss of cut wire ends

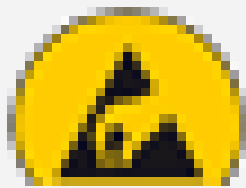



### ESD pliers (electrostatic discharge)

electrostatic energy is discharged through the handles in a gradual and controlled manner

which protects components endangered by electrostatic discharge

in accordance with applicable standards, e.g. IEC TR 61 340-5, DIN EN 61 340-5, SP Method 2472

<b>Article No.</b>	78 13 125 ESD
<b>EAN</b>	4003773025153
<b>Head</b>	polished
<b>Handles</b>	with multi-component grips
<b>Style</b>	1
<b>Pliers</b>	
<b>medium hard wire Ø mm</b>	1,0
<b>soft wire Ø mm</b>	0,2 - 1,6
<b>D mm</b>	7,5
<b>B mm</b>	9,0
<b>A mm</b>	13,5
<b>Length mm</b>	125
<b>Net weight g</b>	57

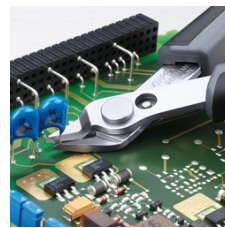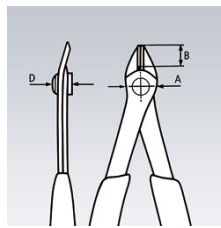

technical change and errors excepted

