



**Pumptrol<sup>®</sup> Pressure Switches,  
Class 9013 Type FRG, Form H**


**Complete Contact Replacement Kit**  
(includes new diaphragm)

**Class 9998 Type PC290**  
All Form H devices


**Important:** The maximum allowable  
pressure rating of this  
switch is **300 psi.**

65013-005-99A

## Wiring Diagram

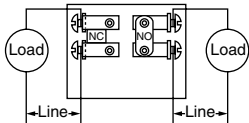

## Adjustments

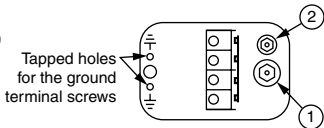

### Adjust in the proper sequence:

1. Turn nut 1 down to raise the low operating point.
2. Turn nut 2 down to raise the high operating point.

**CAUTION:** To avoid damage, do not exceed the maximum allowable pressure. Check the switch operation after resetting.