

# 97 81 180


## Crimping Pliers for end sleeves (ferrules) with front loading



- for crimping end sleeves (ferrules) according to DIN 46228 parts 1 + 4 in the range 0.5 to 6.0 mm<sup>2</sup>
- ideal for work in confined areas, e.g. in narrow and deep switch boxes
- Special tool steel, forged, oil-hardened



<b>Article No.</b>	97 81 180
<b>EAN</b>	4003773019794
<b>Head</b>	polished
<b>Handles</b>	plastic coated
<b>Applications</b>	End Sleeves (ferrules)
<b>Capacity mm<sup>2</sup></b>	0,5 - 6,0
<b>Number of crimping positions</b>	1
<b>AWG</b>	20 - 10
<b>Length mm</b>	180
<b>Net weight g</b>	227

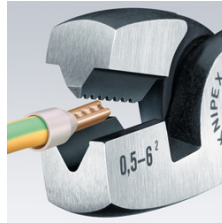

*technical change and errors excepted*

