

The best of both hygiene & efficiency


Vikan® Waterfed System



Harnessing the power of water for hygienic cleaning



Stiff Waterfed Hand Brush

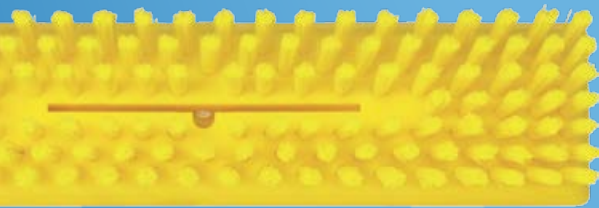

Stiff Waterfed Deck Scrub

The Vikan® waterfed system is FDA-compliant to optimize hygiene when cleaning processing equipment and facilities.

Every product is designed for ease of use and years of dependable performance. Whether spraying dirt and residue off floors, scrubbing walls or cleaning stainless steel tanks, the Vikan waterfed system puts water right at hand for safe, thorough cleaning.



9324x

Water Gun

Apply tension on the rubber insulated trigger to control pressure of water jet. Suitable for cleaning floors and machinery; also can be used for rinsing off work surfaces after chemical foaming.



7056Qx

Stiff Waterfed Hand Brush



Often used for boot washing; water runs through the center of the brush and out through holes in between the bristles. The robust quick connect coupling allows for easy connection of hose using the Vikan coupling system.

Waterfed Handles



2991Q / 2973Q

Used in conjunction with a condensation squeegee or waterfed brush system, these handles allow for comfortable use reaching high walls, ceilings and overhead pipes. They feature a quick connect coupling for easy attachment of a hose or bottle.



7041x / 7043x

Deck Scrubs



Deck scrubs are made of durable polypropylene with polyester bristles. 7041x features extremely stiff bristles while 7043x comes with soft bristles. Vikan deck scrubs are great at cleaning in narrow spaces. 7043x is ideal for cleaning walls.



0703US

Watertight Coupling

This stainless steel watertight coupling is used as part of the complete Vikan waterfed system. Connect a standard hose to any Vikan waterfed product equipped with a quick connect coupling; i.e., handle, water gun, hand brush, or deck scrub.



7067x

Adjustable Angle Brush



This brush features split fiber bristles that absorb liquid to efficiently utilize soapy water. The soft bristles are ideal for sensitive surfaces. The design is excellent for rinsing after foaming.

Controlling water usage with water-tight water control

The Vikan Heavy Duty Water Gun is a game changer. Enabling high quality water distribution within a durable casing, it is able to withstand tough environments and ensure efficient water consumption. Excessive water usage is minimized and allows users to utilize the amount of water required, rather than drenching every surface in sight.

- Hose and couplings can withstand a maximum pressure of 20 Bar and 158°F



Watergun
9324x

Waterfed
Hand Brush
7056Qx

1/2" Male Coupling
0712

Watertight
Coupling
0703US

1/2" Female Coupling
0701

1/2" Hose Clamp
(included with 0701)

1/2" GHT Hose

1/2" Hose Pipe

Vikan® waterfed system



Water Gun

Part no.	Material	Dimensions	Weight
9324	Brass / Stainless Steel / Rubber	7.1 in x 5.7 in x 2.25 in	1.76 lbs.

Waterfed Handles

Part no.	Material	Length	Diameter	Weight
2991	Aluminium, Polypropylene	61.5 in	1.25 in	1.58 lbs.
2991Q	Aluminium, Polypropylene	60.9 in	1.25 in	1.58 lbs.
2973	Aluminium, Polypropylene	63.5 in - 113.75 in	1.25 in	2.26 lbs.
2973Q	Aluminium, Polypropylene	62.9 in - 113.9 in	1.25 in	2.24 lbs.

Watertight Coupling

Part no.	Material	Dimensions	Weight
0703US	Stainless Steel	2 in x 1.12 in	0.26 lbs.

Stiff Waterfed Hand Brush

Part no.	Bristle Type	Bristle Length	Width	Length
7056Q	Stiff	1.1 in	1.8 in	12.5 in

Wide Deck Scrub

Part no.	Bristle Type	Bristle Length	Width	Length
7041	Stiff	0.9 in	3 in	10.75 in
7043	Medium	1.1 in	3 in	10.9 in

Angle-Adjustable Washing Brush

Part no.	Bristle Type	Bristle Length	Width	Length
7067	Soft/Split	1.6 in	2.75 in	9.25 in

Fully updated product specifications are available at Vikan.com.

See waterfed systems online at remcoproducts.com

Available in the U.S. from:

REMCO PRODUCTS CORPORATION

Tel.: (317) 876-9856

Fax: (800) 585-8619

www.remcoproducts.com

sales@remcoproducts.com

8/16 VKN-P112 | Vikan® is a registered trademark of Vikan A/S

