

MASTER[®] APPLIANCE

Designers and Manufacturers of Heat Tools for Industry

MASTERFLOW[®] HEAT BLOWER

A Heavy Duty, Industrial Quality,
Continuous Duty Heat Blower



- Brushless induction type motor for quiet continuous operation
- 3 models produce 300° F/150° C, 500° F/260° C, 750° F/400° C
- High temperatures accomodate many heating, drying & shrinking applications
- High airflow rating, 47 CFM at 2,200 FPM, means jobs get done fast
- Rubber backed stand permits 90° non-slip adjustability. Use in any position or mount on equipment
- Made in the U.S.A.




120 Volt models



Drying Paint



Shrink Tubing

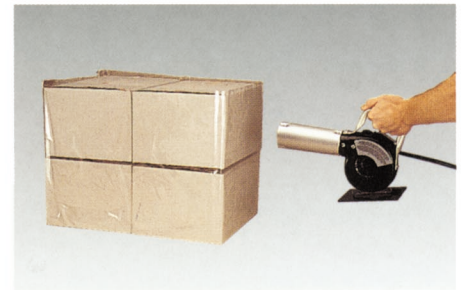

Shrink Packaging

MASTERFLOW HEAT BLOWER

Heavy Duty, Continuous Flow, Portable Heat Blower

High-volume air flow and 24-hour operation is why the Masterflow Heat Blower is the perfect tool for a wide variety of tasks. Its 2" diameter nozzle covers a large area with heated air, to get the job done easier and faster.

The Masterflow Heat Blower is available in three models, at temperatures of 300° F/150° C, 500° F/260° C, and 750° F/400° C. All are fitted on sturdy, rubber-padded adjustable bases which allow 90° rotation for use in any position. The handle is balanced for comfort and convenience during portable applications. The Masterflow Heat Blower can be mounted on walls, workbenches and machines.

Despite its power, the Masterflow is whisper quiet thanks to its brushless induction type motor. It also features a three-way toggle switch with hot, cool and off settings. The cool setting enables the heating element to cool after use, eliminating residual heat.

Safety features include an oil-resistant, grounded cordset and a thermal fuse to protect the heating element from accidental burn-out. An optional, shrink tubing attachment is available for the Masterflow Heat Blower.

SPECIFICATIONS

Size	12" L x 6" W x 9" H, 6" x 6" base (except AH-301 & AH-302, 9" L x 6" W x 9" H)
Weight	6 lbs., shipping weight 8 lbs.
Motor	Induction type
Nozzle	2 5/8" O.D., 1 7/8" air opening
Cord length	6 Ft.
Air velocity	2,200 FPM
Air volume	47 CFM

USES

- Bend and form plastics
- Dry silk screens, inks, circuit boards, parts, etc.
- Melt frost buildup
- Mount over conveyor lines & on machinery
- Shrink packaging

ORDERING INFORMATION

MODEL #	DESCRIPTION	VOLTS	AMPS	WATTS
AH-301	Masterflow Heat Blower 300° F/150° C	120	10.0	1200 (UL & CSA)
AH-302	Masterflow Heat Blower 300° F/150° C	220-240	5.2	1200
AH-501	Masterflow Heat Blower 500° F/260° C	120	14.0	1680 (UL)
AH-501C	Masterflow Heat Blower 500° F/260° C	120	14.0	1680 (CSA)
AH-502	Masterflow Heat Blower 500° F/260° C	220-240	7.3	1680
AH-751	Masterflow Heat Blower 750° F/400° C	120	18.0	2160 (UL)
AH-752	Masterflow Heat Blower 750° F/400° C	220-240	9.4	2160

MASTER[®]
APPLIANCE

Master Appliance Corp.

2420 - 18th St. P.O. Box 68

Racine, WI 53401 U.S.A.

Phone (262) 633-7791 Fax: (262) 633-9745

Email: sales@masterappliance.com

Visit our Web Site at: www.masterappliance.com

Distributed by: