



Industrial Air Circulators-115 Volt


Oscillating/Non-Oscillating

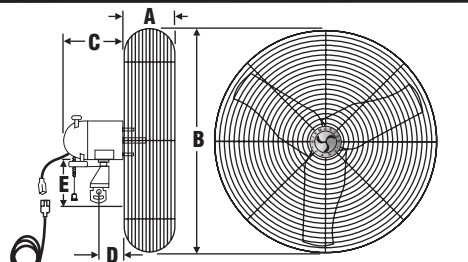

O-3B 3SP Totally Enclosed Oscillating Motor with 15' Three Conductor Cord and Plug

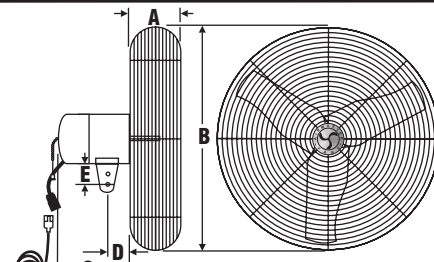

I-3A 3SP Totally Enclosed Non-Oscillating Motor with 15' Three Conductor Cord and Plug

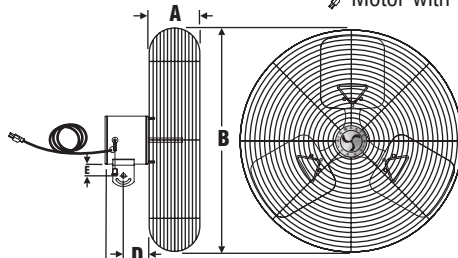


I-1820M 2 SP Open & I-1820TEM Totally Enclosed Non-Oscillating Motor With 10' Cord & Plug




Safety Cable
(Included with overhead mounted fans.)

8CP-2B Pedestal

AMFW30K Wheel Kit
(Solid base only.)

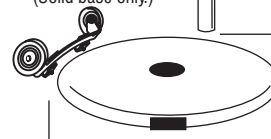


A786B-2 Base

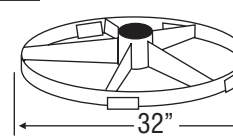


I-2030B Base

FEATURES



- 5 Mounting Options
- Guard Meets OSHA Standards
- 115V, 60 Hz, 1 Phase, 2 Speed (18" & 20") or 3 Speed (24" & 30"), Ball Bearing Motors on Non-Oscillating Models
- 115V, 60 Hz, 1 Phase, 3 Speed, Ball Bearing Motors on Oscillating Models
- Three Conductor Supply Cord and Plug
- 3 Year Warranty
- UL/ CUL Listed
- All Stocked

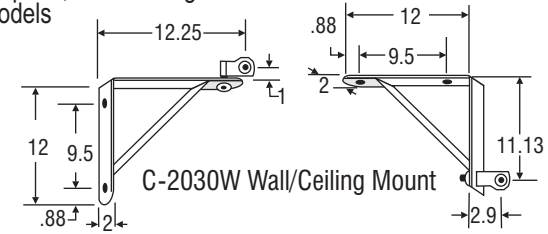

C-2030W Wall/Ceiling Mount

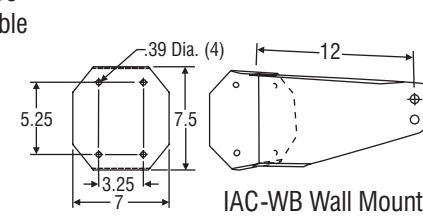

IAC-WB Wall Mount

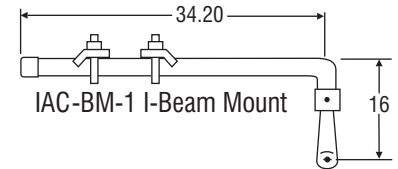 

IAC-BM-1 I-Beam Mount

Model	18" & 20" Fan		24" Fan		30" Fan		C	D	E
	A	B	A	B	A	B			
I-1820M 2 SP Motor	5.75	22.5	-	-	-	-	4.75	2.63	2.58
I-1820TEM 2 SP Motor	5.75	22.5	-	-	-	-	4.75	2.63	2.58
I-3A 3 SP Motor	-	-	6-1/4	26.9	5.25	33.39	9.84	2.95	1.31
O-3B 3 SP Osc. Motor	-	-	6-1/4	26.9	5.25	33.39	11.22	3.15	4.78

FAN NO.	QTY.	MOTOR MODEL NO.	PROPELLER DIAMETER	CFM	RPM	HP	WT.	FAN MOUNT	ACCESSORIES AND REMARKS

Airmaster[®] Fan Company

1300 Falahee Road, Jackson, MI 49203 (517) 764-2300 Fax: (517) 764-3838

www.airmasterfan.com