



THE KING OF SNOW®

YOUR PATH IS CLEAR

A WORD FROM DAN ARIENS

≡ **OUR AMERICAN PATH** ≡

 
When my great-grandfather, Henry Ariens, started building equipment in 1933, he built machines that were designed to be reliable year after year – generation after generation. Today, we remain true to this passion as we engineer machines that tackle the toughest snowfalls and last generations of users.

To date, we have produced more than three million Sno-Thro® machines since we introduced them in 1960. Since then, our passion to be the best has not changed. American craftsmanship. All-steel construction. Superior performance.

During the past 80 years, our teams in Brillion, Wis. have learned a lot about the innovation necessary to continue to make Ariens Sno-Thro lineup The King of Snow. We've learned all-steel construction is essential to long-term durability and performance. We've learned how to pull more snow into our units to handle heavy, wet, chunky, or slushy snow that might slow you down. And, we've pioneered how

to build a gear case that is second to none. These are the factors that contribute to legendary performance, making Ariens The King of Snow.

Many ask with our broad product line, which machine do I prefer? For me, it's the Platinum 24, however, whichever Ariens Sno-Thro you choose, I assure you it will be a part of your family for many years to come. And best of all, you'll have the ability to pass exceptional equipment on to your next generation. **Welcome to the family!**



Dan Ariens
President & CEO



TABLE OF CONTENTS

PERFORMANCE

Every machine in the Ariens Sno-Thro® lineup is engineered to provide long-lasting, unsurpassed performance you can rely on. Choose the machine best suited for your needs and preferences:

pg 08-09



Typical Snowfall: Up to 9"
Use: Residential or Commercial

PATH-PRO SERIES

pg 10-11



Typical Snowfall: Up to 12"
Use: Residential

COMPACT SERIES

pg 12-15



Typical Snowfall: 16" or more
Use: Residential

DELUXE + PLATINUM SERIES

pg 16-19



Typical Snowfall: 16" or more
Use: Heavy Residential / Commercial

PRO + HYDRO PRO SERIES

pg 20-21



Typical Snowfall: 12" or more
Use: Residential/Commercial Sloped or unpaved surface

TRACK SERIES

pg 22-23



Typical Snowfall: Up to 6"
Use: Commercial, clean to surface

POWER BRUSH SERIES



BUILDING AN AMERICAN HEIRLOOM

THE PATH TO EXCELLENCE



Your needs. Your preferences. Our priority. With a rich 80 year heritage of manufacturing products hailed for exceptional performance and unsurpassed American craftsmanship standards, Ariens continues to remain the number one brand Sno-Thro® worldwide.


From materials to technology, many things have changed since the company first began. However, at the heart of the Ariens legacy, one thing has always remained constant — a fusion of passion and pride inherent during every step of manufacturing and distribution. From engineering to production and customer support staff, Ariens employs a workforce of individuals dedicated to quality. Rather than meet expectations, we strive to exceed them. Every Ariens product comes backed by industry-leading warranties supported by an extensive dealer network so you can rest assured you've made a smart investment.

By listening to generations of loyal customers and understanding how our products are used, Ariens continues to evolve with high-quality products designed to meet the changing demands of today's consumers. So no matter what snow covered challenge lies ahead, the solution is simple and the path is clear, you can always rely on Ariens — the King of Snow®!



QUALITY DEFINED

Dependable. Long-lasting. Legendary. No matter what snow covered challenge lies ahead, rest assured your path is always clear with an Ariens Deluxe Sno-Thro®.

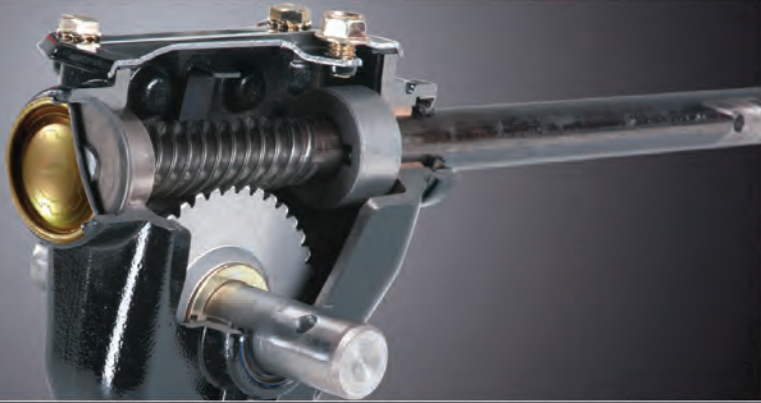

The Heart of a Legend. Unique to the Ariens Sno-Thro lineup, the Ariens cast iron gear case creates the industry's fastest auger ratio to ensure you move more snow in less time. Featuring alloy steel gears and synthetic gear oil, it's engineered to withstand years of rugged use contributing to Ariens enduring legacy of exceptional performance and unsurpassed American Craftsmanship.



Durable by Design. The Ariens Deluxe 2-stage Sno-Thro has a high angle discharge chute capable of throwing snow up to 50 feet away. And because it's all-steel, the chute is able to handle whatever winter has to offer from chunks of hard snow and ice to other debris that a plastic chute cannot.



Efficiency is Essential. Featuring the largest intake tunnel and freeze-resistant impeller in its class, the Ariens Deluxe throws 30% more snow than the competition for quick, efficient snow removal.



Engineered to Excel. Complete with the largest-in-class, 14" diameter, fully welded steel serrated augers and the largest shear bolts available for long-term durability and relentless snow throwing capability.



Power to Overcome the Elements. With a longer belt life than the competition and the only dual belt drive system in its class, the Ariens Deluxe is able to sustain power indefinitely without the need for adjustments.



PASSIONATELY BUILT IN
BRILLION, USA

Exceptional durability. Reliable performance. Unsurpassed results. Backed by industry-leading warranties, Ariens Sno-Thro® lineup offers a wide range of snow removal solutions engineered to suit the diverse needs of today's consumers.



Every Ariens Sno-Thro is engineered to be rugged and reliable with emphasis on the highest American Craftsmanship standards to ensure years of legendary performance.

Time tested. Generation approved. For performance, durability, and power you'll be proud to pass on to the next generation — choose Ariens, the number one brand Sno-Thro worldwide.

Built to last from the handlebars to the housing, every Ariens 2-stage Sno-Thro features all-steel construction so you can overcome winter's relentless conditions for years to come.

Backed by an industry-leading 5-year warranty, the Ariens commercial-duty cast iron gear case is a remarkably engineered component unique to Ariens Sno-Thro lineup.

Unsurpassed design. Unrivaled guarantees. Every Ariens product comes backed by a 3-year warranty supported by an extensive independent dealer network.

MAKING THE VERY BEST SNO-THRO ***PATH OF PRECISION***

Sophisticated engineering tools, thorough testing and regimented processes have their place in Sno-Thro® design and development, but nothing can replace the value of a dynamic engineering organization. Ariens is proud to employ an outstanding team of accomplished engineers that utilize years of experience to build, shape and refine contemporary Ariens products.

Building first-class snow removal equipment year after year is no accident. The knowledge, unique vision and hands-on approach our engineers and designers take to collaborate together and effectively translate customer interests into industry-leading products are essential aspects of Ariens product development. Tailored high-strength steel, automotive inspired leak-proof gear drives, performance tuned drivelines and impeccable engine winterization are trademarks of the Ariens Sno-Thro brand. An insatiable passion for perfection, attention to detail and pursuit of knowledge are pillars of our engineering culture. This is what elevates Ariens to be The King of Snow.



PATH-PRO® SINGLE STAGE

Trademark durability and robust design characteristics are just the beginning. Lightweight, compact, easy to maneuver, transport and store, the Ariens Path-Pro provides quick, efficient snow removal for up to 9" of accumulation. If you desire exceptional power and performance in a small package you can depend on, look no further than the Ariens Path-Pro.

3 COLD
YEAR START
PROMISE
TESTED TO -24 DEGREES FAHRENHEIT



ARIENS AX ENGINE

Robust engine options provide superior power regardless of the elements with electric start available for rapid, no fuss start-up.



MODEL OVERVIEW

MODEL	ARIENS PATH-PRO™ 21	ARIENS PATH-PRO™ 21	ARIENS PATH-PRO™ 21	ARIENS PATH-PRO™ 21	ARIENS PATH-PRO™ 21
ENGINE	ARIENS AX136	ARIENS AX136	ARIENS AX208	ARIENS AX208	ARIENS AX208
ENGINE POWER	7 FT-LBS (136CC)	7 FT-LBS (136CC)	9.5 FT-LBS (208CC)	9.5 FT-LBS (208CC)	9.5 FT-LBS (208CC)
STARTING SYSTEM	RECOIL	120V/RECOIL	RECOIL	120V/RECOIL	120V/RECOIL
CHUTE CONTROL	MANUAL	MANUAL	MANUAL	MANUAL	REMOTE

➔ Enhanced or step-up feature



FOLDING ERGO HANDLEBAR

Large diameter, folding handlebars provide strength, operator comfort, and easy storage.



SEMI-PNEUMATIC WHEELS

Designed for strength and durability, large impact-absorbent wheels move through snow with ease.



MAINTENANCE FRIENDLY

Cowl design provides unrestricted access to engine controls and service points including the spark plug and oil drain for easy routine maintenance.



REMOTE CHUTE ROTATION

Throw snow exactly where you want it by simply moving the control forward and backward to direct the chute right or left. *(Available on 938033)*




HOUSING & PADDLE

Steel-walled housing shears through packed snow and drifts effortlessly. Comes complete with reinforced rubber paddles and an adjustable scraper bar that clears snow down to the surface while propelling the unit forward.

COMPACT

A lightweight machine engineered to provide heavy-duty results, the Ariens Compact Sno-Thro® is robust and dependable so you can take on harsh winter conditions all season long. Durable from the dash panel to the housing, it comes complete with folding handlebars for easy storage. Exceptional results along with unsurpassed performance and design make the Ariens Compact an ideal snow removal solution for up to 12-inches of average snowfall.

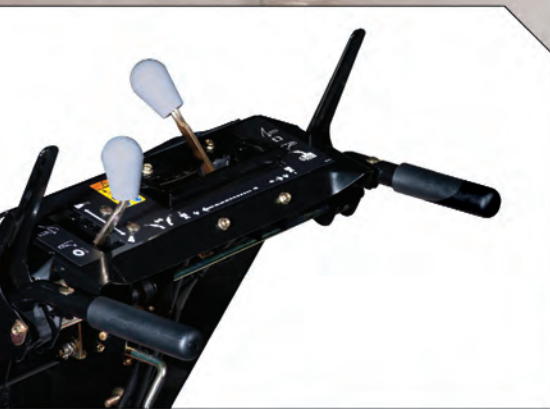

ALL-STEEL DASH PANEL

All controls are easy to reach and use.



	MODEL OVERVIEW	
MODEL	COMPACT 22	COMPACT 24
ENGINE	ARIENS AX208	ARIENS AX208
ENGINE POWER	9.5 FT-LBS (208CC)	9.5 FT-LBS (208CC)
HOUSING	22" WIDTH, 20" HEIGHT	24" WIDTH, 20" HEIGHT
CHUTE DEFLECTION	MANUAL	REMOTE

➔ Enhanced or step-up feature



FOLDING HANDLEBARS

Tubular steel handlebars fold down for convenient storage during the off-season.



STEEL CHUTE

All-steel chute withstands the elements while throwing snow up to 40 feet with streamlined accuracy.



POWERFUL IN-DASH HEADLIGHT

Bright, powerful light illuminates the clearing path in adverse conditions while making the operator more visible to others for safety.



TOP LOAD CAST IRON GEAR CASE

Rugged and reliable, the Ariens commercial-duty cast iron gear case comes complete with alloy steel gears, synthetic gear oil, and an industry-leading 5-year warranty.

DELUXE

Don't let Mother Nature's winter fury slow you down. From light accumulation to dense, heavy snow, the Ariens Deluxe empowers you to clear your path through 16" of snow with a maximum throwing distance of 50 feet. Featuring a large 14-inch, 3-blade high-speed impeller, you'll throw more snow in less time so you can get back to what matters.

AUTO-TURN™

Snow removal has never been easier. Straining yourself to maneuver a big, heavy machine or fumbling with triggers is now a thing of the past. Experience the maximum control, precise turning capabilities and smooth operation of an Ariens Sno-Thro® equipped with Auto-Turn technology. Turn when and where you want with ultimate traction because Auto-Turn is just that — automatic!



MODEL OVERVIEW				
MODEL	DELUXE 24	DELUXE 28	DELUXE 28	DELUXE 30
ENGINE	ARIENS AX254	ARIENS AX254	ARIENS AX291	ARIENS AX306
ENGINE POWER	12.5 FT-LBS (254CC)	12.5 FT-LBS (254CC)	14.5 FT-LBS (291CC)	15 FT-LBS (306CC)
HOUSING	24" WIDTH, 21" HEIGHT	28" WIDTH, 21" HEIGHT	28" WIDTH, 21" HEIGHT	30" WIDTH, 21" HEIGHT
STEERING	AUTO-TURN™	AUTO-TURN™	AUTO-TURN™	AUTO-TURN™

➔ Enhanced or step-up feature




14" IMPELLER

Throw snow fast and far with the largest-in-class, freeze-resistant, 14-inch, 3-blade, high-speed impeller.




DUAL BELT AUGER DRIVE

Enjoy the benefit of superior power and maintenance-free operation with Ariens exclusive dual belt drive system.

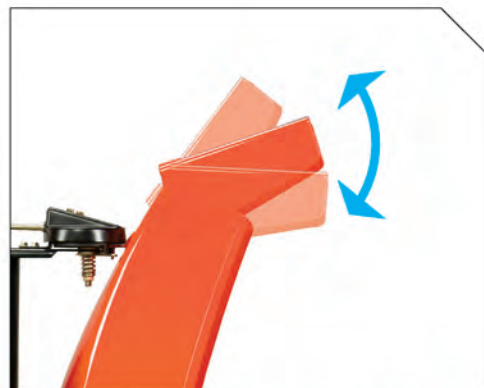

REMOTE CHUTE DEFLECTOR AND ROTATION CONTROL

Adjust the height and direction of the plume to throw snow exactly where you want it with convenient, easy-to-use controls.

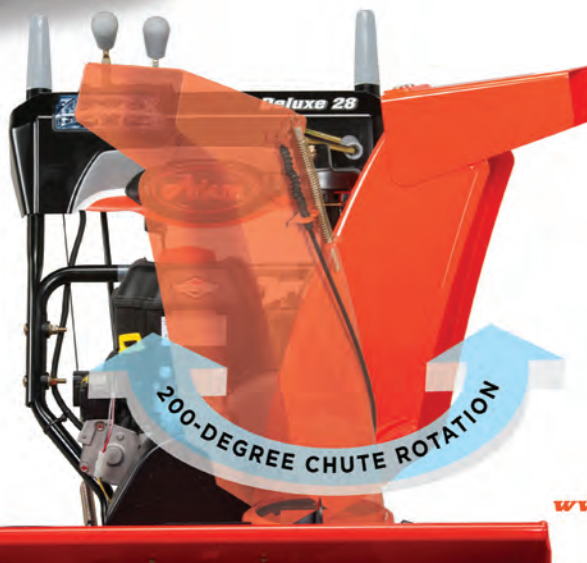

PLATINUM + PLATINUM SHO

Clear your path and enjoy the journey. State-of-the-art features including Auto-Turn™ steering technology, Quick Turn chute rotation, and handwarmers take snow removal to a level of unmatched comfort and ease with the Ariens Platinum & Platinum SHO series. For a smart investment you can pass on to the next generation, look no further than Ariens, The King of Snow!

3 COLD
YEAR START
PROMISE
TESTED TO -20 DEGREES FAHRENHEIT




ARIENS AX ENGINE

Featuring a low profile design, 2-position throttle system, and low tone muffler for quiet engine operation, Ariens AX engines come supported by a 3-year Cold Start Promise.

MODEL OVERVIEW

MODEL	PLATINUM 24 SHO	PLATINUM 30	PLATINUM 30 SHO
ENGINE	ARIENS AX306	ARIENS AX369	ARIENS AX414
ENGINE POWER	15 FT-LBS (306CC)	17 FT-LBS (369CC)	20 FT-LBS (414CC)
HOUSING	24" WIDTH, 21" HEIGHT	30" WIDTH, 21" HEIGHT	30" WIDTH, 21" HEIGHT
IMPELLER	SUPER HIGH OUTPUT STEEL 3-BLADE	STEEL 3-BLADE	SUPER HIGH OUTPUT STEEL 3-BLADE

 Enhanced or step-up feature



POWERFUL IN-DASH HEADLIGHT

Bright, powerful light illuminates the clearing path in adverse conditions while making the operator more visible to others for safety.



HANDWARMERS

Keep hands cozy despite harsh winter conditions with dash-controlled handwarmers.



ALL-STEEL DASH PANEL

Easy-to-use dash panel and controls are built to last.



SUPER HIGH OUTPUT IMPELLER

The Super High Output, 14" 3-blade, high-speed impeller has improved belts and sheave for increased snow throwing distance.



QUICK TURN CHUTE

Place snow exactly where you want it with a dash-mounted chute control that rotates 200 degrees left and right.


PROFESSIONAL

Powerful performance is an understatement. No other machine can match the dependability and functionality of the Professional Sno-Thro®. It's built large to put you in complete charge of the most intimidating snow from deep drifts to thick, snowplow packed driveways.



MODEL OVERVIEW

	PROFESSIONAL 28	PROFESSIONAL 32
MODEL	PROFESSIONAL 28	PROFESSIONAL 32
ENGINE	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®
ENGINE POWER	21 FT-LBS (420CC)	21 FT-LBS (420CC)
HOUSING	28" WIDTH, 23.5" HEIGHT	32" WIDTH, 23.5" HEIGHT
STARTING SYSTEM	120V/RECOIL	120V/RECOIL

 Enhanced or step-up feature



DRIFT CUTTERS

Effortlessly shear through packed snow and drifts no matter how high or compact with Ariens drift cutters.



SKID SHOES

Commercial-duty, 1/2" thick steel skid shoes and a boron steel scraper bar provide consistent performance and long life.



TOP LOAD CAST IRON GEAR CASE

Rugged and reliable, the Ariens commercial-duty cast iron gear case comes complete with alloy steel gears, synthetic gear oil, and an industry-leading 5-year warranty.



**CERTIFIED
TO START
DOWN TO 20°
BELOW ZERO**



ARIENS POLAR FORCE PRO ENGINE BY BRIGGS & STRATTON®

Featuring easy 1-2-3 start, a crankshaft balancing system, a Durabore cast iron cylinder sleeve and forged crankshaft, the Ariens 420cc, 21ft/lb engine is engineered to exceed expectations.

ARIENS HOUSING

Rugged and relentless, Ariens all-steel housing provides unsurpassed durability to withstand years of use. From heavy snowfall, to slush, ice and other debris, the Ariens Professional Sno-Thro is prepared to handle whatever Mother Nature has to offer. Featuring a 23.5" tall housing unit, 16" steel serrated augers and your choice of a 28 or 32-inch clearing path, you'll have the means to make easy work of any job.

HYDRO PRO

Clear your path for years to come with an Ariens Hydro Pro Sno-Thro® featuring a unique hydrostatic drive system that's maintenance-free with a robust design for long life and durability. Complete with synthetic oil, no wearable components, and an enhanced thermal management system, the Ariens Hydro Pro series is engineered strong to last long with infinitely variable speed selection that makes it easy to operate.



MODEL OVERVIEW

	HYDRO PRO 28	HYDRO PRO 32	HYDRO PRO 36
MODEL	HYDRO PRO 28	HYDRO PRO 32	HYDRO PRO 36
ENGINE	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®
ENGINE POWER	21 FT-LBS (420CC)	21 FT-LBS (420CC)	21 FT-LBS (420CC)
HOUSING	120V/RECOIL	12V KEYSTART	120V/RECOIL
STARTING SYSTEM	28" WIDTH, 23.5" HEIGHT	32" WIDTH, 23.5" HEIGHT	36" WIDTH, 23.5" HEIGHT

➔ Enhanced or step-up feature



INFINITE SPEED CONTROL

Harness the ability to slow down or speed up in small increments to suit your needs and preferences.



HYDRO RELEASE VALVE

Conveniently located release valve allows the operator to disengage the hydro drive for easy transport.



TOP LOAD CAST IRON GEAR CASE

Rugged and reliable, the Ariens commercial-duty cast iron gear case comes complete with alloy steel gears, synthetic gear oil, and an industry-leading 5-year warranty.



SKID SHOES

Commercial-duty, ½" thick steel skid shoes and a boron steel scraper bar provide consistent performance and long life.

HYDRO-GEAR® COMMERCIAL

MAINTENANCE-FREE

Created specifically for Ariens in partnership with Hydro-Gear®, the Ariens Hydro Pro boasts a hydrostatic transmission. Complete with synthetic oil, no wearable components, and an advanced thermal management system for maintenance-free operation.



TRACK


Breeze through winter's worst conditions like never before. Through hard-packed snow drifts, up or down steep driveways, and across slippery paths, nothing provides the traction, power, and performance to overcome the elements like an Ariens Track Sno-Thro®.



MODEL OVERVIEW

MODEL	COMPACT TRACK 24	DELUXE TRACK 28	PRO TRACK 28	HYDRO PRO TRACK 28	HYDRO PRO TRACK 32
ENGINE	ARIENS AX208	ARIENS AX254	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®	ARIENS POLAR FORCE PRO BY BRIGGS & STRATTON®
ENGINE POWER	9.5 FT-LBS (208CC)	12.5 FT-LBS (254CC)	21 FT-LBS (420CC)	21 FT-LBS (420CC)	21 FT-LBS (420CC)
HOUSING	24" WIDTH, 20" HEIGHT	28" WIDTH, 21" HEIGHT	28" WIDTH, 23.5" HEIGHT	28" WIDTH, 23.5" HEIGHT	32" WIDTH, 23.5" HEIGHT
STEERING	SOLID LOCKED	SOLID LOCKED	AUTO-TURN	AUTO-TURN	AUTO-TURN
STARTING SYSTEM	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	12V KEYSTART
DRIVE TYPE	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	HYDROSTATIC	HYDROSTATIC

Enhanced or step-up feature

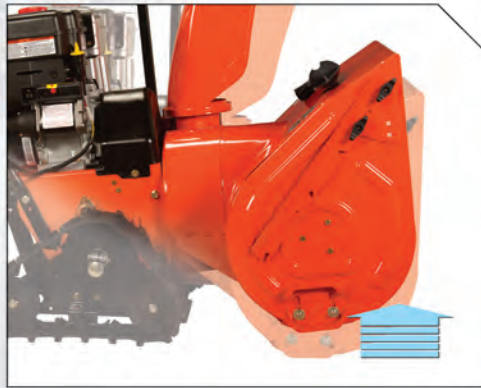

FINGERTIP HEIGHT CONTROL

Select one of five height positions to lift the housing over grass and gravel or lower it to dig into packed snow and ice.



TOP-LOAD CAST IRON GEAR CASE

Rugged and reliable, the Ariens commercial-duty cast iron gear case comes complete with alloy steel gears, synthetic gear oil, and an industry-leading 5-year warranty.



AUTO TURN™

Snow removal has never been easier. Straining yourself to maneuver a big, heavy machine or fumbling with triggers is now a thing of the past. Experience the maximum control, precise turning capabilities, and smooth operation of an Ariens Sno-Thro® equipped with Auto-Turn technology. Turn when and where you want with ultimate traction because Auto-Turn is just that — automatic! (Available on model numbers 926042, 926056 and 926514.)



5.5-INCH DIRECTIONAL SNOW TRACK SYSTEM

Prevail over varying terrain from steep hills to slippery paths and everything in between with a rugged, 5.5-inch directional track system.

POWER BRUSH

Harness the power and versatility of an Ariens Power Brush. From snow to slush, sand, dirt, leaves, and even gravel, this multi-functional, all-season machine cleans down to the surface decreasing environment impact and reducing labor costs. Built with the same outstanding American craftsmanship standards as an Ariens Sno-Thro[®], you can feel confident knowing your power brush will provide legendary performance long into the future.



	MODEL OVERVIEW		
MODEL	POWER BRUSH 28	POWER BRUSH 36	HYDRO BRUSH 36
ENGINE	SUBARU EX17	➡ SUBARU EX27	➡ SUBARU EX30
ENGINE POWER	169CC	➡ 265CC	➡ 287CC
CLEARING WIDTH	28 INCH	➡ 36 INCH	➡ 36 INCH
STEERING	AUTOMATIC TRACTION CONTROL	AUTOMATIC TRACTION CONTROL	AUTOMATIC TRACTION CONTROL
DRIVE TYPE	DISC-O-MATIC	DISC-O-MATIC	➡ HYDROSTATIC
STARTING SYSTEM	120V/RECOIL	120V/RECOIL	12V KEYSTART

➡ Enhanced or step-up feature




ALL-SEASON USE

Dethatch the lawn, clear decorative surfaces of snow, slush, gravel and other debris. Use it during any season, for any reason.



BRUSH ANGLE REMOTE CONTROL

40-degree brush head rotation and an operator controlled pivot lock make it quick and easy to change the brush direction.

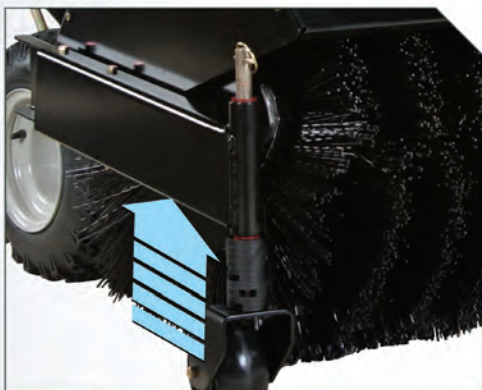

HEIGHT ADJUSTMENT SYSTEM

Raise or lower the brush head to accommodate varying surfaces and reduce brush wear.



CLEAN TO PAVEMENT

Eliminate the need to salt walkways while decreasing your environmental impact to meet green initiatives.



SPECIFICATIONS

	COMPACT 22	COMPACT 24	COMPACT TRACK 24	DELUXE 24	DELUXE 28	DELUXE 28+
MODEL #	920013	920021	920022	921024	921030	921037
STAGE TYPE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE
ENGINE POWER*	9.5 FT-LB (208CC)	9.5 FT-LB (208CC)	9.5 FT-LB (208CC)	12.5 FT-LB (254CC)	12.5 FT-LB (254CC)	14.5 FT-LB (291CC)
ENGINE BRAND	ARIENS AX	ARIENS AX	ARIENS AX	ARIENS AX	ARIENS AX	ARIENS AX
STARTING SYSTEM	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL
CLEARING WIDTH	22 IN (55.9 CM)	24 IN (60.1 CM)	24 IN (60.1 CM)	24 IN (60.1 CM)	28 IN (71.2 CM)	28 IN (71.2 CM)
HOUSING HEIGHT	20 IN (50.8 CM)	20 IN (50.8 CM)	20 IN (50.8 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)
THROWING DISTANCE	3 FT - 40 FT (9-12.2 M)	3 FT - 40 FT (9-12.2 M)	3 FT - 40 FT (9-12.2 M)	3 FT - 50 FT (9 - 15.2 M)	3 FT - 50 FT (9 - 15.2 M)	3 FT - 50 FT (9 - 15.2 M)
CHUTE ROTATION	2.5X QUICK TURN	2.5X QUICK TURN	2.5X QUICK TURN	2.5X ICE DRILL	2.5X ICE DRILL	2.5X ICE DRILL
DEFLECTOR CONTROL	MANUAL	REMOTE	REMOTE	REMOTE	REMOTE	REMOTE
TIRE SIZE	13 IN X 4 IN (33 X 10 CM)	15 IN X 5 IN (38 X 13 CM)	5.5" WIDE TRACK	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 4.8 IN (41 X 12 CM)
TIRE TYPE	POLAR TRAC	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TRACK	POLAR TRAC	POLAR TRAC	DIRECTIONAL SNOW TREAD
STEERING	PIN LOCK	PIN LOCK	SOLID LOCKED	AUTO-TURN	AUTO-TURN	AUTO-TURN
FUEL TANK CAPACITY	2.9QT (2.7L)	2.9QT (2.7L)	2.9QT (2.7L)	2.9QT (2.7L)	2.9QT (2.7L)	3.8QT (3.6L)
DRIVE TYPE	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC
SPEEDS	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE
GEAR CASE	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON
GEAR CASE WARRANTY	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL
IMPELLER PROFILE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE
IMPELLER DIAMETER	12 IN (30.5 CM)	12 IN (30.5 CM)	12 IN (30.5 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)
AUGER DIAMETER	11 IN (27.9 CM)	11 IN (27.9 CM)	11 IN (27.9 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)
AUGER TYPE	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED
SKID SHOES	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE
SCRAPER BAR	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE
PRODUCT WARRANTY	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM
FEATURES AT A GLANCE						
HALOGEN HEADLIGHT	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
HANDWARMERS	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL
REMOTE DEFLECTOR	•	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
ELECTRIC START	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
DRIFT CUTTERS	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL
TRACK DRIVE	•	•	STANDARD	OPTIONAL	OPTIONAL	OPTIONAL
ONE HAND INTERLOCK	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
DIMENSIONS						
LENGTH	51.9 IN (131.8 CM)	50.8 IN (129 CM)	51.9 IN (131.8 CM)	57.91 IN (147.1 CM)	57.91 IN (147.1 CM)	57.91 IN (147.1 CM)
WIDTH	24.4 IN (62 CM)	26.4 IN (67 CM)	26.4 IN (67 CM)	26.4 IN (67 CM)	30.4 IN (77.2 CM)	30.4 IN (77.2 CM)
HEIGHT	44.3 IN (112.5 CM)	45.4 IN (115.3 CM)	42.6 IN (108 CM)	44.25 IN (112.4CM)	44.25 IN (112.4CM)	44.25 IN (112.4CM)
WEIGHT	179 LB (81.2 KG)	187 LB (84.8 KG)	218 LB (98.9 KG)	235 LB (106.6 KG)	241 LB (109.3 KG)	241 LB (109.3 KG)

* Engine output stated in gross torque per SAEJ1940 as rated by engine manufacturer

ACCESSORIES & ATTACHMENTS

For a complete listing of compatible accessories and attachments, visit your local Ariens dealer or go to: www.ariens.com



Tire Chains

Featuring superior two-link spaced cross chains, Ariens Sno-Thro tire chains provide added traction on hills, ice, and hard-packed snow.



DELUXE 30	DELUXE TRACK 28	PLATINUM 24 SHO	PLATINUM 30	PLATINUM 30 SHO	PROFESSIONAL 28	PROFESSIONAL 32
921032	921023	921038	921029	921040	926038	926039
TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE
15 FT-LB (306CC)	12.5 FT-LB (254CC)	15 FT-LB (306CC)	17 FT-LB (369CC)	20 FT-LB (414CC)	21 FT-LB (420CC)	21 FT-LB (420CC)
ARIENS AX	ARIENS AX	ARIENS AX	ARIENS AX	ARIENS AX	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON
120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL	120V/RECOIL
30 IN (76.2 CM)	28 IN (71.2 CM)	24 IN (60.1 CM)	30 IN (76.2 CM)	30 IN (76.2 CM)	28 IN (71.2 CM)	32 IN (81.3 CM)
21 IN (53.3 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)
3 FT - 50 FT (.9 - 15.2 M)	3 FT - 50 FT (.9 - 15.2 M)	3 FT - 55 FT (.9 - 16.76 M)	3 FT - 50 FT (.9 - 15.2 M)	3 FT - 55 FT (.9 - 16.76 M)	3 FT - 60 FT (.9 - 18.28 M)	3 FT - 60 FT (.9 - 18.28 M)
2.5X ICE DRILL	2.5X ICE DRILL	QUICK TURN	QUICK TURN	QUICK TURN	QUICK TURN	QUICK TURN
REMOTE	REMOTE	REMOTE	REMOTE	REMOTE	REMOTE	REMOTE
16 IN X 4.8 IN (41 X 12 CM)	5.5" WIDE TRACK	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 6.5 IN (41 X 17 CM)
DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TRACK	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD
AUTO-TURN	SOLID LOCKED	AUTO-TURN	AUTO-TURN	AUTO-TURN	AUTO-TURN	AUTO-TURN
3.2QT (3.0L)	2.9QT (2.7L)	3.2QT (3.0L)	3.2QT (3.0L)	3.2QT (3.0L)	5.9QT (5.6L)	5.9QT (5.6L)
DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC	DISC-O-MATIC
6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE	6 FORWARD/ 2 REVERSE
CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON
5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL	5YR CONSUMER / 1YR COMMERCIAL
STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE
14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)
14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	16 IN (40.6 CM)	16 IN (40.6 CM)
STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED
STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	STEEL REVERSIBLE	COMMERCIAL SKIDS	COMMERCIAL SKIDS
STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE
3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM
STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
OPTIONAL	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	STANDARD	STANDARD
OPTIONAL	STANDARD	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL	OPTIONAL
STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
57.91 IN (147.1 CM)	57.9 IN (147.1 CM)	57.91 IN (147.1 CM)	57.91 IN (147.1 CM)	57.91 IN (147.1 CM)	61.5 IN (156 CM)	61.5 IN (156 CM)
32.4 IN (82.3 CM)	30.4 IN (77.2 CM)	26.4 IN (67.1 CM)	32.4 IN (82.3 CM)	32.4 IN (82.3 CM)	30.5 IN (77.5 CM)	34.5 IN (87.6 CM)
44.25 IN (112.4 CM)	44.2 IN (112.4 CM)	44.25 IN (112.4 CM)	44.25 IN (112.4 CM)	44.25 IN (112.4 CM)	45 IN (114.3 CM)	45 IN (114.3 CM)
259 LB (117.5 KG)	262 LB (118.8 KG)	254 LB (115.2 KG)	274 LB (124.3 KG)	274 LB (124.3 KG)	307 LB (139 KG)	314 LB (142 KG)

Floor Mat

Ariens heavy-duty floor mats collect water from melting snow while providing a protective layer between the Sno-Thro and floor surface during storage.



Sno-Thro® Cab

Ariens Sno-Thro cab has a spacious, rugged steel frame, durable fabric, and freeze resistant windows to protect against heavy snow, wind, and snow blow back conditions.



Maintenance Kit

Keep your Ariens powering through winter with routine maintenance.

SPECIFICATIONS

	PROFESSIONAL TRACK 28	HYDRO PRO 28	HYDRO PRO 32	HYDRO PRO 36	HYDRO PRO TRACK 28	HYDRO PRO TRACK 32
MODEL #	926042	926053	926517	926055	926056	926514
STAGE TYPE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE	TWO STAGE
ENGINE POWER*	21 FT-LB (420CC)	21 FT-LB (420CC)	21 FT-LB (420CC)	21 FT-LB (420CC)	21 FT-LB (420CC)	21 FT-LB (420CC)
ENGINE BRAND	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON	ARIENS POLAR FORCE BY BRIGGS & STRATTON
STARTING SYSTEM	120V/RECOIL	120V/RECOIL	12V KEYSTART	120V/RECOIL	120V/RECOIL	12V KEYSTART
CLEARING WIDTH	28 IN (71.2 CM)	28 IN (71.2 CM)	32 IN (81.3 CM)	36 IN (91.4 CM)	28 IN (71.2 CM)	32 IN (81.3 CM)
HOUSING HEIGHT	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)	23.5 IN (59.7 CM)
THROWING DISTANCE	3 FT - 60 FT. (.9 - 18.28 M)	3 FT - 60 FT. (.9 - 18.28 M)	3 FT - 60 FT. (.9 - 18.28 M)	3 FT - 60 FT. (.9 - 18.28 M)	3 FT - 60 FT. (.9 - 18.28 M)	3 FT - 60 FT. (.9 - 18.28 M)
CHUTE ROTATION	QUICK TURN	QUICK TURN	QUICK TURN	QUICK TURN	QUICK TURN	QUICK TURN
DEFLECTOR CONTROL	REMOTE	REMOTE	REMOTE	REMOTE	REMOTE	REMOTE
TIRE SIZE	5.5" WIDE TRACK	16 IN X 4.8 IN (41 X 12 CM)	16 IN X 6.5 IN (41 X 17 CM)	16 IN X 6.5 IN (41 X 17 CM)	5.5" WIDE TRACK	5.5" WIDE TRACK
TIRE TYPE	DIRECTIONAL SNOW TRACK	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TRACK	DIRECTIONAL SNOW TRACK
STEERING	AUTO-TURN	AUTO-TURN	AUTO-TURN	AUTO-TURN	AUTO-TURN	AUTO-TURN
FUEL TANK CAPACITY	5.9QT (5.6L)	5.9QT (5.6L)	5.9QT (5.6L)	5.9QT (5.6L)	5.9QT (5.6L)	5.9QT (5.6L)
DRIVE TYPE	DISC-O-MATIC	HYDROSTATIC	HYDROSTATIC	HYDROSTATIC	HYDROSTATIC	HYDROSTATIC
SPEEDS	6 FORWARD/ 2 REVERSE	VARIABLE	VARIABLE	VARIABLE	VARIABLE	VARIABLE
GEAR CASE	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON	CAST IRON
GEAR CASE WARRANTY	5YR CONSUMER/ 5YR COMMERCIAL	5YR CONSUMER/ 5YR COMMERCIAL	5YR CONSUMER/ 5YR COMMERCIAL	5YR CONSUMER/ 5YR COMMERCIAL	5YR CONSUMER/ 5YR COMMERCIAL	5YR CONSUMER/ 5YR COMMERCIAL
IMPELLER PROFILE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE	STEEL 3 BLADE
IMPELLER DIAMETER	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)	14 IN (35.6 CM)
AUGER DIAMETER	16 IN (40.6 CM)	16 IN (40.6 CM)	16 IN (40.6 CM)	16 IN (40.6 CM)	16 IN (40.6 CM)	16 IN (40.6 CM)
AUGER TYPE	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED	STEEL SERRATED
SKID SHOES	COMMERCIAL SKIDS	COMMERCIAL SKIDS	COMMERCIAL SKIDS	COMMERCIAL SKIDS	COMMERCIAL SKIDS	COMMERCIAL SKIDS
SCRAPER BAR	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE	STEEL ADJUSTABLE
PRODUCT WARRANTY	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM
FEATURES AT A GLANCE						
HALOGEN HEADLIGHT	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
HANDWARMERS	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
REMOTE DEFLECTOR	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
ELECTRIC START	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
DRIFT CUTTERS	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
TRACK DRIVE	STANDARD	•	•	•	STANDARD	STANDARD
ONE HAND INTERLOCK	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
DIMENSIONS						
LENGTH	61.5 IN (156 CM)	61.5 IN (156 CM)	61.5 IN (156 CM)	61.5 IN (156 CM)	61.5 IN (156 CM)	61.5 IN (156 CM)
WIDTH	30.5 IN (77.5 CM)	30.5 IN (77.5 CM)	34.5 IN (87.6 CM)	38.5 IN (97.8 CM)	30.5 IN (77.5 CM)	34.5 IN (87.6 CM)
HEIGHT	45 IN (114.3 CM)	45 IN (114.3 CM)	45 IN (114.3 CM)	45 IN (114.3 CM)	45 IN (114.3 CM)	45 IN (114.3 CM)
WEIGHT	333 LB (151 CM)	316 LB (143.3 KG)	314 LB (142 KG)	327 LB (148.3 KG)	343 LB (155.6 KG)	379.4 LB (172.1 KG)

* Engine output stated in gross torque per SAEJ1940 as rated by engine manufacturer.

ACCESSORIES & ATTACHMENTS

For a complete listing of compatible accessories and attachments, visit your local Ariens dealer or go to: www.ariens.com



Sno-Thro® Cover

Perfect for in-between snow or off-season storage, the Ariens Sno-Thro Cover is water repellent and tear-resistant for long-lasting protection.



ARIENS PATH-PRO	ARIENS PATH PRO	ARIENS PATH PRO	POWER BRUSH 28	POWER BRUSH 36	HYDRO BRUSH 36
938030 / 938034	938031 / 938032	938033	921025	926057	926515
SINGLE-STAGE	SINGLE-STAGE	SINGLE-STAGE	BRUSH	BRUSH	BRUSH
7.0 FT-LB (136CC)	9.5 FT-LB (208CC)	9.5 FT-LB (208CC)	169CC	265CC	287CC
ARIENS AX	ARIENS AX	ARIENS AX	SUBARU EX17	SUBARU EX27	SUBARU EX30
RECOIL (120V ON 938034)	RECOIL (120V ON 938032)	120V/RECOIL	120V/RECOIL	120V/RECOIL	12V KEYSTART
21 IN (53.3 CM)	21 IN (53.3 CM)	21 IN (53.3 CM)	28 IN (71.2 CM)	36 IN (91.4 CM)	36 IN (91.4 CM)
12.2 IN (31 CM)	12.2 IN (31 CM)	12.2 IN (31 CM)	N/A	N/A	N/A
3FT - 25FT (.9 - 7.6M)	3FT - 35FT (.9 - 10.7M)	3FT - 35FT (.9 - 10.7M)	N/A	N/A	N/A
MANUAL	MANUAL	REMOTE	N/A	N/A	N/A
MANUAL	MANUAL	MANUAL	N/A	N/A	N/A
7.5 IN X 1.75 IN (19.1 X 4.4 CM)	7.5 IN X 1.75 IN (19.1 X 4.4 CM)	7.5 IN X 1.75 IN (19.1 X 4.4 CM)	15 IN X 5 IN (38 X 13CM)	16 IN X 6.5 IN (41 X 17 CM)	16 IN X 6.5 IN (41 X 17 CM)
SEMI-PNEUMATIC DIAMOND TREAD	SEMI-PNEUMATIC DIAMOND TREAD	SEMI-PNEUMATIC DIAMOND TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD	DIRECTIONAL SNOW TREAD
SOLID UNLOCKED	SOLID UNLOCKED	SOLID UNLOCKED	AUTOMATIC TRACTION CONTROL	AUTOMATIC TRACTION CONTROL	AUTOMATIC TRACTION CONTROL
2.9QT (2.7L)	2.9QT (2.7L)	2.9QT (2.7L)	3.4 QT (3.6L)	5.7QT (6.1L)	5.7QT (6.1L)
AUGER PROPELLED	AUGER PROPELLED	AUGER PROPELLED	DISC-O-MATIC	DISC-O-MATIC	HYDROSTATIC
1 FORWARD	1 FORWARD	1 FORWARD	6 FORWARD/2 REVERSE	6 FORWARD/2 REVERSE	VARIABLE
N/A	N/A	N/A	N/A	CAST ALUMINUM	CAST ALUMINUM
N/A	N/A	N/A	N/A	N/A	N/A
N/A	N/A	N/A	N/A	N/A	N/A
N/A	N/A	N/A	N/A	N/A	N/A
8.375 IN (21.3 CM)	8.375 IN (21.3 CM)	8.375 IN (21.3 CM)	18 IN (45.7 CM) BRUSH	25 IN (63.5 CM) BRUSH	25 IN (63.5 CM) BRUSH
REINFORCED RUBBER	REINFORCED RUBBER	REINFORCED RUBBER	BRUSH	BRUSH	BRUSH
N/A	N/A	N/A	N/A	N/A	N/A
POLYMER ADJUSTABLE	POLYMER ADJUSTABLE	POLYMER ADJUSTABLE	N/A	N/A	N/A
3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 90 DAY COMM	3YR CONS / 1YR COMM	3YR CONS / 1YR COMM
•	•	•	•	STANDARD	STANDARD
•	•	•	•	•	STANDARD
•	•	•	•	•	•
STANDARD ON 938034	STANDARD ON 938032	STANDARD	STANDARD	STANDARD	STANDARD
•	•	•	•	•	•
•	•	•	•	•	•
STANDARD	STANDARD	STANDARD	STANDARD	STANDARD	STANDARD
54.3 IN (137.9 CM)	54.3 IN (137.9 CM)	54.3 IN (137.9 CM)	65 IN (165.1 CM)	72 IN (182.9 CM)	72 IN (182.9 CM)
21.6 IN (54.9 CM)	21.6 IN (54.9 CM)	21.6 IN (54.9 CM)	34 IN (86.4 CM)	44 IN (111.8 CM)	44 IN (111.8 CM)
40.9 IN (103.9 CM)	40.9 IN (103.9 CM)	40.9 IN (103.9 CM)	44 IN (111.8 CM)	43 IN (109.2 CM)	43 IN (109.2 CM)
87 LB (39.46 KG)	87 LB (39.46 KG)	97 LB (44 KG)	230 LB (104.3 KG)	325 LB (147.4 KG)	335 LB (151.9 KG)

Non-Abrasive Skid Shoes

Ariens offers steel or polyethylene replacement skid shoes to prolong Sno-Thro life.



Drift Cutters

Easily cut through packed snow and drifts no matter how high or compact.



Handwarmer Kit

Ariens dash-controlled handwarmers are easy to install for maximum comfort despite harsh winter conditions

VISIT US ONLINE

Product Information • Consumer Reviews • View Videos of Ariens Products • Dealer Locator • Customer Support

WWW.ARIENS.COM



Scan with mobile device
for additional Ariens
product information.



©Registered Trademark and TM trademark of Ariens Company. Briggs & Stratton®, Subaru® & Hydrogear® are registered trademarks of their respective companies. Sno-Thru unit specifications and features are subject to change without notice. Photos are a representation, actual product may differ.

WWW.ARIENS.COM

© Copyright 2014 Ariens Company. All rights reserved.

An *Ariens* Company Brand