

Sidewinder® Articulating Head Tactical Flashlight

FL STANDARD	C4® LED HIGH
	55 LUMENS
	5h 30min
	69m
	1,175cd
	1m
	3m

Product is tested per ANSI/NEMA FL-1, 2009 standard



Case Material: High impact super-tough nylon case offers exceptional durability and weather resistance. All openings are O-ring sealed. Available in Coyote and OD Green. Unbreakable polycarbonate lens with scratch-resistant coating. Gasket sealed.

Dims/Weight: Length: 2.34 in (4.94 cm) Width: 1.08 in. (2.74 cm) Depth: 4.65 in. (11.81 cm) ; 4.38 oz (124 grams) 5.02 oz (142 grams) with "AA" batteries

Light Source: High output white C4® LED, shockproof, 50,000Hr lifetime/55 lumens, 1,175 candela peak beam intensity and 69m beam distance
 (See model for specific LED configuration)
 5mm IR LED, 880 nm peak wavelength, shockproof, 100,000Hr lifetime/25mW/sr (min) radiant intensity
 5mm Red LED, 630 nm peak wavelength, shockproof, 100,000Hr lifetime/1 lumen, 40 candela peak beam intensity and 13m beam distance
 5mm Blue LED, 470 nm peak wavelength, shockproof, 100,000Hr lifetime/1.8 lumens, 130 candela peak beam intensity and 23m beam distance
 5mm Green LED, 527 nm peak wavelength, shockproof, 100,000Hr lifetime/4.5 lumens, 68 candela peak beam intensity and 16m beam distance

On/Off/Intensity Mode Selection: Compound On-Off mode selector switch ergonomically separates On-Off-Dimming-Strobe and LED selection functions. Design does not require the operator to access separate switching locations on the device. Rubber dome actuator and 4 position pull-to-turn locking rotary selector knob with tactile indicator (IR for Military and Aviation models; green LED for Sportsman model) provides easy operation even when wearing heavy gloves.

Battery: Two (2) "AA" size alkaline batteries (included) provide fast replacement with readily available batteries. Lithium "AA" cells allow extended operation in extreme temperature environments (-40F to 150F). Tactile battery polarity indication on body allows replacement of cells in dark environment.

Approvals: Most models meet applicable European Community Directives.

Warranty: Streamlight warrants its Sidewinder (excepting batteries) will be free from manufacturing defects under normal use for 12 months after purchase. During the warranty period, at its sole discretion, Streamlight will repair or replace any defective part or product

Features:

Push-button switch specified to 300K operations	Cord attachment holes provided in battery compartment cover capable of supporting 25 lbs of load
Pull-to-turn locking rotary knob prevents accidental mode changes	Tactile battery polarity indicators for battery replacement in the dark
Push-button switch enables/disables selected lighting source starting at low intensity and progressing to the brightest intensity in 4 discreet steps	Tethered battery compartment cap facilitates battery replacement in the dark without losing cap
Double-click of button initiates high intensity strobe of selected light source	IPX7 Rated design; waterproof to 1 meter for 30 minutes. Meets MIL-STD-801F Method 512.4

SIDEWINDER® LIGHT OUTPUT & BATTERY RUN TIME						
LED	Light Output	Low 5% Output	Medium 1 25% Output	Medium 2 60% Output	High 100% Output	Strobe 100% Output
C4®	55 Lumens	100 Hrs*	45 Hrs	11 Hrs	5.5 Hrs	10 Hrs
5mm IR	25mW/sr (min) radiant intensity	200 Hrs*	140 Hrs	60 Hrs	24 Hrs	40 Hrs
5mm Red	1 Lumens	200 Hrs*	140 Hrs	60 Hrs	24 Hrs	40 Hrs
5mm Blue	1.8 Lumens	150 Hrs*	100 Hrs	35 Hrs	16 Hrs	30 Hrs
5mm Green	4.5 Lumens	150 Hrs*	100 Hrs	35 Hrs	16 Hrs	30 Hrs


*All runtime claims to 10% of initial output level. Illumination output electronically regulated.

Item	UPC	Part #
<i>Military Model - Each LED features 4 levels of increased output intensities: Low, Medium, Medium-High, High, plus Strobe.</i>		
Sidewinder White C4 LED, Red, Blue, IR LEDs. Includes 2 "AA" alkaline batteries. Clam Packaged - Coyote	080926-14000-4	14000
Sidewinder White C4 LED, Red, Blue, IR LEDs. Includes 2 "AA" alkaline batteries. Clam Packaged - Green	080926-14001-1	14001
Sidewinder White C4 LED, Red, Blue, IR LEDs. Includes helmet mount & 2 "AA" alkaline batteries. Clam Packaged - Green	080926-14027-1	14027
<i>Aviation Model - Each LED features 4 levels of increased output intensities: Low, Medium, Medium-High, High, plus Strobe.</i>		
Sidewinder White C4 LED, Green, Blue, IR LEDs. Includes 2 "AA" alkaline batteries. Clam Packaged - Coyote	080926-14008-0	14008
Sidewinder White C4 LED, Green, Blue, IR LEDs. Includes retainer and 2 "AA" alkaline batteries. Boxed - Coyote	080926-14024-0	14024
<i>Sportsman Model - Each LED features 4 levels of output intensities: High, Medium, Medium-High, High, Low plus Strobe.</i>		
Sidewinder Sportman Model White C4 LED, Red, Blue, Green LEDs. Includes 2 "AA" alkaline batteries. Clam Packaged - Coyote	080926-14002-8	14002





Helmet not included

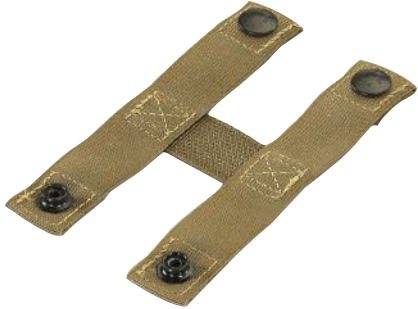

Item		UPC	Part #
Sidewinder Helmet Mount	Coyote	080926-14055-4	14055
Sidewinder Helmet Mount	Green	080926-14056-1	14056
Safety Wand	Glow-in-the-Dark	080926-14902-1	14902
Replacement retainer		080926-14030-1	14030
1913 rail mount adapter (for helmets only. Not intended for use with long guns)	Coyote	080926-14057-8	14057
1913 rail mount adapter (for helmets only. Not intended for use with long guns)	Green	080926-14058-5	14055
Lithium batteries - 2 Pack		080926-85175-7	85175
Lithium batteries - 12 Pack		080926-85177-1	85177
Lithium batteries - 400 Pack		080926-85179-5	85179
Lithium batteries - 6 Pack		080926-85180-1	85180

