

# YES!

WE CAN!



## BLACK RIVETWELL™ SHELVING

While Parchment remains an affordable all-time favorite, our prestigious black Rivetwell shelving is a great way to add style to your facility.

Midnight Ebony powder coat finish with precision smooth surfaces will look fantastic in your office as well as your warehouse. Make a statement with our new black color! Black Rivetwell shelving is center supported double rivet unit for extra heavy duty applications, and can be used with a number of decking options.



Shown with Wire Decking



**Shown with  
EZ-Deck**



**Without  
Decking**



**Shown with  
Featherdeck**



**Shown with  
Particle Board Decking**

# YES!

**WE CAN!**




**PARTICLE BOARD DECK**



**EZ DECK**



**WIRE DECK**

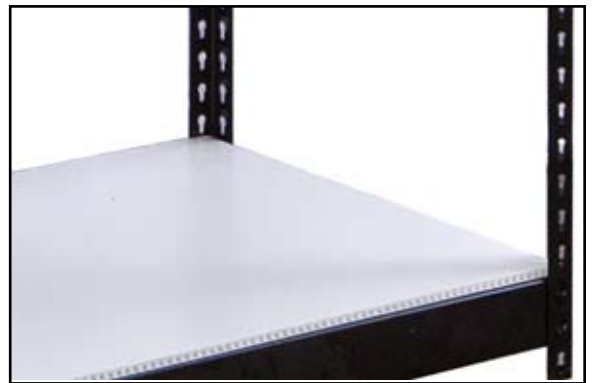

**FEATHERDECK**

- 3 shelf levels adjustable on 1-1/2" increments
- Midnight Ebony (Black) powder coat finish
- All levels are center supported
- Height 84"
- Double rivet connection on all shelf supports

*\* Level Capacity based on a uniformly distributed load (1.65 safety factor)*

*Starter Units: Consist of four standard angle posts, two left-to-right and two front-to-back double rivet angle beams per level and one center support per level (two center supports per level at 96" wide units).*

*Add*

*On Units: Consist of two standard tee posts, two left-to-right and two front-to-back double rivet angle beams per level and one center support per level (two center supports per level at 96" wide units).*

## Black Rivetwell Shelving

Type	Width	Depth	Model No. No Deck	Level Capacity*	Model No. Particle board	Level Capacity*	Model No. Wire Deck	Level Capacity*	Model No. Featherdeck	Level Capacity*	Model No. EZ Deck	Level Capacity*
Starter	48"	18"	14L083	1400	14L144	770	14C690	900	14L205	290	14L265	770
Add On	48"	18"	14L084	1400	14L145	770	14C691	900	14L206	290	14L266	770
Starter	48"	24"	14L085	1400	14L146	700	14C692	700	14L207	250	14L267	700
Add On	48"	24"	14L086	1400	14L147	700	14C693	700	14L208	250	14L268	700
Starter	48"	30"	14L087	1310	14L148	705	14C694	550	14L209	165	14L269	705
Add On	48"	30"	14L088	1310	14L149	705	14C695	550	14L210	165	14L270	705
Starter	48"	36"	14L089	1220	14L150	755	14C696	500	14L211	125	14L271	755
Add On	48"	36"	14L090	1220	14L151	755	14C697	500	14L212	125	14L272	755
Starter	48"	48"	14L091	1125	14L152	920	14C698	500	14L213	150	14L273	920
Add On	48"	48"	14L092	1125	14L153	920	14C699	500	14L214	150	14L274	920
Starter	60"	18"	14L093	1200	14L154	835	14C701	1800	14L215	380	14C640	835
Add On	60"	18"	14L094	1200	14L155	835	14C702	1800	14L216	380	14C641	835
Starter	60"	24"	14L095	1200	14L156	700	14C703	1400	14L217	200	14C642	700
Add On	60"	24"	14L096	1200	14L157	700	14C704	1400	14L218	200	14C643	700
Starter	60"	30"	14L097	1200	14L158	650	14C705	1000	14L219	150	14C644	650
Add On	60"	30"	14L098	1200	14L159	650	14C706	1000	14L220	150	14C645	650
Starter	60"	36"	14L099	1200	14L160	665	14C707	1000	14L221	130	14C646	665
Add On	60"	36"	14L101	1200	14L161	665	14C708	1000	14L222	130	14C647	665
Starter	60"	48"	14L102	1200	14L162	750	14C709	1000	14L223	145	14C648	750
Add On	60"	48"	14L103	1200	14L163	750	14C710	1000	14L224	145	14C649	750
Starter	72"	18"	14L104	1000	14L164	1000	14C711	1000	14L225	310	14C650	1000
Add On	72"	18"	14L105	1000	14L165	1000	14C712	1000	14L226	310	14C651	1000
Starter	72"	24"	14L106	1000	14L166	770	14C713	1000	14L227	185	14C652	770
Add On	72"	24"	14L107	1000	14L167	770	14C714	1000	14L228	185	14C653	770
Starter	72"	30"	14L108	1000	14L168	680	14C715	1000	14L229	160	14C654	680
Add On	72"	30"	14L109	1000	14L169	680	14C716	1000	14L230	160	14C655	680
Starter	72"	36"	14L110	1000	14L170	655	14C717	1000	14L231	155	14C656	655
Add On	72"	36"	14L111	1000	14L171	655	14C718	1000	14L232	155	14C657	655
Starter	72"	48"	14L112	1000	14L172	685	14C719	1000	14L233	160	14C658	685
Add On	72"	48"	14L113	1000	14L173	685	14C720	1000	14L234	160	14C659	685
Starter	96"	18"	14L114	620	14L174	620	14C721	620	14L235	375	14C660	620
Add On	96"	18"	14L115	620	14L175	620	14C722	620	14L236	375	14C661	620
Starter	96"	24"	14L116	620	14L176	620	14C723	620	14L237	290	14C662	620
Add On	96"	24"	14L117	620	14L177	620	14C724	620	14L238	290	14C663	620
Starter	96"	30"	14L118	620	14L178	620	14C725	620	14L239	185	14C664	620
Add On	96"	30"	14L119	620	14L179	620	14C726	620	14L240	185	14C665	620
Starter	96"	36"	14L120	620	14L180	620	14C727	620	14L241	185	14C666	620
Add On	96"	36"	14L121	620	14L181	620	14C728	620	14L242	185	14C667	620
Starter	96"	48"	14L122	620	14L182	620	14C729	620	14L243	230	14C668	620
Add On	96"	48"	14L123	620	14L183	620	14C730	620	14L244	230	14C669	620
<b>EXTRA LEVELS</b>												
	48"	18"	14L124	1400	14L184	770	14C731	900	14L245	290	14C670	770
	48"	24"	14L125	1400	14L185	700	14C732	700	14L246	250	14C671	700
	48"	30"	14L126	1310	14L186	705	14C733	550	14L247	165	14C672	705
	48"	36"	14L127	1220	14L187	755	14C734	500	14L248	125	14C673	755
	48"	48"	14L128	1125	14L188	920	14C735	500	14L249	150	14C674	920
	60"	18"	14L129	1200	14L189	835	14C736	1800	14L250	380	14C675	835
	60"	24"	14L130	1200	14L190	700	14C737	1400	14L251	200	14C676	700
	60"	30"	14L131	1200	14L191	650	14C738	1000	14L252	150	14C677	650
	60"	36"	14L132	1200	14L192	665	14C739	1000	14L253	130	14C678	665
	60"	48"	14L133	1200	14L193	750	14C740	1000	14L254	145	14C679	750
	72"	18"	14L134	1000	14L194	1000	14C741	1000	14L255	310	14C680	1000
	72"	24"	14L135	1000	14L195	770	14C742	1000	14L256	185	14C681	770
	72"	30"	14L136	1000	14L196	680	14C743	1000	14L257	160	14C682	680
	72"	36"	14L137	1000	14L197	655	14C744	1000	14L258	155	14C683	655
	72"	48"	14L138	1000	14L198	685	14C745	1000	14L259	160	14C684	685
	96"	18"	14L139	620	14L199	620	14C746	620	14L260	375	14C685	620
	96"	24"	14L140	620	14L201	620	14C747	620	14L261	290	14C686	620
	96"	30"	14L141	620	14L202	620	14C748	620	14L262	185	14C687	620
	96"	36"	14L142	620	14L203	620	14C749	620	14L263	185	14C688	620
	96"	48"	14L143	620	14L204	620	14C750	620	14L264	230	14C689	620