



Features

- Snap-on and twist installation requires no tools
- Easily adjusts by rotating up or down
- For support and positioning of refrigeration, A/C tubing, PEX piping, conduit and cabling
- Compliant with UL® 2043 and suitable for use in air handling spaces

CADDY® SWIFT CLIP Threaded Rod Attachment



Material: Polyamide
Temperature: -40 – 284 °F

Part Number	Outer Diameter	Copper Tube Size	Pipe Size	Rod Size
TRC062	5/8"	1/2"	-	3/8"
TRC075	3/4"	5/8"	-	3/8"
TRC087	7/8"	3/4"	1/2"	3/8"
TRC100	1"	-	3/4"	3/8"
TRC112	1 1/8"	1"	-	3/8"
TRC125	1 1/4"	-	1"	3/8"
TRC137	1 3/8"	1 1/4"	-	3/8"
TRC150	1 1/2"	-	-	3/8"
TRC162	1 5/8"	1 1/2"	-	3/8"
TRC200	2"	-	-	3/8"
TRC212	2 1/8"	2"	-	3/8"

UL is a registered certification mark of UL LLC.

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.


Copyright © 2013 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.



Features

- Snap-in installation requires no tools
- Fits into strut channel, twist installation
- Use for installation of refrigeration, A/C tubing and PEX piping in horizontal and vertical channels
- Compliant with UL® 2043 and suitable for use in air handling spaces

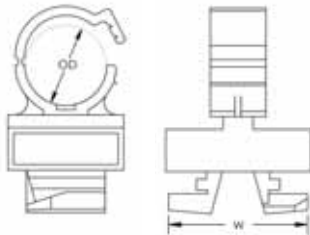

CADDY® SWIFT CLIP Strut Clamp for Tube/Pipe




Material: Polyamide
Temperature: -40 – 284 °F

Part Number	Outer Diameter OD	Copper Tube Size	Pipe Size	Width W
TSM0037	3/8"	1/4"	-	1 5/8"
TSM0050	1/2"	3/8"	-	1 5/8"
TSM0062	5/8"	1/2"	-	1 5/8"
TSM0075	3/4"	5/8"	-	1 5/8"
TSM0087	7/8"	3/4"	1/2"	1 5/8"
TSM0112	1 1/8"	1"	-	1 5/8"
TSM0137	1 3/8"	1 1/4"	-	1 5/8"
TSM0162	1 5/8"	1 1/2"	-	1 5/8"

Can also be used with PEX piping. For PEX pipe sizes, refer to the Copper Tube Size column.

Features

- Snap-in installation requires no tools
- Fits into strut channel, twist installation
- Compliant with UL® 2043 and suitable for use in air handling spaces

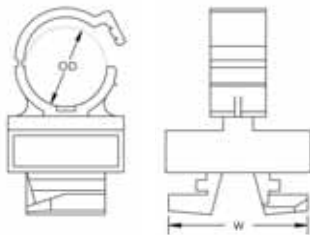

CADDY® SWIFT CLIP Strut Clamp for Insulated Tube/Pipe



Material: Polyamide
Temperature: -40 – 284 °F

Part Number	Outer Diameter OD	Copper Tube Size	Copper Tube with 3/8" Insulation	Copper Tube with 1/2" Insulation	Pipe Size	Width W
TSMI0062	5/8"	1/2"	-	-	-	1 5/8"
TSMI0075	3/4"	5/8"	-	-	-	1 5/8"
TSMI0087	7/8"	3/4"	-	-	1/2"	1 5/8"
TSMI0100	1"	-	1/4"	-	3/4"	1 5/8"
TSMI0112	1 1/8"	1"	3/8"	-	-	1 5/8"
TSMI0125	1 1/4"	-	1/2"	1/4"	1"	1 5/8"
TSMI0137	1 3/8"	1 1/4"	5/8"	3/8"	-	1 5/8"
TSMI0150	1 1/2"	-	7/8"	5/8"	-	1 5/8"
TSMI0162	1 5/8"	1 1/2"	1 1/8"	3/4"	-	1 5/8"
TSMI0200	2"	-	-	7/8"	-	1 5/8"
TSMI0212	2 1/8"	2"	1 3/8"	1 1/8"	-	1 5/8"

Can also be used with PEX piping. For PEX pipe sizes, refer to the Copper Tube Size column.

