



PRODUCT FEATURES

- Single gang, stainless steel plate with low voltage mounting ring
- 12 key illuminated 3x4 keypad
- True 10-digit operation (10 digits plus * and # keys)
- 99 user code capability
- Easy programming from the keypad
- Passage mode and Lockout mode
- Configurable audible keystroke echo
- Red, green and yellow LEDs for status and programming feedback
- Fail secure or fail safe-capable
- Easy to install with simple hand tools
- Accepts 12V or 24VAC or DC current
- 5 Amp SPDT timed, control relay output
- Request to Exit (REX) input
- MagnaCare Lifetime Replacement No Fault Warranty

PRODUCT OPTIONS

- Weather-resistant cover
- Weather-resistant backbox

Dimensions:
2-3/4"W x 4-1/2"H x 5/32"D

Electrical:
70mA at 12VDC or 24VDC
Maximum 30VDC or 300VAC switched voltage

Operating Temperature:
-10 to +140F [-23 to +60C]
Primarily for indoor applications

Shipping Weight:
1lb [0.45kg]

Finishes:
US32B/630 - Satin Stainless Steel



WCC



WBB

WCC and WBB allow DK-12 keypad to be mounted in outdoor locations not directly exposed to rain or snow

DK-12

Digital Keypad


All-in-One Keypad System for Single-Door Traffic Control

The DK-12 standalone keypad and controller is ideal for lower security requirements such as traffic control. Easy to install and easy to program, the one-piece DK-12 supports 99 user codes, including Passage mode and Lockout mode.

» MODELS

PART # | Description

DK-12	Digital Keypad System w/ Illuminated Keys - Single Gang
WBB	Weather Back Box
WCC	Weather Cover - Clear

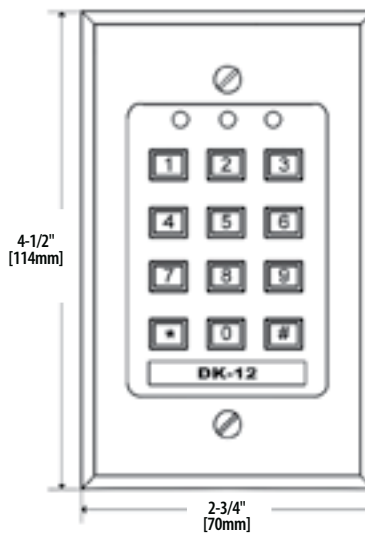

SECURITRON
ASSA ABLOY