




### Technical Specs

	22A592	22A593
SHIPPING WEIGHT	21.75 LBS	31 LBS
MAXIMUM LIQUID TEMPERATURE	180°F (82°C)	180°F (82°C)
INTAKE & DISCHARGE PORTS	3/4" PORT, NPT	1" PORT, NPT
FLOW	0 - 32 GPM MAX	0 - 46 GPM MAX
MAX AIR SUPPLY PRESSURE	100 PSI (1.4 - 7 KGF/CM <sup>2</sup> )	100 PSI (1.4 - 7 KGF/CM <sup>2</sup> )
BODY MATERIAL	ALUMINUM	ALUMINUM
LIFT - DRY, WET	18 FT, 28 FT	18 FT, 28 FT
<b>AIR VALVE</b>		
LUBRICATION	NO LUBRICATION REQUIRED	NO LUBRICATION REQUIRED
MANUAL OVERRIDE	YES	YES
<b>LIQUID SIDE</b>		
EASY REPAIR	YES	YES
BALL CHECK VALVE	BUNA N	BUNA N
O-RINGS	BUNA N	BUNA N
DIAPHRAGMS	BUNA N	BUNA N

# DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP


22A592, 22A593

## Dimensional Drawings

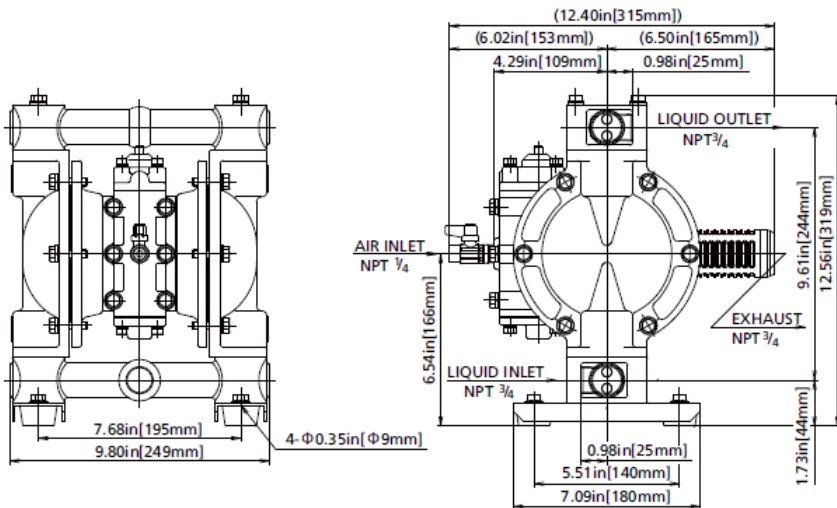


22A592


## Performance Curves

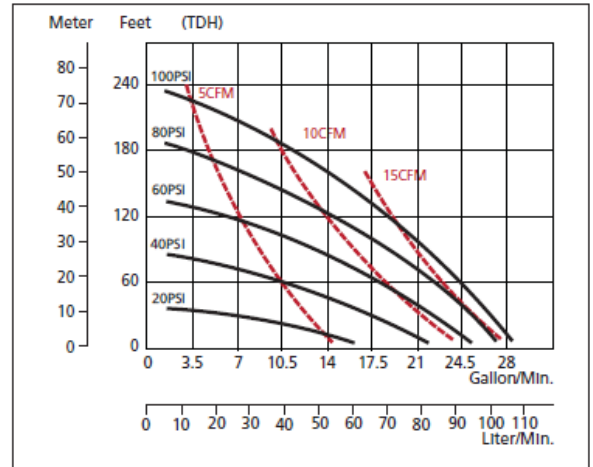

22A592

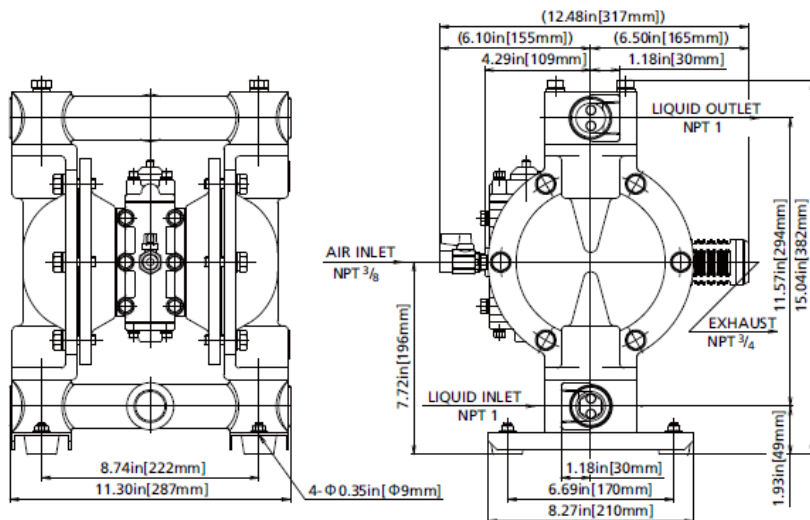

22A593

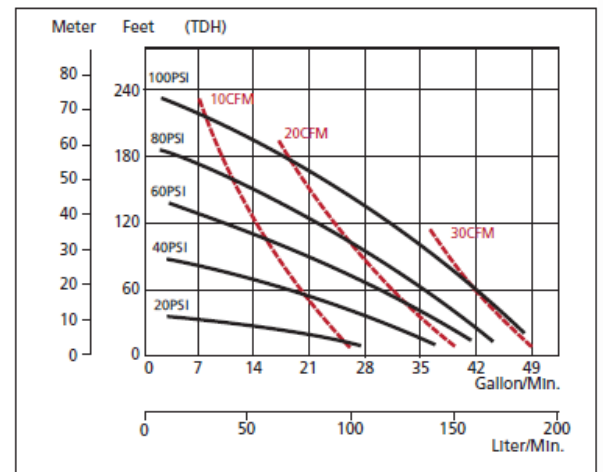

22A593

Find it at Grainger.

Call or visit your local branch or go to [grainger.com/dayton](http://grainger.com/dayton) for complete product line information.

