

Technical Specs

22A604


22A605

SHIPPING WEIGHT	32.0 LBS	32.0 LBS
MAXIMUM LIQUID TEMPERATURE	212°F (100°C)	212°F (100°C)
INTAKE & DISCHARGE PORTS	1" PORT, SANITARY CLAMP	1" PORT, SANITARY CLAMP
FLOW	0 - 32 GPM MAX	0 - 32GPM MAX
MAX AIR SUPPLY PRESSURE	100 PSI (1.4 - 7 KGF/CM ²)	100 PSI (1.4 - 7 KGF/CM ²)
BODY MATERIAL	316 STAINLESS STEEL	316 STAINLESS STEEL
LIFT-DRY, WET	18 FT, 28 FT	18FT, 28 FT
AIR VALVE		
LUBRICATION	NO LUBRICATION REQUIRED	NO LUBRICATION REQUIRED
MANUAL OVERRIDE	YES	YES
LIQUID SIDE		
EASY REPAIR	YES	YES
BALL CHECK VALVE	PTFE	PTFE
O-RINGS	PTFE	PTFE
DIAPHRAGMS	PTFE	HYTREL


DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP

22A604, 22A605


Dimensional Drawing

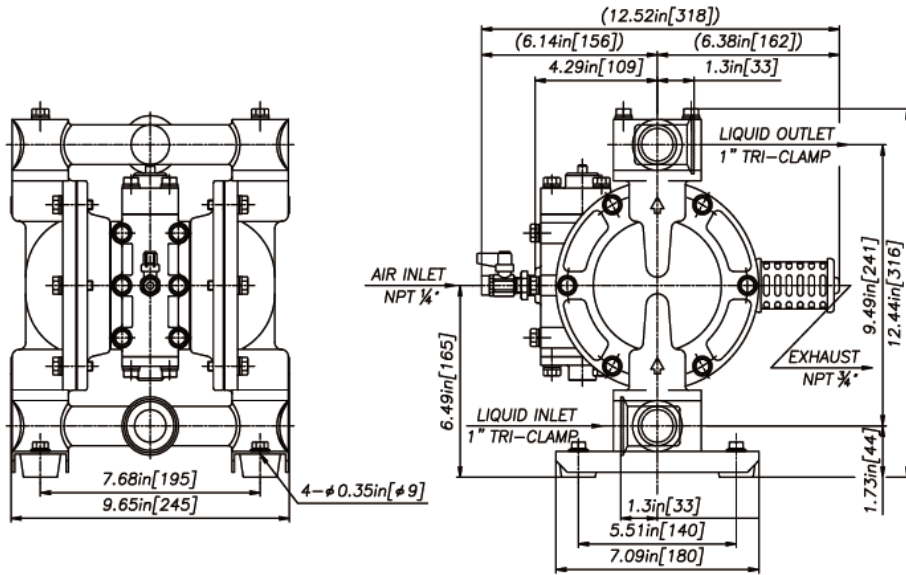

Performance Curve

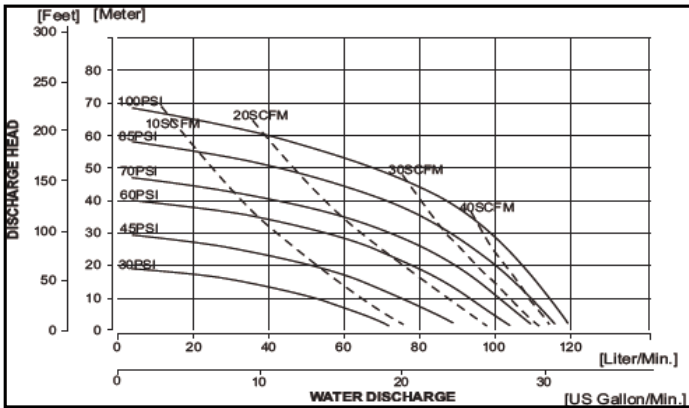

22A604

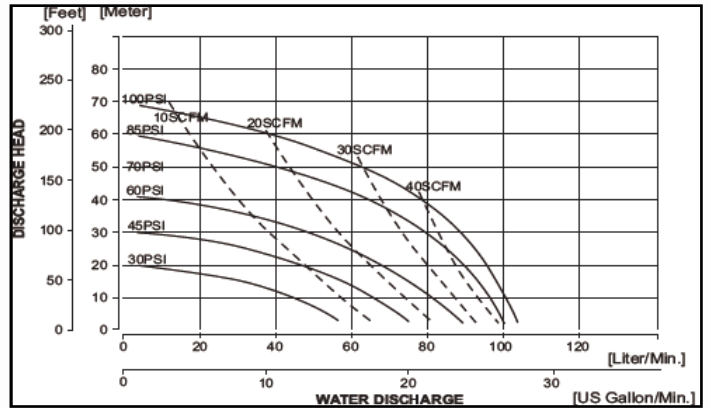

22A605

Find it at Grainger.

Call or visit your local branch or go to grainger.com/dayton for complete product line information.

