


## DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP DATA SHEET 6PY35, 6PY40

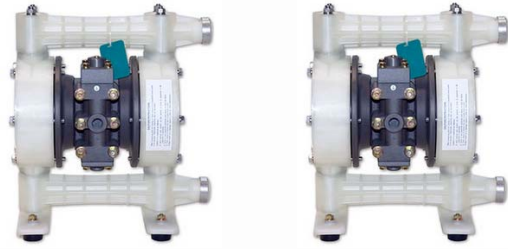


### Technical Specs

	6PY35	6PY40
SHIPPING WEIGHT	21.7 LBS	21.9 LBS
MAXIMUM LIQUID TEMPERATURE	180°F (82°C)	212°F (100°C)
INTAKE & DISCHARGE PORTS	3/4" PORT, NPT	3/4" PORT, NPT
FLOW	0 - 28 GPM MAX	0 - 28 GPM MAX
MAX AIR SUPPLY PRESSURE	20 - 100 PSI (1.4 - 7 KGF/CM <sup>2</sup> )	20 - 100 PSI (1.4 - 7 KGF/CM <sup>2</sup> )
BODY MATERIAL	POLYPROPYLENE	POLYPROPYLENE
LIFT- DRY, WET	18 FT, 28 FT	18 FT, 28 FT
<b>AIR VALVE</b>		
LUBRICATION	NO LUBRICATION REQUIRED	NO LUBRICATION REQUIRED
MANUAL OVERRIDE	YES	YES
<b>LIQUID SIDE</b>		
EASY REPAIR	YES	YES
BALL CHECK VALVE	SANTOPRENE®	PTFE
O-RINGS	SANTOPRENE®/EPDM	PTFE
DIAPHRAGMS	SANTOPRENE®	PTFE


# DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP

6PY35, 6PY40


## Dimensional Drawing

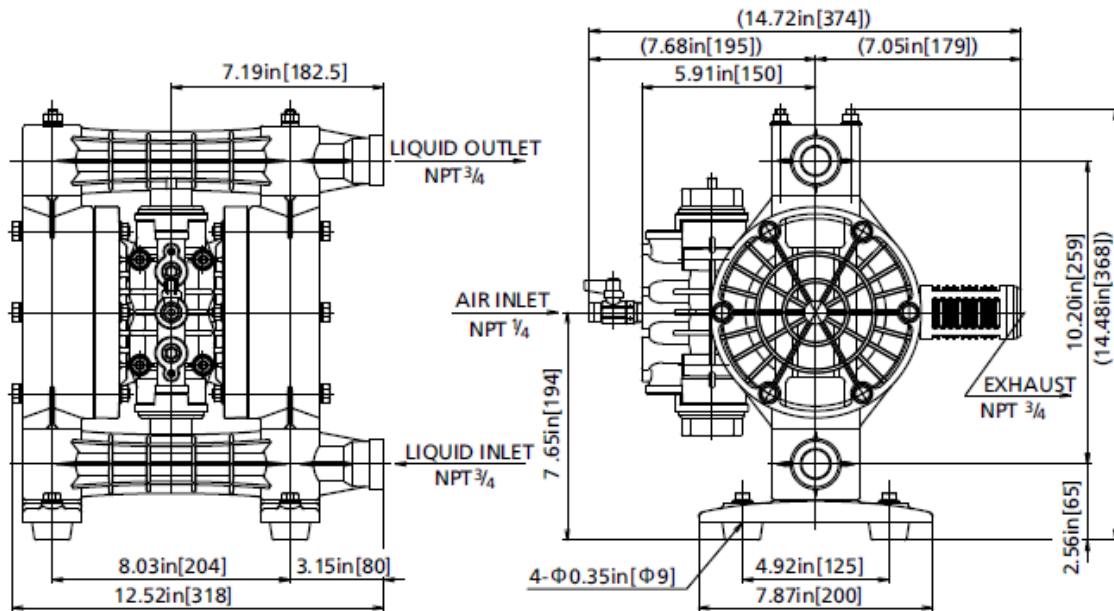

## Performance Curve

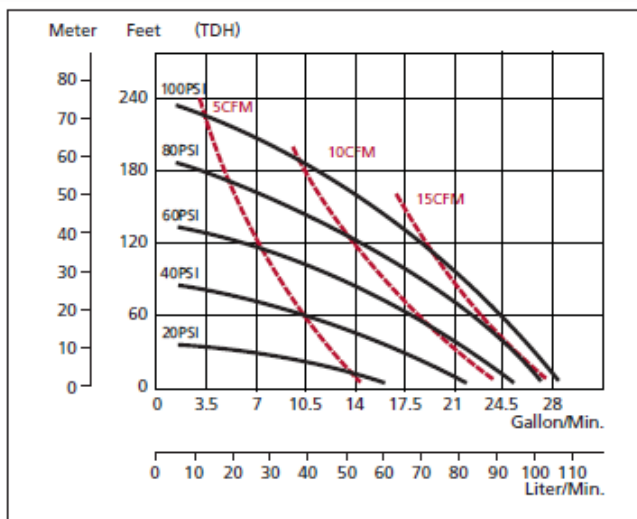

6PY35

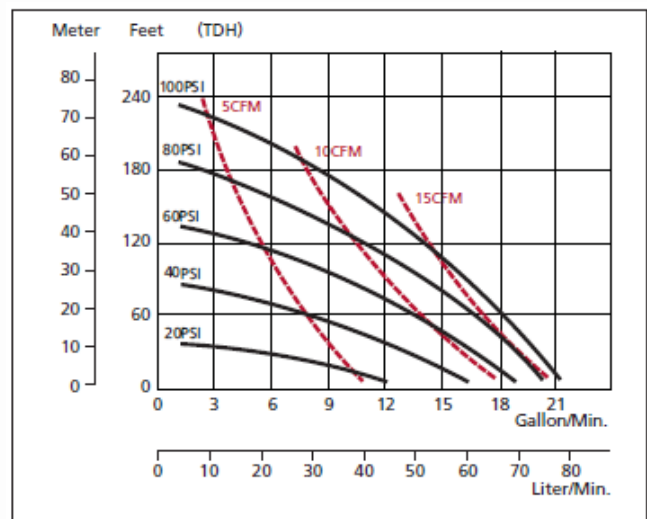

6PY40

Find it at Grainger.

Call or visit your local branch or go to [grainger.com/dayton](http://grainger.com/dayton) for complete product line information.

