



PRODUCT FEATURES

- Redundant switches
- Release triggered by either 1/8" mechanical movement or reliable touch sense technology
- Optional MicroShield Anti-microbial coating ideal for infection control in health care environment
- Resistant to interference from radio frequency or electromagnetic frequency and external impact/bounce attempts
- All metal construction
- Can be field cut to fit non-standard door widths
- 16 ft. [4.8m] 22AWG 6 conductor cable and armored door cord included
- Automatic dual voltage 12VDC or 24VDC
- Resists electrostatic discharge up to 27,000 volts
- MagnaCare Lifetime Replacement No Fault Warranty

PRODUCT OPTIONS

- 36" Length
- 42" Length
- 48" Length
- EL- Prefix any model for ElectroLynx® ready

- Through-bolt kit for doors 1-3/4" to 2-1/4" thick
- D- Prefix any model for dummy bar with no release function
- -I Add to any model for Illuminated via fiber optics
- -A Add to any model for MicroShield Anti-microbial coating

SPECIFICATIONS

- CAN/ULC-S533 Listed
- ANSI/UL 294 Listed
- CSA-C22.2 No.205 Listed
- NFPA 101
- Patent pending

Electrical:

Dual Sense Bar Only - 24mA at 12VDC or 24VDC

Dual Sense Bar with Illumination - 44mA at 12VDC or 24VDC

Operating Temperature:


+32 to +120F [0 to +49C]
Recommended for indoor use only

Shipping Weight:

6lbs [2.72kg] to 8lbs [3.63kg]
depending on length

Finishes:

BK - Black anodized
CL - Clear anodized

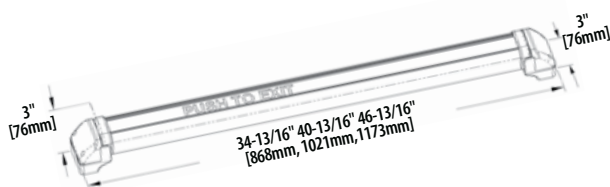

DSB

Dual Sense Bar

Dependable Touch and Mechanical Release for Superior Safety and Redundancy

The dependable DSB Dual Sense Bar is the most reliable exit device available for magnetically locked, non-fire-rated doors. Its unique design delivers superior fault tolerance with two independent, redundant switch circuits for releasing the lock. The DSB can be installed on all types of interior metal, aluminum or wood doors. Meets "no special tools or knowledge" criteria required by code.

MODELS

PART # | Description

DSB-BK	DSB - 36", Black Anodized
DSB-BK42	DSB - 42", Black Anodized
DSB-BK48	DSB - 48", Black Anodized
DSB-BKA	DSB - 36", Black Anodized, Anti-Microbial
DSB-BKA42	DSB - 42", Black Anodized, Anti-Microbial
DSB-BKA48	DSB - 48", Black Anodized, Anti-Microbial
DSB-BKI	DSB - 36", Illuminated, Black Anodized
DSB-BKI42	DSB - 42", Illuminated, Black Anodized
DSB-BKI48	DSB - 48", Illuminated, Black Anodized
DSB-BKIA	DSB - 36", Illuminated, Black Anodized, Anti-Microbial
DSB-BKIA42	DSB - 42", Illuminated, Black Anodized, Anti-Microbial
DSB-BKIA48	DSB - 48", Illuminated, Black Anodized, Anti-Microbial
DSB-CL	DSB - 36", Clear Anodized
DSB-CL42	DSB - 42", Clear Anodized
DSB-CL48	DSB - 48", Clear Anodized
DSB-CLA	DSB - 36", Clear Anodized, Anti-Microbial
DSB-CLA42	DSB - 42", Clear Anodized, Anti-Microbial
DSB-CLA48	DSB - 48", Clear Anodized, Anti-Microbial
DSB-CLI	DSB - 36", Illuminated, Clear Anodized
DSB-CLI42	DSB - 42", Illuminated, Clear Anodized
DSB-CLI48	DSB - 48", Illuminated, Clear Anodized
DSB-CLIA	DSB - 36", Illuminated, Clear Anodized, Anti-Microbial
DSB-CLIA42	DSB - 42", Illuminated, Clear Anodized, Anti-Microbial
DSB-CLIA48	DSB - 48", Illuminated, Clear Anodized, Anti-Microbial
DSB-TDM	Through Door Mounting Kit for DSB
TCP-BK	Touch Bar Cover Plates - Set of 2, Black Anodized
TCP-CL	Touch Bar Cover Plates - Set of 2, Clear Anodized

