

**Models:**

92858, 92801, 92803  
 92811, 92824, 92825  
 92827, 92828, 92846  
 92847, 92848, 92849  
 92863, 94432, 94434  
 94450


Parts Page Reorder No. PD08•35  
 Effective July, 2008

# Aluminum Hub Dynacushion®

*Pneumatic Wheel*



Always operate, inspect and maintain this tool in accordance with the Safety Code for portable air tools (ANSI B186.1) and any other applicable safety codes and regulations. Please refer to Dynabrade's Warning/Safety Operating Instructions for more complete safety information.

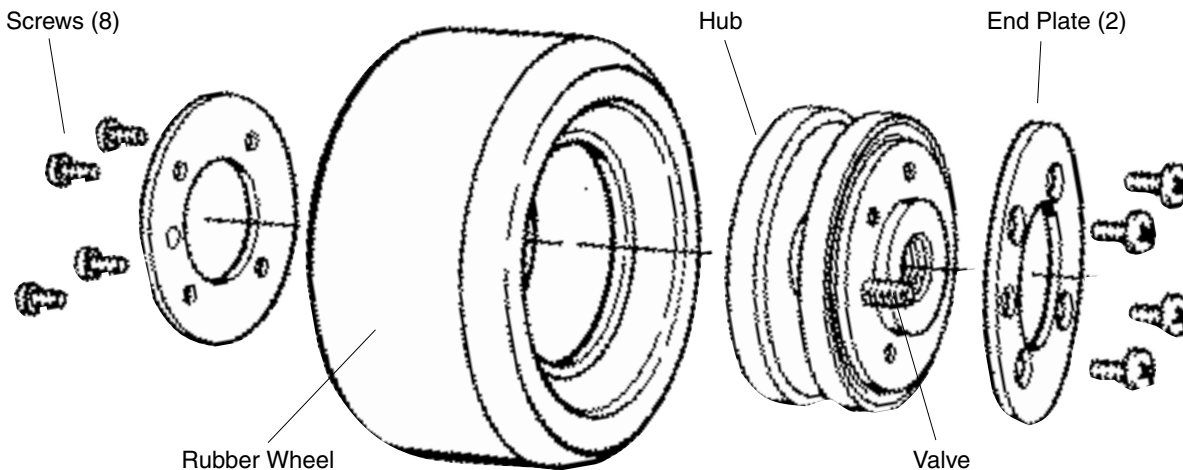

Inflate Dynacushion to 20 PSI maximum.

## Dynacushion® Pneumatic Wheel - Parts Chart

No.	Part No.	Description/Size	Rubber Wheel	Hub	Valve	End Plate	Screw
1	92858	2-1/4" D. x 3" W	94433	98070	94489	98071	N/A
2	92801	5" D. x 3-1/2" W	94481	98099	94489	N/A	98067
3	92803	5" D. x 3-1/2" W	94481	98125	94489	N/A	98067
4	92811	5" D. x 2-3/4" W	94482	98099	94489	N/A	98067
5	92824	3-1/4" D. x 3" W	92646	98080	94489	N/A	98063
6	92825	3-1/4" D. x 3" W	92646	98081	94489	N/A	98063
7	92827	3-1/4" D. x 3" W	92647	98080	94489	N/A	98063
8	92828	3-1/4" D. x 3" W	92647	98081	94489	N/A	98063
9	92846	3" D. x 2 1/4" W	92643	98074	94489	N/A	98067
10	92847	3" D. x 2 1/4" W	92643	98075	94489	N/A	98067
11	92848	3" D. x 2 1/4" W	92644	98074	94489	N/A	98067
12	92849	3" D. x 2 1/4" W	92644	98075	94489	N/A	98067
13	92863	90mm D x 100mm W	92651	92864	94489	N/A	98067
14	94432	2-1/4" D. x 3" W	94433	98070	94489	98072	N/A
15	94434	3-1/4" D. x 7" W	94435	98087	94489	N/A	98067
16	94450	8-1/4" D x 9" W	94451	94462	94489	94461	95427



**DYNABRADE, INC.,** 8989 Sheridan Drive • Clarence, New York 14031-1490 • Telephone: (716) 631-0100 • Fax: 716-631-2073  
**DYNABRADE EUROPE s.a.r.l.,** Zone Artisanale • L-5485 Wormeldange—Haut, Luxembourg • Telephone: 352 76 84 94 • Fax: 352 76 84 95